

Features


- **Inverter technology** creates quiet, clean power.
- **Lightweight, compact design** with built in handle for easy portability.
- **Low-oil level shutdown** automatically safeguards engine from damage.
- **FlexPower™ Mode** saves fuel and reduces noise.
- **Durable, fully enclosed case** for added durability and strength.
- **Circuit breakers** provide electronic overload protection.
- **LED lights** indicate status.

Models 5793-0, 5793-1, 5793-2 UPC: 696471057935
(EPA/49-State/cETL)



AC Rated Output Running Watts 2000
AC Maximum Output Starting Watts 2200

49-State Control Panel

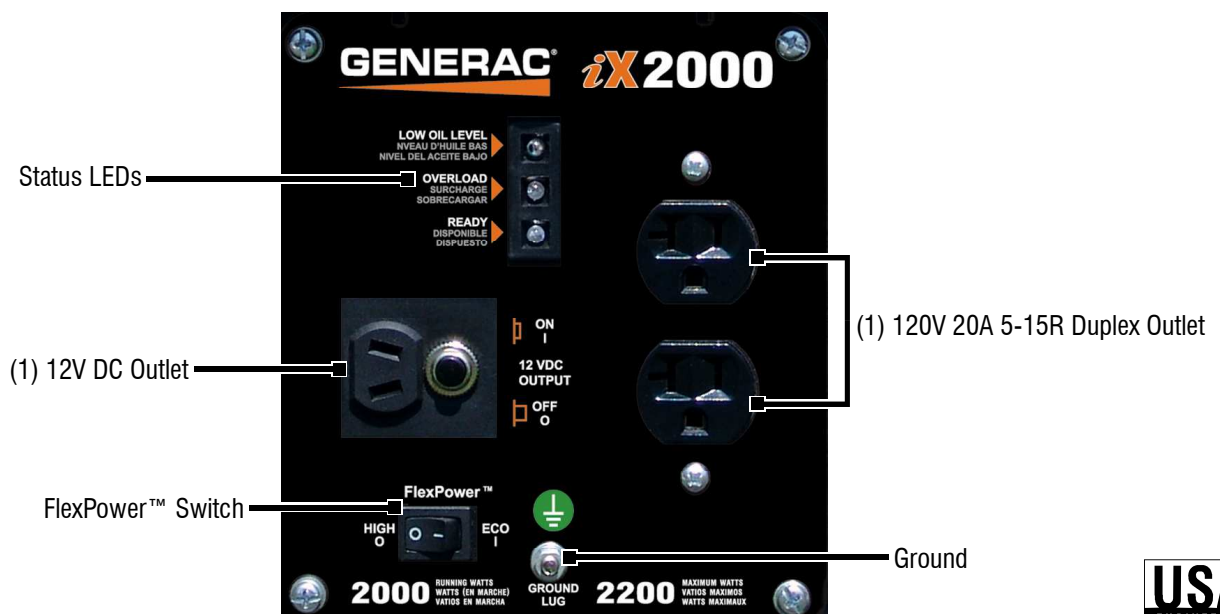

iX2000

Specifications

| | |
|----------------------------------|---|
| Product Series | iX2000 |
| Model (Configuration) | 5793-0, 5793-1, 5793-2 (EPA/49-State/cETL) |
| AC Rated Output Running Watts | 2000 |
| AC Maximum Output Starting Watts | 2200 |
| Rated AC Voltage | 120 VAC |
| Rated AC Frequency | 60 Hz |
| Rated 120 VAC Amperage | 16.7 |
| Max 120 VAC Amperage | 18.3 |
| Engine Displacement | 127cc |
| Engine Type | OHV |
| Engine RPM | Variable |
| Recommended Oil | 10W-30 / SAE 30 |
| Lubrication Method | Splash |
| Choke Location | On Side of Unit |
| Fuel Shut Off | On Side of Unit |
| Idle Control | FlexPower™ |
| Starting Method | Recoil Pull Start |
| Low Oil Shutdown | Low Level |
| Neutral Bonded to Ground | No |

| | |
|-------------------------------|-----------------|
| Start Switch Type | On/Off |
| Switch Location | On Side of Unit |
| Fuel Tank Capacity Gal (Ltrs) | 0.85 (3.23) |
| Run Time at 25% (Hours) | 5.3 |
| Maintenance Kit | Sold Separately |
| Warranty- Residential | 2 Year |
| Warranty- Commercial | 6 Months |

Dimensions and Weights

| | |
|--------------------------|-------------|
| Length in (mm) | 22 (559) |
| Width in (mm) | 12 (305) |
| Height in (mm) | 18 (457) |
| Carton Length in (mm) | 25 (635) |
| Carton Width in (mm) | 13.75 (350) |
| Carton Height in (mm) | 20.75 (525) |
| Unit Weight lbs (kg) | 52 (23.5) |
| Shipping Weight lbs (kg) | 63 (28.4) |

