

XG10000E

XG SERIES
Commercial/Residential
Portable Generators

A/C Rated Output Watts: 10000
A/C Maximum Output Watts: 12500

Model 5802-0

UPC Number: 696471058024
Emissions Certification: 49-State



features

- GENERAC OHVI ENGINE WITH FULL PRESSURE LUBRICATION
- ILLUMINATED CONTROL PANEL
- POWERBAR DISPLAYS AVAILABLE WATTAGE
- FULL-WRAP, HEAVY DUTY FRAME TUBING
- LOCKING, FOLDING HANDLES
- NEVER FLAT, RALLY-STYLE WHEELS
- COVERED OUTLETS FOR PROTECTION FROM THE ELEMENTS
- HOUR METER WITH MAINTENANCE RESETS
- LOW-OIL SHUTDOWN TO PREVENT ENGINE DAMAGE
- GFCI OUTLET PROTECTION

customer connections

Connection Outlets


A	4X5-20R.GFCI
B	1xL5-30R
C	1xL14-30R
D	1x14-50R

Circuit Breakers

M	(2) 20A
N	(2) 30A
O	(1) 42A

Other Features

H	Fuel Cut-Off
I	Power Bar
J	Hour Meter
K	Illuminated Control Panel
L	12VDC Battery Charger Input

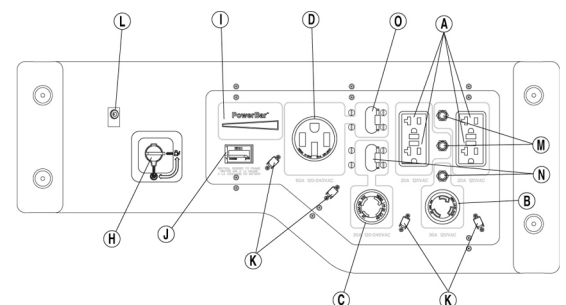

XG10000E

specifications

Product Series	XG10000E
Model	5802-0
Configuration/Emissions	49-State
A/C Rated Output Watts:	10000
A/C Maximum Output Watts:	12500
A/C Voltage	120/240
A/C Frequency	60 Hz
Rated 120/240 VAC Amperage	41.7
Max 120/240 VAC Amperage	52.1
Engine Displacement	530cc
Engine Type	OHVI
Engine RPM	3600
Recommended Oil	SAE 30
Lubrication Method	Full Pressure
Choke Type	Manual Lever
Fuel Shut Off	On Control Panel
Idle Control	Full Speed
Starting Method	Electric
Battery	Included
Battery Size	12VDC 18 Ah
Low Oil Shutdown Method	Low Pressure

Start Switch Type	3-Position
Switch Location	On Engine
Single-Point Lifting Eye	N/A
Fuel Gauge	Built-in Tank
Fuel Tank Capacity (Gal)	10.00
Fuel Tank Capacity (Ltrs)	37.85
Run Time at 50% (Hours)	10.00
Cord Set	N/A
Handle Style	Folding Interlocked
Wheel type	10" Solid Wheels
Maintenance Kit	Included
Warranty - Residential	2 Year
Warranty - Commercial	1 Year

dimensions and weights

Length (L)	32.0
Width (W)	29.5
Height (H)	31.0
Extended Length (EL)	48.5
Carton Length	34.0
Carton Width	24.5
Carton Height	33.0
Unit Weight (lbs)	300.0
Shipping Weight (lbs)	325.0

