

## GP6500E

GP SERIES  
Commercial/Residential  
Portable Generators

A/C Rated Output Watts: 6500  
A/C Maximum Output Watts: 8000

Model 5941-0

UPC Number: 696471059410  
Emissions Certification: 49-State



### features

- LONG LIFE OHV ENGINE
- LOW OIL SHUTDOWN PROTECTION
- COVERED, CIRCUIT BREAKER PROTECTED OUTLETS
- STEEL FUEL TANK WITH BUILT-IN FUEL GAUGE
- LOCKING, FOLD-DOWN HANDLE
- NEVER-FLAT WHEEL KIT
- 1.25" HARDENED STEEL TUBE FRAME
- ELECTRIC START - BATTERY INCLUDE
- HOUR METER TO TRACK MAINTENANCE
- LOW TONE MUFFLER

### customer connections

#### Connection Outlets


A	(4) 5-20R 120V
B	L14-30R Twist-Lock 120/240V

#### Circuit Breakers

M	(2) 20A
N	(2) 25A

#### Other Features

H	Hour Meter
I	Off/On/Start Switch
J	12VDC Battery Charger Input

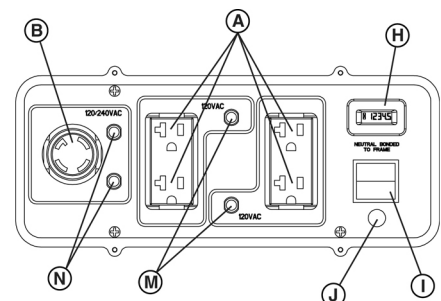

# GP6500E

## specifications

Product Series	GP6500E
Model	5941-0
Configuration/Emissions	49-State
A/C Rated Output Watts:	6500
A/C Maximum Output Watts:	8000
A/C Voltage	120/240VAC
A/C Frequency	60 Hz
Rated 120/240 VAC Amperage	27.1
Max 120/240 VAC Amperage	33.3
Engine Displacement	389cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	SAE30
Lubrication Method	Splash Sump
Choke Type	Manual Lever
Fuel Shut Off	Manual Lever
Idle Control	Full Speed
Starting Method	Electric/Manual
Battery	Included
Battery Size	12VDC 10 Ahr
Low Oil Shutdown Method	Low Level

Start Switch Type	3-Position
Switch Location	On Control Panel
Single-Point Lifting Eye	N/A
Fuel Gauge	Built-in Tank
Fuel Tank Capacity (Gal)	7.20
Fuel Tank Capacity (Ltrs)	27.25
Run Time at 50% (Hours)	10.00
Cord Set	N/A
Handle Style	Folding
Wheel type	9.5" Solid Wheels
Maintenance Kit	Sold Separately
Warranty - Residential	2 Year
Warranty - Commercial	1 Year

## dimensions and weights

Length (L)	28.8
Width (W)	26.8
Height (H)	25.0
Extended Length (EL)	45.0
Carton Length	31.0
Carton Width	21.7
Carton Height	23.5
Unit Weight (lbs)	195.0
Shipping Weight (lbs)	209.0

