



## GROUNDING ECONOMY PIPE CLAMPS



Copper wire only

### Bare Wire Type

Cast bronze high-copper alloy pipe clamp with plated steel screws  
For bonding bare copper wire to water pipe, such as a water meter shunt

NAED NUMBER	CATALOG NUMBER	WATER PIPE SIZE	GROUND WIRE MAX	FIG	CTN QTY
30140	G 1S	1/2" TO 1"	2 STR	1	50
30180	G 2S	1 1/4" TO 2"	2 STR	1	25



Figure 1

### Armored Wire Type

Cast bronze high-copper alloy pipe clamp with plated steel screws  
For bonding bare or armored copper wire  
Also use with jacketed cables or cords  
Separate two-screw clamping strap for armor

NAED NUMBER	CATALOG NUMBER	WATER PIPE SIZE	GROUND WIRE MAX	FIG	CTN QTY
30560	G 20	1/2" TO 1"	2 STR	2	50
30260	G 4S	1 1/4" TO 2"	4 STR	2	10



Figure 2

### 1/2" Conduit Type

Cast bronze high-copper alloy pipe clamp with plated steel screws  
Hub threaded for 1/2" conduit  
Connect wire under hub-screw

NAED NUMBER	CATALOG NUMBER	WATER PIPE SIZE	GROUND WIRE MAX	FIG	CTN QTY
30300	G 5S	1/2" TO 1"	6 SOL	3	25
30340	G 6S	1 1/4" TO 2"	6 SOL	3	20



Figure 3

### Brass Screw Type

Cast bronze high-copper alloy pipe clamp with brass screws  
For bonding bare copper wire to water pipe, such as a water meter shunt

NAED NUMBER	CATALOG NUMBER	WATER PIPE SIZE	GROUND WIRE MAX	FIG	CTN QTY
70610	G 1S-BS	1/2" TO 1"	2 STR	4	50
70614	G 2S-BS	1 1/4" TO 2"	2 STR	4	25

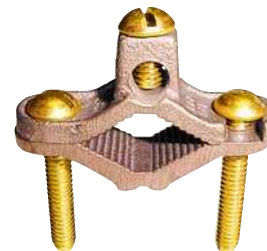


Figure 4

### Direct Burial Type

Cast bronze high-copper alloy pipe clamp with silicon bronze screws  
For bonding bare copper wire to water pipe, such as a water meter shunt  
UL listed for direct burial in earth or concrete, G 20-DB has armor clamp

NAED NUMBER	CATALOG NUMBER	WATER PIPE SIZE	GROUND WIRE MAX.	FIG	CTN QTY
70620	G 1S-DB	1/2" TO 1"	2 STR	5	50
70622	G 2S-DB	1 1/4" TO 2"	2 STR	5	25
70630	G 20-DB	1/2" TO 1"	2 STR	2	50



Figure 5

PLATING: For tin plating add suffix letter "P" to catalog numbers.