



GROUNDING

GREAVES EXCLUSIVE


Ground-Lok™ CLAMP SYSTEM SERRATED HEAD - ASSEMBLED



BRONZE WATER PIPE GROUND CLAMPS

Copper wire only

NAED NUMBER	CATALOG NUMBER	INCLUDES ADAPTER TYPE	WATER PIPE SIZE (IPS)	GROUND WIRE RANGE	CTN QTY	EST. SHIPPING	
						WEIGHT (lbs)	UNIT
30200	G 3		1/2 - 1		25	11.74	CTN
30240	G 4	WIRE	1/4 - 2	4/0 STR	20	6.56	CTN
30480	G 15	ADAPTER	2 1/2 - 4		4	5.43	CTN
30500	G 16		4 1/2 - 6		4	6.90	CTN
FOR 1/2" RIGID CONDUIT							
30280	G 5		1/2 - 1		25	12.39	CTN
30320	G 6	1/2" CONDUIT	1/4 - 2	2/0 STR	20	13.46	CTN
30520	G 18	SIZE	2 1/2 - 4		4	5.46	CTN
30540	G 19		4 1/2 - 6		4	7.10	CTN
FOR 3/4" RIGID CONDUIT							
30360	G 7		1/2 - 1		25	13.39	CTN
30380	G 8	3/4" CONDUIT	1/4 - 2	3/0 STR	20	14.26	CTN
30580	G 21	SIZE	2 1/2 - 4		4	5.62	CTN
30600	G 22		4 1/2 - 6		4	7.10	CTN
FOR 1" RIGID CONDUIT							
30400	G 9		1/2 - 1		25	14.64	CTN
30420	G 10	1" CONDUIT	1/4 - 2	3/0 STR	10	7.76	CTN
30620	G 24	SIZE	2 1/2 - 4		2	3.04	CTN
30640	G 25		4 1/2 - 6		2	3.86	CTN

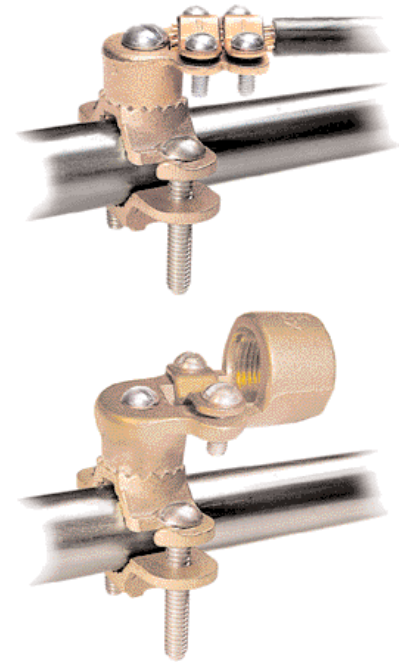

PLATING: For tin-plating add suffix letter "P" to CATALOG NUMBERS.
UL listed to #4 AWG. CSA certified as shown.

Ground-Lok™ CLAMP SYSTEM BRASS SCREWS



G1BS SERIES

NAED NUMBER	CATALOG NUMBER	INCLUDES ADAPTER TYPE	WATER PIPE SIZE (IPS)	GROUND WIRE MAX	CTN QTY	EST. SHIPPING	
						WEIGHT (lbs)	UNIT
70560	G 1 BS	-	1/2 - 1		50	12.7	CTN
70565	G 2 BS	-	1/4 - 2	#2 STR	25	10.5	CTN
70570	G 12 BS	-	2 1/2 - 4		4	4.23	CTN
70575	G 13 BS	-	4 1/2 - 6		4	6.00	CTN
70580	G 40 BS	Wire	-	4/0 STR	20	4.67	CTN
70585	G 41 BS	1/2" Conduit	-	2/0 STR	20	5.17	CTN
70590	G 42 BS	3/4" Conduit	-	3/0 STR	20	5.83	CTN
70600	G 43 BS	1" Conduit	-	3/0 STR	20	6.74	CTN
70566	G 3 BS	Wire	1/2 - 1	4/0 STR	25	12.1	CTN
70567	G 4 BS	Wire	1/4 - 2	4/0 STR	10	3.50	CTN

PLATING: For tin-plating add suffix letter "P" to CATALOG NUMBERS. UL listed to #4 AWG. CSA certified as shown.



www.greaves-usa.com

11 Heritage Park, Clinton, CT 06413 • Phone 860-664-4505 • Fax 860-664-4546
TOLL FREE 1-800-243-1130 (Outside CT)