

GROUNDING

GREAVES EXCLUSIVE

HIGH-WING™ SYSTEM

Continuous Run Capability


For Direct Burial Grounding and Bonding

Corrosion-resistant cast bronze alloy body, silicon bronze hardware
 Applications include galvanized pipe, rod, tube, fencing, rebar (#6, 3/4" and up)
 Suitable for use in harsh environments such as agricultural buildings,
 swimming pool/spa, food processing, marine, grounding grid and others
 Orient head in any direction - lock in position with serrated teeth
 Replaces exothermic welding
 Clamps are approved for direct burial in earth and concrete

G-DB SERIES

NAED NUMBER	CATALOG NUMBER	WATER PIPE SIZE	REBAR SIZE		GROUND WIRE	CTN QTY
			#	INCH		
30750	G 140-DB	1/2" - 1"	6 - 9	3/4 - 1 1/8		25
30760	G 240-DB	1 1/4" - 2"	11	1 3/8	#4/0STR-10SOL	10
30770	G 440-DB	2 1/2" - 4"	-	-		2
30780	G 640-DB	4 1/2" - 6"	-	-	2	

Not for use on epoxy coated rebar

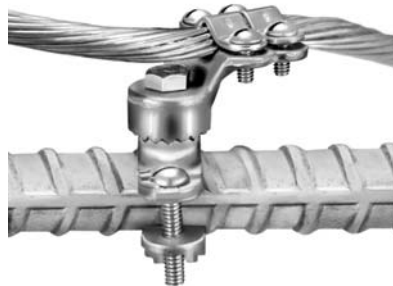

Direct Burial

Copper wire only

Wire up to #4/0 AWG
 Pipe sizes 1/2" to 6"



REBAR GROUND CLAMPS

Jones Bond™ Lay-in Rebar Clamp for Continuous Loop Grounding / Bonding
 Pool / Spa bonding and grounding
 "Ufer" Grounding (concrete encased electrodes)
 Replaces Exothermic Welding

Installs quickly, grips rebar firmly between ridges with special teeth
 Bronze body, stainless steel screw for direct burial
 CSA Certified for direct burial in earth and concrete on rebar

J-DB SERIES

NAED NUMBER	CATALOG NUMBER	WIRE RANGE	REBAR SIZE		WEIGHT LBS/CTN	CTN QTY
			#	INCH		
27101	J 29-DB	8 - 6 SOL	3	3/8	7.5	50
27110	J 30-DB	8 SOL - 4 STR	4	1/2	8.5	50
27120	* J 31-DB	6 SOL - 2/0 STR	5	5/8	5.0	25
27130	** J 32-DB	6 SOL - 4/0 STR	4,5,6	1/2,5/8,3/4	4.3	12

Not for use on epoxy coated rebar.

*UL listed for #4 STR - #2 STR

** UL pending

Direct Burial

Copper wire only



Patent Pending