

PLS V 6.5W HYB GX23 TITANIUM LED SERIES




APPLICATIONS


Retail




Hospitality

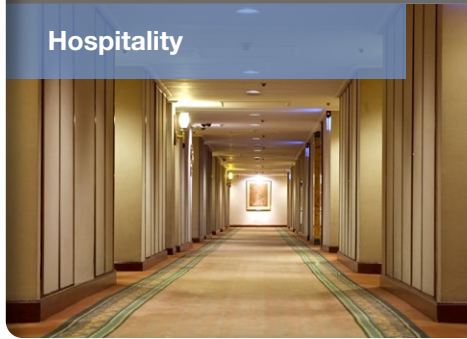

Office

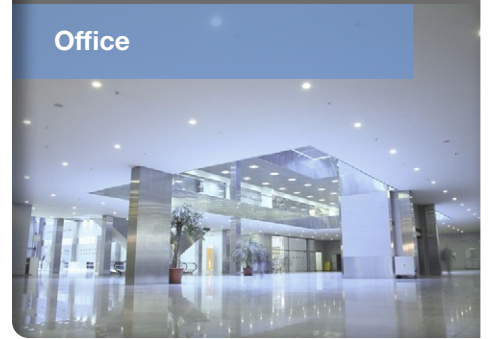

Base: GX23 (2-pin CFL)
Voltage: Magnetic ballast compatible
 120-277V
Dimmable: No
PF: 0.9
Lifetime (L70): 50,000 hrs
Weight: 0.16lb / 73g

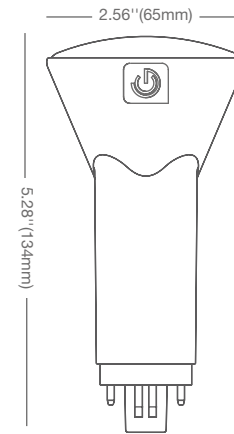

SPECIFICATIONS

Model	Product	Power (W)	CCT	CRI (typ.)	Lumens	LPW	Beam Angle
6.5PLSV/827/HYB/GX23	28378	6.5	Soft White 2700K	82	570	88	120°
6.5PLSV/830/HYB/GX23	28379	6.5	Warm White 3000K	82	600	92	120°
6.5PLSV/835/HYB/GX23	28380	6.5	Neutral White 3500K	82	600	92	120°
6.5PLSV/840/HYB/GX23	28381	6.5	Cool White 4000K	82	620	95	120°

* Suitable for damp locations. Not for use where directly exposed to weather or water
 ** Not intended for use in enclosed fixtures