


## UNIFIED GLARE RATING (UGR) <19

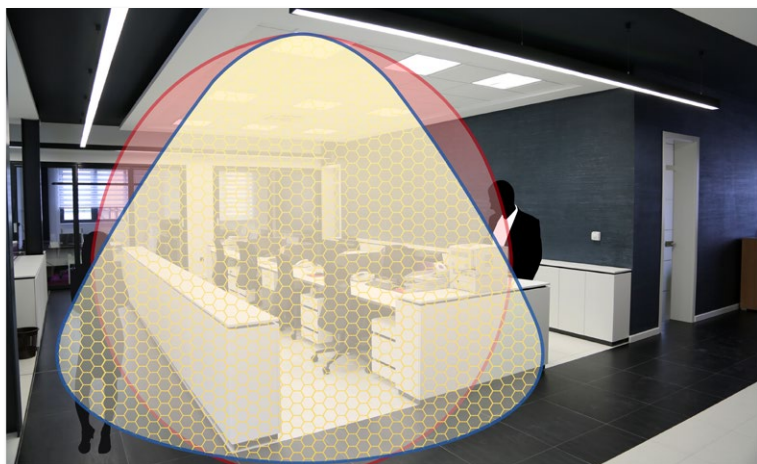

**GREEN CREATIVE Panel**  
UGR <19

- Comfortable light at all viewing angles
- More useful light
- No perceptible discomfort

**Standard LED Panel**  
UGR >23

- Harsh glare at viewing angles >65°
- More wasted light
- Perceptible discomfort

## SPECIFICATIONS

Product Model	28345 30PAN22DIM/830/277V	28346 30PAN22DIM/835/277V	28347 30PAN22DIM/840/277V
<b>Type</b>	Panel 2x2'	Panel 2x2'	Panel 2x2'
<b>Power (W)</b>	30	30	30
<b>Voltage - Frequency</b>	120-277V 50-60Hz	120-277V 50-60Hz	120-277V 50-60Hz
<b>Color Temp. (ANSI)</b>	3000K	3500K	4000K
<b>CRI (Ra)</b>	82	82	82
<b>Typical lumens (lm)</b>	3350	3350	3450
<b>Efficacy (LPW)</b>	112	112	115
<b>Beam Angle</b>	95°	95°	95°
<b>Dimmable</b>	Yes	Yes	Yes
<b>Power Factor</b>	0.9	0.9	0.9
<b>THD</b>	<20%	<20%	<20%
<b>Ambient Temp. Rating</b>	-22°F / -30°C - 104°F / 40°	-22°F / -30°C - 104°F / 40°	-22°F / -30°C - 104°F / 40°
<b>Rated Lifetime - L70 (hrs.)</b>	75,000	75,000	75,000
<b>Dimensions (LxWxH)</b>	23.62"x23.62"x1.81" (600x600x46mm)	23.62"x23.62"x1.81" (600x600x46mm)	23.62"x23.62"x1.81" (600x600x46mm)
<b>Weight (lb. / g)</b>	7.61lb. / 3.45kg	7.61lb. / 3.45kg	7.61lb. / 3.45kg

**Note: To order the EMERGENCY BACKUP add /EM to the model number Ex. 30PAN22DIM/840/277V/EM**

\* Suitable for damp locations. Not for use where directly exposed to weather or water

## ACCESSORY ORDERING INFORMATION

Model	Product	Description
MOUNTFRAME22	28390	2X2' Surface Mount Frame
SUSPCABLE22	28392	70.9" (1.8m) Aircraft Suspension Cable (Set of 4 Cables for 1 2X2' Fixture)