

# MR16 6W DIM. TITANIUM LED SERIES 4.0



Ref.#:DS029-MR16-6W

## APPLICATIONS

### Recessed Lighting




### Accent / Display Lighting



### Track Lighting



## ILLUMINANCE

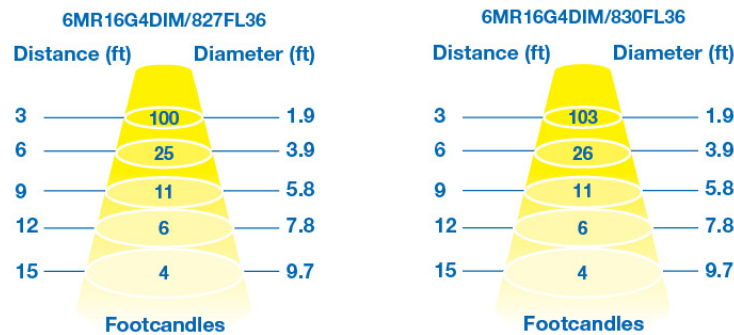

## SPECIFICATIONS

Product Model	40755 6MR16G4DIM/827FL36	40756 6MR16G4DIM/830FL36
Type	MR16	MR16
Base	Bi-pin GU5.3	Bi-pin GU5.3
Power (W)	6	6
Voltage - Frequency	12V 60Hz	12V 60Hz
Color Temp. (ANSI)	Warm White 2700K	Warm White 3000K
CRI (Ra)	80	80
Typical lumens (lm)	425	450
Efficacy (LPW)	71	75
Beam Angle	FL 36°	FL 36°
CBCP (cd)	900	925
Dimmable	Yes***	Yes***
Power Factor	0.9	0.9
Rated Lifetime - L70 (hrs.)	30,000	30,000
Dia. x MOL	1.97"x1.89"(50x48mm)	1.97"x1.89"(50x48mm)
Weight (lb. / g)	0.12lb. / 55g	0.12lb. / 55g

\* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$4 halogen with 1000-hr lifetime, \$25 LED with 30,000-hr lifetime

\*\* Suitable for use in totally enclosed fixtures

\*\*\* List of tested dimmer switches and transformers available on website

\*\*\*\* Suitable for damp locations. Not for use where directly exposed to weather or water