


5.5" SQUARE DOWNLIGHT 10W TITANIUM LED SERIES



DUAL INSTALLATION


4" J-BOX FLUSHMOUNT

For all models

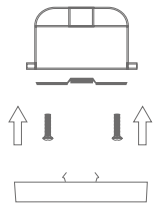

ACCESSORIES INCLUDED:

 - Attach mounting bracket to J-box
- Click downlight into mounting bracket



Mounting Bracket



J-Box Screws




Wire Nuts



LED Adapter

4" & 6" CAN RECESSED

4" CAN - 5.5" & 7" models
6" CAN - 7" model only

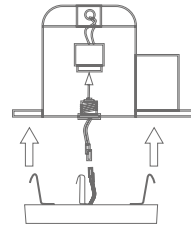

ACCESSORIES SOLD SEPARATELY:

- Connect E26 adapter to the LED adapter
- Insert mounting clips and push downlight up until flush with ceiling



E26 Adapter



Mounting Clips



Ground Screw



LED Adapter

SPECIFICATIONS

Product Model	58247 10SMPS5.5DIM/927	58248 10SMPS5.5DIM/930	58249 10SMPS5.5DIM/940
Type	5.5" SMPS	5.5" SMPS	5.5" SMPS
Base	LED Adapter (E26 & GU24 optional)	LED Adapter (E26 & GU24 optional)	LED Adapter (E26 & GU24 optional)
Power (W)	10	10	10
Voltage - Frequency	120V 60Hz	120V 60Hz	120V 60Hz
Color Temp. (ANSI)	Soft White 2700K	Warm White 3000K	Cool White 4000K
CRI (Ra)	90	90	90
Typical lumens (lm)	550	550	560
Efficacy (LPW)	55	55	56
Beam Angle	100°	100°	100°
Dimmable	Yes**	Yes**	Yes**
Housing Compatibility	4" J-box / Most 6" housing	4" J-box / Most 6" housing	4" J-box / Most 6" housing
Power Factor	0.9	0.9	0.9
Rated Lifetime - L70 (hrs.)	50,000	50,000	50,000
Dia. x MOL	5.59"x1.65" (142x42mm)	5.59"x1.65" (142x42mm)	5.59"x1.65" (142x42mm)
Weight (lb. / g)	0.62lb. / 281g	0.62lb. / 281g	0.62lb. / 281g

ACCESSORY ORDERING INFORMATION

Model	Product	Description
SMP/ACC	58033	4" or 6" Recessed Can Accessories for 5.5" & 7" Round & Square (5.5" for Use in 4" Can Only, 7" for Use in 4" or 6" Can)

* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$4 incandescent with 1000-hr lifetime, \$30 LED with 50,000-hr lifetime

** List of tested dimmer switches available on website