

6" DOWNLIGHT 11W TITANIUM CRI^{SP} LED SERIES



CRISP



11W REPLACES



65W Inc.

80% Energy Savings

\$193 Savings per lamp*

- ⌚ Innovative CLICK design
- ⌚ Fits most 4" J-boxes and 5-6" recessed housings
- ⌚ Installs in just minutes - no rewiring
- ⌚ Wet location rated
- ⌚ Exceptional color rendering CRI 90
- ⌚ Richer reds and natural skin tones (R9 60, R13 90)



40,000 H



DIMMABLE



65 LPW EFFICACY



5 YR WARRANTY



CRI (Ra) 90



WET LOCATION




DOWNLIGHT PRODUCT FEATURES

DUAL INSTALLATION:

4" J-BOX FLUSHMOUNT

ACCESSORIES INCLUDED:

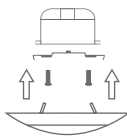

- Attach mounting bracket to J-box
- Click downlight into mounting bracket



Mounting Bracket



J-Box Screws




Wire Nuts



LED Adapter

4" CAN RECESSED

ACCESSORIES SOLD SEPARATELY:

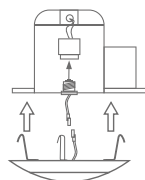


- Connect E26 adapter to the LED adapter
- Insert mounting clips and push downlight up until flush with ceiling



E26 Adapter



 LED Adapter




Mounting Bracket



Mounting Clips

5-6" CAN RECESSED

ACCESSORIES SOLD SEPARATELY:

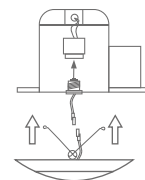

- Connect E26 adapter to the LED adapter
- Squeeze mounting springs and push downlight up until flush with ceiling



E26 Adapter



LED Adapter



Mounting Springs

6" DOWNLIGHT 11W TITANIUM CRI^{SP} LED SERIES



APPLICATIONS

General Lighting



Recessed Lighting



Accent Lighting



SPECIFICATIONS

Product Model	58101 11SMDL6DIM/927	58102 11SMDL6DIM/930	58103 11SMDL6DIM/940
Type	6" SMDL	6" SMDL	6" SMDL
Base	E26 / LED Adapter (GU24 optional)	E26 / LED Adapter (GU24 optional)	E26 / LED Adapter (GU24 optional)
Power (W)	11	11	11
Voltage - Frequency	120V 60Hz	120V 60Hz	120V 60Hz
Color Temp. (ANSI)	Soft White 2700K	Warm White 3000K	Cool White 4000K
CRI (Ra)	90	90	90
Typical lumens (lm)	680	720	750
Efficacy (LPW)	62	65	68
Beam Angle	110°	110°	110°
Dimmable	Yes**	Yes**	Yes**
Housing Compatibility	4" J-box / Most 5-6" housing	4" J-box / Most 5-6" housing	4" J-box / Most 5-6" housing
Power Factor	0.9	0.9	0.9
Rated Lifetime - L70 (hrs.)	40,000	40,000	40,000
Dia. x MOL	7.32"x1.30" (186x33mm)	7.32"x1.30" (186x33mm)	7.32"x1.30" (186x33mm)
Weight (lb. / g)	0.45lb. / 204g	0.45lb. / 204g	0.45lb. / 204g

ACCESSORIES (SOLD SEPARATELY)

Product Model	57973 SMDL4/ACC	57974 SMDL6/ACC
Type	4" Can Installation Accessories	5-6" Can Installation Accessories

* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$4 incandescent with 1000-hr lifetime, \$25 LED with 40,000-hr lifetime

** List of tested dimmer switches available on website