



## ILLUMINANCE & CANDELA DISTRIBUTION


6MR16DIM/827FL35/35W

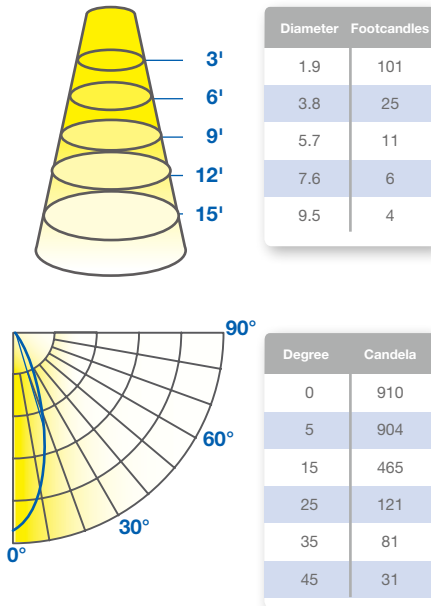

6MR16DIM/830FL35/35W

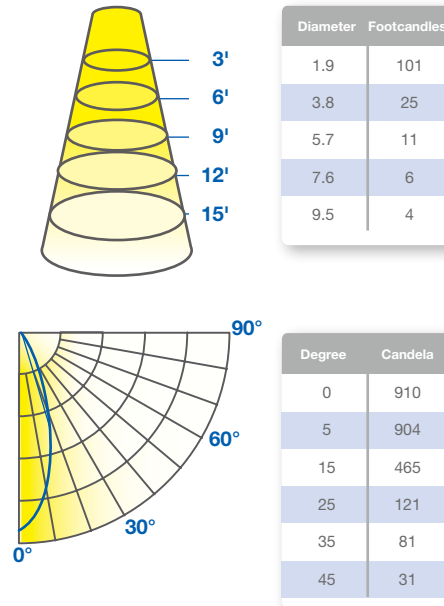

- Base:** GU5.3
- Voltage:** 12V
- Dimmable:** Yes\*\*\*
- PF:** 0.9
- Lifetime:** 25,000 hrs
- Weight:** 0.09lb. / 41g

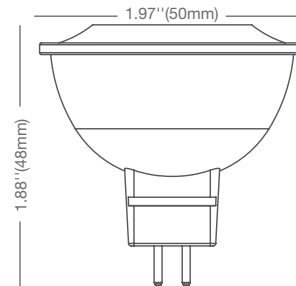

## SPECIFICATIONS

Model	Product	Power (W)	CCT	CRI (typ.)	Lumens	LPW	Beam Angle	CBCP (cd)
6MR16DIM/827FL35/35W	58285	6	Soft White 2700K	82	425	71	FL 35°	910
6MR16DIM/830FL35/35W	58286	6	Warm White 3000K	82	450	75	FL 35°	910

\* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$4 halogen with 1000-hr lifetime, \$20 LED with 25,000-hr lifetime

\*\* Suitable for use in totally enclosed fixtures

\*\*\* List of tested dimmer switches available on website