



APPLICATIONS


Retail

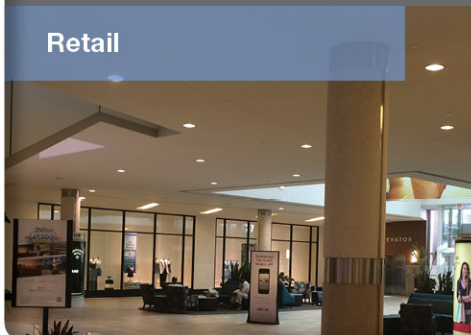

Hospitality

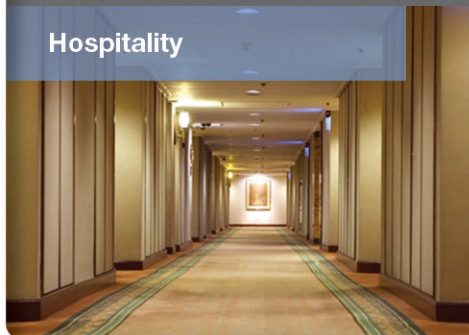

Office

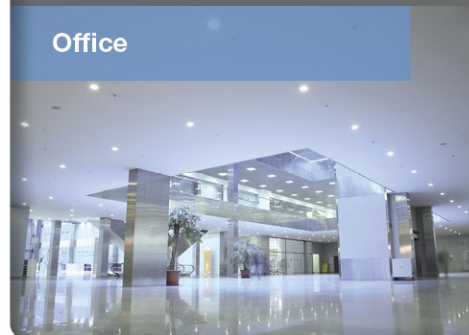

Ref.#:DS076-CDL-22W

SPECIFICATIONS*

Product Model	97685 22CDL6G4DIM/827/277V (MTO)	97686 22CDL6G4DIM/830/277V	97687 22CDL6G4DIM/835/277V	97688 22CDL6G4DIM/840/277V
Type	6" Commercial Downlight	6" Commercial Downlight	6" Commercial Downlight	6" Commercial Downlight
Power (W)	22	22	22	22
Voltage - Frequency	120-277V 50-60Hz	120-277V 50-60Hz	120-277V 50-60Hz	120-277V 50-60Hz
Color Temp. (ANSI)	Warm White 2700K	Warm White 3000K	Neutral White 3500K	Natural White 4000K
CRI (Ra) (typ.)	80	80	80	80
Typical lumens (lm)	1350	1400	1450	1500
Efficacy (LPW)	61	64	66	68
Beam Angle	90°	90°	90°	90°
Dimmable	Yes	Yes	Yes	Yes
Power Factor	0.9	0.9	0.9	0.9
Rated Lifetime - L70 (hrs.)	40,000	40,000	40,000	40,000
Dia. x MOL	6.02"x5.39" (153x137mm)	6.02"x5.39" (153x137mm)	6.02"x5.39" (153x137mm)	6.02"x5.39" (153x137mm)
Trim Weight (lb. / g)	0.78lb / 354g	0.78lb / 354g	0.78lb / 354g	0.78lb / 354g
Driver Weight (lb. / g)	1.74lb / 793g	1.74lb / 793g	1.74lb / 793g	1.74lb / 793g

* Specification data is preliminary and may be subject to change
 ** Suitable for damp locations. Not for use where directly exposed to weather or water
 *** Not intended for use in enclosed fixtures
 **** Full installation guide and more details available on website