


5" OR 6" DOWNLIGHT 12W TITANIUM CRI^{SP} LED SERIES

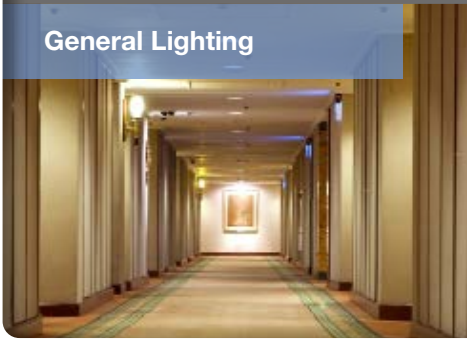


APPLICATIONS

General Lighting



Recessed Lighting

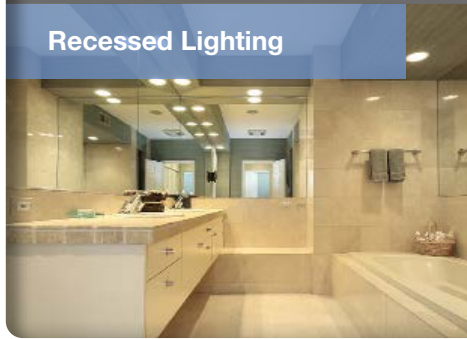

Accent Lighting



Ref.#DS094-6DL-12W

SPECIFICATIONS**

Product Model	97765 12DL6DIM/927	97766 12DL6DIM/930
Type	5" or 6" Downlight	5" or 6" Downlight
Base	E26 / LED Adapter (GU24 optional)	E26 / LED Adapter (GU24 optional)
Power (W)	12	12
Voltage - Frequency	120V 60Hz	120V 60Hz
Color Temp. (ANSI)	Soft White 2700K	Warm White 3000K
CRI (Ra)	90	90
R9 / R13 (typ.)	60 / 90	60 / 90
Typical lumens (lm)	720	750
Efficacy (LPW)	60	63
Beam Angle	100°	100°
Dimmable	Yes***	Yes***
Housing Compatibility	Most 5" and 6" housing	Most 5" and 6" housing
Power Factor	0.9	0.9
Rated Lifetime - L70 (hrs.)	35,000	35,000
Dia. x MOL	7.48"x3.74" (190x95mm)	7.48"x3.74" (190x95mm)
Weight (lb. / g)	0.71lb. / 322g	0.71lb. / 322g

* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$4 incandescent with 1000-hr lifetime, \$28 LED with 35,000-hr lifetime
 ** Specification data is preliminary and may be subject to change

*** List of tested dimmer switches available on website
 **** Suitable for damp locations. Not for use where directly exposed to weather or water