


## APPLICATIONS


### Chandelier

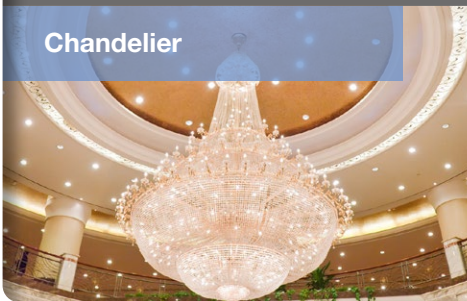

### Sconce



### Uplighting

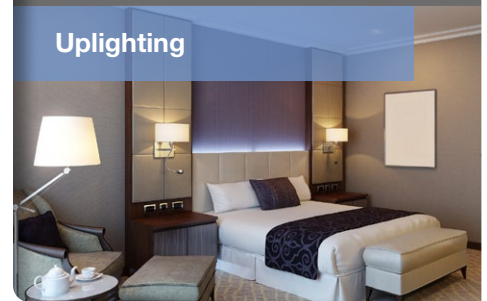

Ref.# DS100-B11-4.5W-300317

## SPECIFICATIONS

Product Model	97817 4.5B11DIM/827/R	97818 4.5B11DIM/827/E26
Type	B11 (candle)	B11 (candle)
Base	E12	E26
Power (W)	4.5	4.5
Voltage - Frequency	120V 60Hz	120V 60Hz
Color Temp. (ANSI)	Warm White 2700K	Warm White 2700K
CRI (Ra)	80	80
Typical lumens (lm)	300	300
Efficacy (LPW)	64	64
Beam Angle	230°	230°
Dimmable	Yes**	Yes**
Power Factor	0.9	0.9
Rated Lifetime - L70 (hrs.)	25,000	25,000
Dia. x MOL	1.50"x4.13" (38x105mm)	1.50"x3.94" (38x100mm)
Weight (lb. / g)	0.11lb / 49g	0.12lb / 54g

\* Savings per lamp based on \$0.11 / kw energy cost, 12 hrs / day lamp usage, \$2 incandescent with 1000-hr lifetime, \$16 LED with 25,000-hr lifetime

\*\* List of tested dimmer switches available on website

\*\*\* Not intended for use in totally enclosed fixtures

\*\*\*\* Suitable for damp locations. Not for use where directly exposed to weather or water