 


## FISHING

### Kwik Silver® Steel Fish Tapes - 1/8" Wide



438-10



- Kwik Silver® plated fish tape wire is corrosion resistant.
- Same strength as conventional steel tape.
- Smooth plating makes it easier to fish with, saving you time on the job.
- High-impact nylon, one-piece handle for maximum durability, long life, and easy, comfortable use.
- Large handle grip for greater user control.
- Self-tensioning case for easy tape winding.
- Wide, impact-resistant rewinder case with viewports to ensure tape fit and retaining strap on inside to hold tape secure.

CAT. NO.	UPC NO.	DESCRIPTION
438-5	29045	65' × 1/8" × 0.060" (19.8 m × 3.2 mm × 1.5 mm) Steel Fish Tape in 8 1/2" Winder Case
438-5BP	00170	65' × 1/8" × 0.060" (19.8 m × 3.2 mm × 1.5 mm) Steel Fish Tape in 8 1/2" Winder Case, 5-pack
438-10	28256	125' × 1/8" × 0.060" (33 m × 3.2 mm × 1.5 mm) Steel Fish Tape in 12" Winder Case
438-10BP	00171	125' × 1/8" × 0.060" (33 m × 3.2 mm × 1.5 mm) Steel Fish Tape in 12" Winder Case, 5-pack
438-20	29046	240' × 1/8" × 0.060" (73 m × 3.2 mm × 1.5 mm) Steel Fish Tape in 12" Winder Case
438-20BP	00172	240' × 1/8" × 0.060" (73 m × 3.2 mm × 1.5 mm) Steel Fish Tape in 12" Winder Case, 5-pack
R438-5	29047	50' × 1/8" × 0.060" (15.2 m × 3.2 mm × 1.5 mm) Steel Fish Tape without Winder Case
R438-10	28257	100' × 1/8" × 0.060" (30.5 m × 3.2 mm × 1.5 mm) Steel Fish Tape without Winder Case
R438-20	29048	200' × 1/8" × 0.060" (61 m × 3.2 mm × 1.5 mm) Steel Fish Tape without Winder Case
R438B	29367	<b>A</b> Swivel Ball Head for use on 1/8" steel fish tapes
R438-BM	05853	<b>A</b> Ball Tip Male Half
439-1	30859	<b>A</b> 12" (305 mm) Flexible Fish Tape Leader
11081	11081	<b>R</b> 8 1/2" Case / Handle Kit
11082	11082	<b>R</b> 12" Case / Handle Kit

#### SPECIFICATIONS

<b>Capacity</b>	1/8" (3.2 mm) tape width- 400 lbs. (1.7 kN) maximum design strength	
<b>Weight</b>	438-5 - 2.75 lbs. (1.2 kg)	R438-5 - 2 lbs. (0.9 kg)
	438-10 - 5 lbs. (2.3 kg)	R438-10 - 3lbs. (1.4 kg)
	438-20 - 7lbs. (3.2 kg)	R438-20 - 6 lbs. (2.7 kg)



International Tel: +1.815.397.7070  
Fax: +1.815.397.9247

USA Tel: 800.435.0786  
Canada Tel: 800.435.0786  
Fax: 800.524.2853

## Steel Fish Tapes



- High-impact nylon, one-piece handle for maximum durability, long life, and easy, comfortable use.
- Large handle grip for greater user control.
- Self-tensioning case for easy tape winding.
- Wide, impact-resistant rewinder case with viewports to ensure tape fit and retaining strap on inside to hold tape secure.
- Dirt-free tape finish keeps hands cleaner during use.

### SPECIFICATIONS

**Capacity** 1/4" (6.4 mm) tape width – 400 lbs. (1.7 kN) maximum design strength.  
438-5H - 1/8" (3.2 mm) tape width- 400lbs. (1.7 kN) maximum design strength.

### Weight

- 438-5H – 2.75 lbs. (1.3 kg)
- R538-10 – 6 lbs. (2.7 kg)
- R538-20 – 11 lbs. (5 kg)
- 538-10 – 8 lbs. (3.6 kg)

CAT. NO.	UPC NO.	DESCRIPTION
438-5H	07500	50' × 1/8" × 0.045" (15.2 m × 3.2 mm × 1.1 mm) Steel Fish Tape in Winder Case
538-10	30394	100' × 1/4" × 0.060" (30.5 m × 6.4 mm × 1.5 mm) Steel Fish Tape in 12" Winder Case
R538-10	30395	100' × 1/4" × 0.060" (30.5 m × 6.4 mm × 1.5 mm) Steel Fish Tape without Winder Case
R538-20	30396	200' × 1/4" × 0.060" (61 m × 6.4 mm × 1.5 mm) Steel Fish Tape without Winder Case
R438B	29367	Swivel Ball Head for use on 1/8" steel fish tapes
R438-BM	05853	Ball Tip Male Half
439-1	30859 <b>R</b>	12" (305 mm) Flexible Fish Tape Leader
39790	39790	One-Piece Handle
39791	39791 <b>R</b>	12" (305 mm) diameter Replacement Case
11082	11082 <b>R</b>	12" Case / Handle Kit

## Silver Streak® Stainless Steel Fish Tapes - 1/8" Wide



- SILVER STREAK® comes with either 100' (30.5 m) or 200' (61 m) of stainless steel fish tape. It's rust and corrosion-resistant, so it lasts longer and rewinds easier than ordinary tape. It won't leave a nasty residue, either.
- Equipped with SPEED FLEX™ leader silver-soldered onto the fish tape. Streamlined fish tape/leader connection and lightweight, flexible leader design combine to enable user to fish farther, faster.
- High-impact nylon, one-piece handle for maximum durability, long life, and easy, comfortable use.
- Large handle grip for greater user control.
- Self-tensioning case for easy tape winding. (No tension trigger)

### SPECIFICATIONS

**Capacity** 1/8" (3.2 mm) tape width-400 lbs. (1.7 kN) maximum design strength

**Weight** 438-10SS - 5 lbs. (2.3 kg);  
438-20SS - 7 lbs. (3.2 kg)

CAT. NO.	UPC NO.	DESCRIPTION
438-10SS	06408	100' × 1/8" × 0.060" (30.5 m × 3.2 mm × 1.5 mm) Stainless Steel Fish Tape in 12" Winder Case
438-20SS	06410	200' × 1/8" × 0.060" (61 m × 3.2 mm × 1.5 mm) Stainless Steel Fish Tape in 12" Winder Case
R438-10SS	06786	100' × 1/8" × 0.060" (30.5 m × 3.2 mm × 1.5 mm) Stainless Steel Fish Tape without Winder Case
R438-20SS	06787	200' × 1/8" × 0.060" (61 m × 3.2 mm × 1.5 mm) Stainless Steel Fish Tape without Winder Case
439-2	14392 <b>R</b>	12" (305 mm) SPEED FLEX Leader (solder joints)
11082	11082 <b>R</b>	12" Case / Handle Kit

\* No leader on replacement tape

## Flat-Steel Fish Tape- 1/4" Wide



- Flat steel tape reaches easily above ceilings, under carpets, and through walls to install wire.
- 25' (7.6 m) long, extending your reach.
- Winder case with crank handle for easy, compact storage.

CAT. NO.	UPC NO.	DESCRIPTION
438-2X	01696	25' x 1/4" x 0.030" (7.6 m x 6.4 mm x 0.8 mm) Steel Fish Tape

### SPECIFICATIONS


**Weight** 1.25 lb (0.6 kg)

**R** = REPLACEMENT PART **A** = ACCESSORY


## Fiberglass Fish Tapes



540-50,  
540-100  
(12" Case)

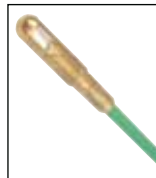

542-100

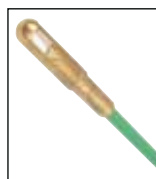

- 12" (305 mm) case has high-impact nylon, one-piece handle for maximum durability, long life, and easy, comfortable use.
- Non-conductive fiberglass tape with low friction coating.
- Has unique non-coiling properties that enable it to fish in large and small conduit equally well, even with wire or cable in place.
- Exclusive, unique, lightweight reel for easy positive feed out and rewind.
- Excellent for installation of telecommunications and data communication cables in overhead plenums, above suspended ceilings and under floors.
- Fiberglass fish tape is the fastest manual fish tape available. It is intended for fishing only. Rope or line is recommended for pulling.

CAT. NO.	UPC NO.	DESCRIPTION
540-50	35742	50' × 0.175" (15.2 m × 4.4 mm) Fiberglass Fish Tape in 12" Winder Case
540-100	35743	100' × 0.175" (30.5 m × 4.4 mm) Fiberglass Fish Tape in 12" Winder Case
542-150	35745	150' × 3/16" (45.7 m × 4.8 mm) Fiberglass Fish Tape in Reel Stand
542-200	35746	200' × 3/16" (61 m × 4.8 mm) Fiberglass Fish Tapes in Reel Stand
542-250	35747	250' × 3/16" (76.2 m × 4.8 mm) Fiberglass Fish Tape in Reel Stand
R540-100	35744	100' × .175" (30.5 m × 4.4 mm) Fiberglass Fish Tape without Case
05156	05156	150' × 3/16" (45.7 m × 4.8 mm) Fiberglass Fish Tape without Case
05157	05157	200' × 3/16" (61 m × 4.8 mm) Fiberglass Fish Tape without Case
05158	05158	250' × 3/16" (76.2 m × 4.8 mm) Fiberglass Fish Tape without Case
10565	10565	<b>R</b> .175" (4.4 mm) pulling eye repair kit, includes (1) pulling eye and adhesive
35750	35750	<b>A</b> Accessory Kit for 3/16" (4.78 mm) fish tapes. Includes flexible pulling leader, flexible pushing leader, pulling eye, splice ferrule and threaded ferrule
35908	35908	<b>R</b> 1/8" (3 mm) Repair Kit - includes threaded end ferrule, splice ferrule and pulling eye
35909	35909	<b>R</b> 3/16" (4.7 mm) Repair Kit
35919	35919	<b>R</b> 1/8" (3 mm) Pulling Eye
35930	35930	<b>R</b> 3/16" (4.7 mm) Pulling Eye
11082	11082	<b>R</b> 12" Case / Handle Kit

### SPECIFICATIONS

<b>Capacity</b>	540 Series- 0.175" (4.4 mm) dia. - 300 lbs. (1.3 kN) maximum design strength 542 Series-3/16" (4.7 mm) dia. - 400 lbs. (1.7 kN) maximum design strength
<b>Weight</b>	540-50 - 1.8 lbs. (0.8 kg) 540-100- 2.1 lbs. (1 kg) R540-100 -1.2 lbs. (0.6 kg) 542-150 -15 lbs. (6.8 kg) 542-200- 16 lbs. (7.2 kg) 542-250- 17 lbs. (7.7 kg)

International Tel: +1.815.397.7070  
Fax: +1.815.397.9247

Canada Tel: 800.435.0786  
Fax: 800.524.2853

USA Tel: 800.435.0786  
Fax: 800.451.2632

## Nylon Fish Tapes

436-5  
(12" Case)



- Co-extruded curl-resistant nylon fish tape fishes equally well in large and small conduit.
- High-impact nylon, one-piece handle for maximum durability, long life, and easy, comfortable use.
- Heavy-duty winder case.
- Nylon fish tape is intended for fishing only. Rope or line is recommended for pulling.

CAT. NO.	UPC NO.	DESCRIPTION
436-5	27396	50' x 3/16" (15.2 m x 4.8 mm) diameter Nylon Fish Tape in 12" Winder Case
436-10	27397	100' x 3/16" (30.5 m x 4.8 mm) diameter Nylon Fish Tape in 12" Winder Case
R436-5	36850	50' x 3/16" (15.2 m x 4.8 mm) diameter Nylon Fish Tape without Winder Case
R436-10	36849	100' x 3/16" (30.5 m x 4.8 mm) diameter Nylon Fish Tape without Winder Case
01664	01664	<b>R</b> Tip (Requires Greenlee K05 or K09 series crimper or #6 hex crimp to install.)
11082	11082	<b>R</b> 12" Case / Handle Kit

### SPECIFICATIONS

<b>Capacity</b>	3/16" (4.8 mm) diameter – 250 lbs. (1.1 kN) maximum design strength	
<b>Weight</b>	436-5 – 2 lbs. (0.9 kg)	R436-5 – 1 lb. (0.5 kg)
	436-10 – 3 lbs. (1.4 kg)	R436-10 – 2 lbs. (0.9 kg)

## Flex-O-Twist® Flexible Steel Fish Tapes

539-50,  
539-100  
(12" Case)



- Made of wound, multi-strand 3/16" (4.8 mm) diameter steel cable for strength and flexibility.
- Flexible... slips through lateral and vertical bends in the same run.
- High-impact, one-piece nylon handle for maximum durability, long life, and easy, comfortable use.
- Heavy-duty winder case.

CAT. NO.	UPC NO.	DESCRIPTION
539-50	30162	50' x 3/16" (15.2 m x 4.8 mm) diameter Flexible Steel Fish Tape in 12" Winder Case
539-100	34002	100' x 3/16" (30.5 m x 4.8 mm) diameter Flexible Steel Fish Tape in 12" Winder Case
439-100	29518	100' x 3/16" (30.5 m x 4.8 mm) diameter Flexible Steel Fish Tape without Winder Case
11082	11082	<b>R</b> 12" Case / Handle Kit

### SPECIFICATIONS

<b>Capacity</b>	3/16" (4.8 mm) tape width – 500 lbs. (2.2 kN) maximum design strength.	
<b>Weight</b>	539-50 – 6 lbs. (2.7 kg)	439-100 – 9 lbs. (4.1 kg)
	539-100 – 10 lbs. (4.5 kg)	34024 – 6 lbs. (2.7 kg)

## SpeedFlex® Flexible Fish Tape Leader




- Silver-solder joint attaches to any 1/8" (3.2 mm) x .060" (1.5 mm) steel fish tape to provide a slim profile that fishes farther, faster.
- High-strength stainless steel cable is used for reliability and long life.
- Beveled edges on the leader reduce the possibility of hangups when pulling wire.
- Up to (6) #10 wires can be attached to the large pulling eye.

CAT. NO.	UPC NO.	DESCRIPTION
439-2	14392	12" (305 mm) SPEED FLEX Leader (solder joint)

SPECIFICATIONS	
Weight	1.3 lbs. (0.6 kg)

## Flex-O-Twist® Flexible Fish Tape Leader

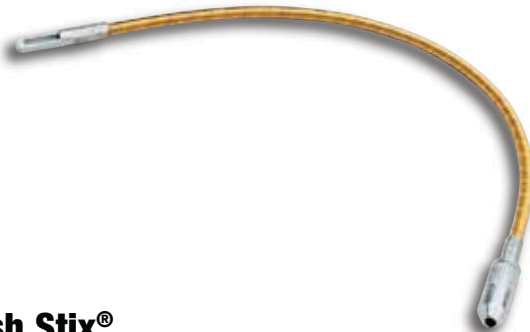

- Helps guide 1/8" steel tapes through sharp bends.
- Thread on the end of the fish tape in place of the swivel ball head.

CAT. NO.	UPC NO.	DESCRIPTION
439-1	30859	12" (305 mm) Flexible Fish Tape Leader

SPECIFICATIONS	
Weight	1.3 lbs. (0.6 kg)

## Fish Stix®



- Highly visible green color rods can be easily threaded together and seen when working above ceilings, down walls, or under raised floors.
- 1/4" (6.4 mm) diameter fiberglass adds rigidity when connecting multiple sections.
- 200 lbs. (0.9 kN) maximum pulling strength.
- Two different threaded tips accommodate various bundles of wire or cable.
- 540-24 includes one 3' (0.9 m) Glo Stix™ section for improved tip visibility.
- Optional Whisk Nose Tip is available for fishing over obstacles, and can be used to guide extended Glo Stix sideways above ceilings by rotating. Can also be used to fish longer lengths by providing a tip that can be snagged from the opposite direction with another extended Fish or Glo Stix with a hook nose tip.

CAT. NO.	UPC NO.	DESCRIPTION
540-12	10504	Fish Stix 12' (3.6 m) kit with bullet nose and "J" hook threaded tips, packaged in clear plastic tube
540-24	10506	Fish Stix 24' (7.3 m) kit with bullet nose and "J" hook threaded tips, packaged in clear plastic tube
11426	11426	<b>A</b> Whisk Nose Tip
10497	10497	<b>R</b> Hook Nose Tip
10498	10498	<b>R</b> Bullet Nose Tip
11583	11583	<b>R</b> 4' Fish Stix Section
11584	11584	<b>R</b> 6' Fish Stix Section
11585	11585	<b>R</b> 3' Glo Stix section

SPECIFICATIONS		
	540-12	540-24
Length	12' (3.6 m) - (3) 4' (1.2 m) Fish Stix sections	24' (7.3 m) - (3) 6' (1.8 m) Fish Stix sections, (1) 3' (0.9 m) Fish Stix section, and (1) 3' Glo Stix section
Weight	1.04 lbs. (0.5 kg)	1.94 lbs. (0.9 kg)
Material	1/4" (6.4 mm) dia. fiberglass rod	1/4" (6.4 mm) dia. fiberglass rod
Minimum Bend Radius	6 1/2" (165 mm)	6 1/2" (165 mm)

International Tel: +1.815.397.7070  
Fax: +1.815.397.9247

Canada Tel: 800.435.0786  
Fax: 800.524.2853

USA Tel: 800.435.0786  
Fax: 800.451.2632