

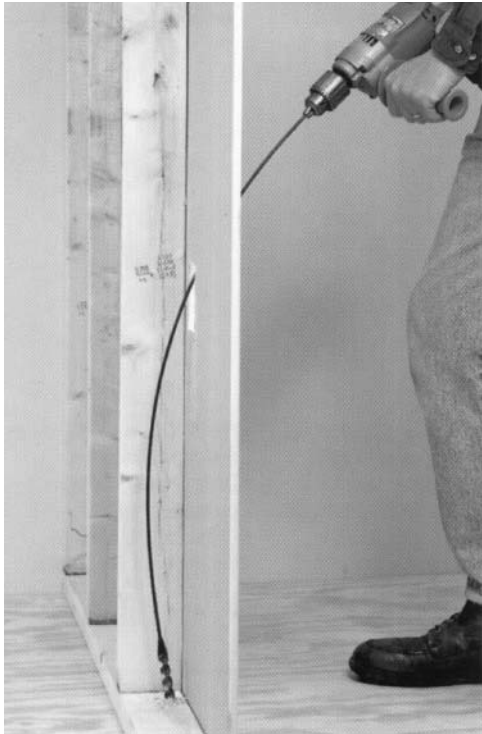


Long (up to 72") Shaft, Flexible Drill Bit System  
 for Wire and Cable Installers

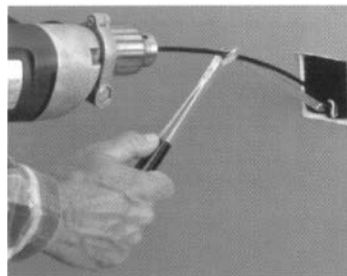

The D'VersiBIT System allows installers to easily install wiring and cable without expensive and time consuming wall damage and repairs. The system features flexible spring steel shaft with high quality drill bits up to 72" long (144' long with extension shaft).

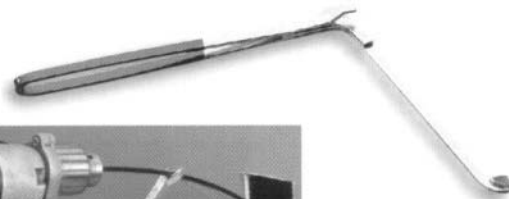

PLACEMENT  
 TOOL



The system has five different type drill bits with two length options - 36" (914mm) and 72" (1828mm). Bit types are M (masonry), HS (high speed steel), A (auger), B (screw point), and C (combination). In addition to the bits, there is a placement tool for aligning the bit inside the wall and to guide it. There are also wire and cable pulling grips that attach to a hole in the bit to pull the wire.

## Ordering Information

| Bit Diameter    | Shaft Length  | Shaft Diameter | Type M<br>Masonry | Type HS<br>High Speed<br>Steel | Type A<br>Auger | Type B<br>Screw Point | Type C<br>Combination |
|-----------------|---------------|----------------|-------------------|--------------------------------|-----------------|-----------------------|-----------------------|
| 3/8" (9.5 mm)   | 36" (914 mm)  | 3/16" (4.8 mm) |                   | 3836D                          | 06-03-36A       | 06-03-36B             | 06-03-36C             |
|                 | 54" (1371 mm) | 3/16" (4.8 mm) | 06-03-54M         |                                |                 |                       |                       |
|                 | 72" (1828 mm) | 3/16" (4.8 mm) |                   | 3872D                          | 06-03-72A       | 06-03-72B             | 06-03-72C             |
| 1/2" (12.7 mm)  | 36" (914 mm)  | 3/16" (4.8 mm) |                   | 1236D                          | 08-03-36A       | 08-03-36B             | 08-06-32C             |
|                 | 72" (1828 mm) | 3/16" (4.8 mm) |                   | 1272D                          | 08-03-72A       | 08-03-72B             | 08-03-72C             |
| 9/16" (14.3 mm) | 36" (914 mm)  | 3/16" (4.8 mm) |                   |                                | 09-03-36A       | 09-03-36B             | 09-03-36C             |
|                 | 72" (1828 mm) | 3/16" (4.8 mm) |                   |                                | 09-03-72A       | 09-03-72B             | 09-03-72C             |

| Extension Bits |               |                |       |
|----------------|---------------|----------------|-------|
|                | Length        | Shaft Diameter | Model |
|                | 36" (914 mm)  | 3/16" (4.8 mm) | 3XT36 |
|                | 72" (1828 mm) | 3/16" (4.8 mm) | 3XT72 |

| Wire and Cable Pulling Grips |               |       |
|------------------------------|---------------|-------|
|                              | Cable Size    | Model |
|                              | 3/8" to 1/2"  | 125   |
|                              | 1/2" to 9/16" | 150   |

| Abrasion Shield   |               |       |
|---|---------------|-------|
| To protect from abrasion and insulation wrapping around bit shaft |               |       |
|   | Size          | Model |
|   | 48" (1219 mm) | 606AS |