


INCANDESCENT LAMPS

Decorative

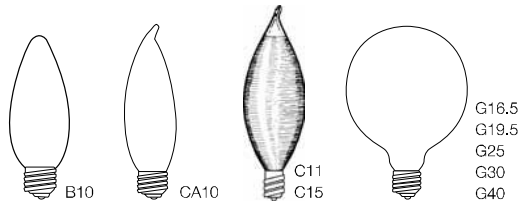

Bulb	Base	Product Number	Footnotes	Product Code	Description	Pkg. Qty.	Volts	Lumens	Avg. Life	Design Filament	MOL	Beam Spread
60 WATT												
B10	Cand.	1009	2	CTC60	Clear 32mm	25/500	130	650	3000	CC-2V	3.87"	-
		101284	X,N,2	CTC60/ND	Clear Neodymium PureLite®	10/50	120	500	5000	CC-2V	3.87"	-
		1010	2	CTF60	Frost 32mm	25/500	130	640	3000	CC-2V	3.87"	-
	E14	121027	X	CTC60/E14	Clear 32mm	25/500	120	650	3000	CC-2V	3.87"	-
	Med.	1018	2	ETC60	Clear 32mm	25/500	130	650	3000	CC-2V	3.87"	-
		102146	2	ETC60/CS	Clear CoverShield®	25/500	130	-	3000	CC-2V	3.87"	-
1019		2	ETF60	Frost 32mm	25/500	130	640	3000	CC-2V	3.87"	-	
CA10	Cand.	2009	2	CFC60	Clear 32mm	25/500	130	650	3000	CC-2V	4.12"	-
		2010	2	CFF60	Frost 32mm	25/500	130	640	3000	CC-2V	4.12"	-
	Med.	2018	2	EFC60	Clear 32mm	25/500	130	650	3000	CC-2V	4.12"	-
		2019	2	EFF60	Frost 32mm	25/500	130	640	3000	CC-2V	4.12"	-
C11	Cand.	100213	2	C11SG60	Clear Spun Glow	25/500	130	-	1500	CC-2V	4.02"	-
		100228	X	C11SG60/AMB	Amber Spun Glow	25/500	130	-	2000	CC-2V	4.02"	-
C15	Med.	100218	2	C15SG60	Clear Spun Glow	25/500	130	-	1500	CC-2V	4.49"	-
		100226	X	C15SG60/AMB	Amber Spun Glow	25/500	130	-	2000	C-9	4.49"	-
G16.5	Cand.	4004	2	G16CL60	Clear	25/500	130	650	3000	CC-2V	3.00"	-
		4018	2	G16WH60	White	25/500	130	560	3000	CC-2V	3.00"	-
G19.5	Med.	104506	2	G19WH60	White	25/500	130	550	1500	C-9	3.50"	-
G25	Med.	5005		G25CL60	Clear	10/100	130	550	3500	C-9	4.50"	-
		102382		G25CL60/SB	Clear Silver Bowl	10/100	130	-	3500	C-9	4.50"	-
		5006		G25WH60	White	10/100	130	480	3500	C-9	4.50"	-
G30	Med.	5506		G30WH60	White	10/100	130	480	5000	C-9	5.00"	-
G40	Med.	5205		G40CL60	Clear	6/24	130	520	5000	C-9	6.93"	-
		5204		G40WH60	White	6/24	130	450	5000	C-9	6.93"	-
100 WATT												
G25	Med.	5007		G25CL100	Clear	10/100	130	1100	3500	C-9	4.50"	-
G40	Med.	5207		G40CL100	Clear	6/24	130	1100	5000	C-9	6.93"	-
		5206		G40WH100	White	6/24	130	950	5000	C-9	6.93"	-

Ⓔ Means this lamp meets Federal Minimum Efficiency standards.
Incandescent lamps symbols, footnotes and abbreviations are located on pages 151-153.