


Incandescent

General Service

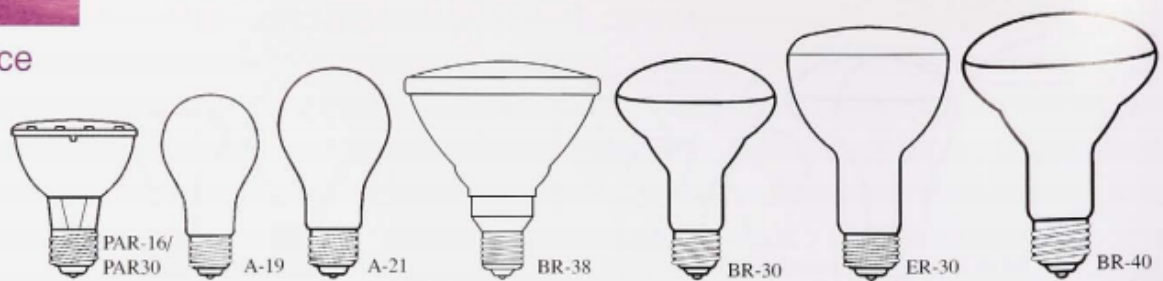

Bulb	Base	Product Number	Product Code	Description	Inner/ Master	Volts	Lumens	Avg. Life	Design Filament	MOL	Beam Spread
75 WATT											
A19	Med.	6226	A19CL75/1	Clear Halco®	120	120	860	1500	CC-6	4¼	-
		6326	A19CL75/5	Clear Halco®	120	130	700	5000	C-9	4¼	-
		103512	A19CL75/P5	Clear Prism® Long Life	120	130	680	5000	C-9M	4¼	-
		841030	A19FR75	Frost Major	48	120	1190	750	CC-6	4 ⁷ / ₁₆	-
		6222	A19SW75/1	Soft White Halco®	120	120	780	1500	CC-6	4¼	-
		6322	A19FR75/5	Frost Halco®	120	130	700	5000	C-9	4¼	-
		103562	A19FR75/P5	Frost Prism® Long Life	120	130	680	5000	C-9M	4¼	-
		103026	A19FR75/P10	Frost Prism® Ultra Life®	20/120	130	620	10000	C-9M	4¼	-
		101161	A19FR75/12V	Frost	12/240	12	850	1500	C-9	4¼	-
		6329	A19BLB75	Blacklight-Blue Halco®	20/120	120	-	800	C-9	4¼	-
		6152	A19RS75	Rough Service Halco®	20/120	130	1100	2500	C-9	4¼	-
		6142	A19TF75	Silicone Coated Halco®	20/120	130	-	2000	C-9	4¼	-
	BA22d	6928	A19FR75B	Frost	20/120	220	700	1000	CC-9	4¼	-
	E27	6922	A19FR75E	Frost	20/120	220	700	1000	CC-9	4¼	-
A21	Med.	101244	A21CL75/ND	CL Neodymium PureLite®	12/60	120	710	5000	C-9M	5	-
		101248	A21FR75/ND	FR Neodymium PureLite®	12/60	120	710	5000	CC-9	5	-
BR30	Med.	104626	BR30FL75/H	Flood Halogen Halco®	12/24	120	900	2500	CC-8	5½	-
BR38	Med.	104090	BR38FL75/5	FL Hard Glass Halco®	12/24	130	650	5000	CC-2V	5½	-
BR40	Med.	404078	BR40FL75/P5	Flood Prism® Long Life	12/24	130	700	5000	C-9M	6 ⁵ / ₈	-
		234898	BR40DB75/SG	Dual Beam	24	125	-	5000	C-9	6½	-
ER30	Med.	9114	ER30FL75/P5	Flood Prism® Long Life	12/60	130	700	5000	C-9M	6¼	-
PAR16	Med.	859034	HP16NFL75/M	Narrow Flood	15	120	900	2000	CC-8	2 ⁷ / ₈	30
		859036	HP16NSP75/M	Narrow Spot	15	120	900	2000	CC-8	2 ⁷ / ₈	10
PAR30	Med.	107633	HP30FL75 (E)	Flood Prism®	15	130	940	2500	CC-8	3½	36
		107670	HP30FL75/120 (E)	Flood Prism®	15	120	940	2500	CC-8	3½	36
		814779	HP30FL75/M (E)	Flood	15	120	1030	2000	CC-8	3 ⁵ / ₈	40
		284927	HP30FL75/M130 (E)	Flood	15	130	965	2000	CC-8	3 ⁵ / ₈	40
		107634	HP30FL75L (E)	Flood L Neck Prism®	15	130	940	2500	CC-8	4½	36
		107672	HP30FL75L/120 (E)	Flood L Neck Prism®	15	120	940	2500	CC-8	4½	36
		814943	HP30FL75L/M (E)	Flood Long Neck	15	120	940	2000	CC-8	4½	40
		229435	HP30FL75L/M130 (E)	Flood Long Neck	15	130	940	2000	CC-8	4½	40
		337212	HP30FL75/SG (E)	Flood Long Neck	15	130	940	2000	CC-8	4½	40
		107820	HP30FL75L/FR (E)	Frost L Neck FL Prism®	15	120	900	2500	CC-8	4½	36
		818057	HP30NFL75/M (E)	Narrow Flood	15	120	1030	3000	CC-8	3 ⁵ / ₈	25
		814802	HP30NSP75/M (E)	Narrow Spot	6	120	1030	3000	CC-8	3 ⁵ / ₈	10
		107540	HP30SP75 (E)	Spot Prism®	15	130	940	2500	CC-8	3½	10
		107542	HP30SP75L (E)	Sp Long Neck Prism®	15	130	940	2500	CC-8	3½	10

To save energy costs, find the bulbs with the light output you need, then choose the one with the lowest watts.

(E) Means this lamp meets Federal Minimum Efficiency standards.