



PAR30



PAR30L



PAR38

SPAR Silver PAR Series



Silver PAR Series lamps use an improved silver reflector construction paired with a Xenon burner to offer increased performance over standard Halogen PAR lamps. The silver reflector technology provides increased efficiency that meets current energy legislation requirements without sacrificing light output or quality.

Specifications:

- EISA Compliant
- 1,500 hour life
- Xenon burner
- Silver spiral reflector for increased efficiency
- Brass base
- Crisp, white light
- Dimmable
- Precision beam control
- Up-to 30% higher lumens per watt than standard Halogen
- Energy efficient alternative to 60W-120W standard Halogen

- » EISA Compliant
- » Xenon Burner
- » Silver Reflector

Markets:

- Residential
- Commercial

Applications:

- Office
- Residential
- Retail/Display
- Accent
- General

where there's light, there's halco®

Contact your account representative at 800.677.3334 for pricing, orders and technical support.

Visit us at halcolighting.com


Ordering Information

Watt	Base	Product #	Product Code	Description	Volts	Color Temp.	CBCP	Lumens	Avg Rated Life	Pkg. Qty.	Filament Design	Beam Angle	Equiv. Watts	MOL
PAR30														
60 Watt	Med.	70345	ⓔ HP30FL60/S/HX	Dimmable Flood	120	3000	2300	1090	1500	1/15	CC-8	30°	75	3.62"
PAR30L														
60 Watt	Med.	70342	ⓔ HP30FL60L/S/HX	Dimmable Flood	120	3000	1900	1090	1500	1/15	CC-8	30°	75	4.75"
60 Watt	Med.	70349	ⓔ HP30WFL60L/S/HX	Dimmable Wide Flood	120	3000	1200	1090	1500	1/15	CC-8	50°	75	4.75"
60 Watt	Med.	70348	ⓔ HP30SP60L/S/HX	Dimmable Spot	120	3000	5800	1090	1500	1/15	CC-8	10°	75	4.75"
PAR38														
50 Watt	Med.	70350	ⓔ HP38FL50/S/HX	Dimmable Flood	120	3000	1300	920	1500	1/15	CC-8	30°	60	5.31"
60 Watt	Med.	70341	ⓔ HP38FL60/S/HX	Dimmable Flood	120	3000	2000	1090	1500	1/15	CC-8	30°	75	5.31"
70 Watt	Med.	70346	ⓔ HP38FL70/S/HX	Dimmable Flood	120	3000	2800	1350	1500	1/15	CC-8	30°	90	5.31"
70 Watt	Med.	70352	ⓔ HP38SP70/S/HX	Dimmable Spot	120	3000	7200	1350	1500	1/15	CC-8	10°	90	5.31"
80 Watt	Med.	70351	ⓔ HP38FL80/S/HX	Dimmable Flood	120	3000	3000	1580	1500	1/15	CC-8	30°	120	5.31"

ⓔ Means this bulb meets the Federal minimum efficiency standards.

This product contains an internal halogen-based capsule that may continue to operate and emit UV if the outer glass envelope is cracked or broken. The capsule is under pressure, operates at high temperatures, and could unexpectedly shatter, which may result in the discharge of extremely hot glass particles into the fixture and/or surrounding area, creating a risk of personal injury or fire. Adhering to the operating instructions will greatly reduce these risks.

Energy Savings Comparison

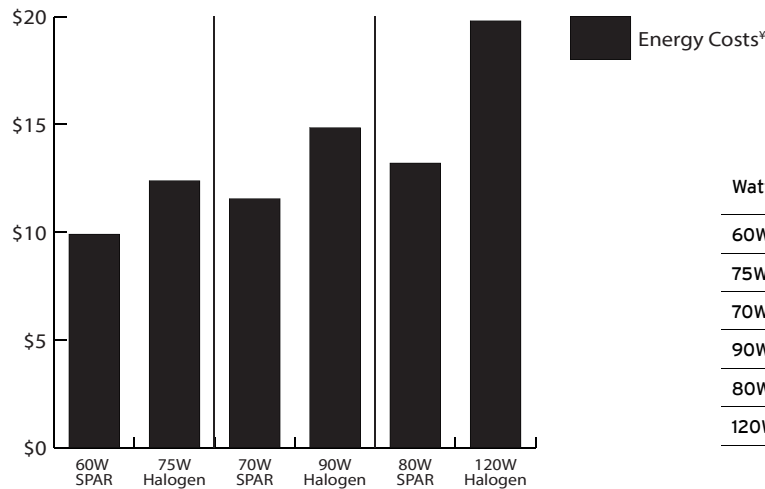

Watts	Energy Costs	Energy Savings
60W SPAR	\$9.90	\$2.48
75W Halogen	\$12.38	
70W SPAR	\$11.55	\$3.30
90W Halogen	\$14.85	
80W SPAR	\$13.20	\$6.60
120W Halogen	\$19.80	

* Energy costs based on \$0.11 kWh over 1,500 hour life.