


Incandescent General Service

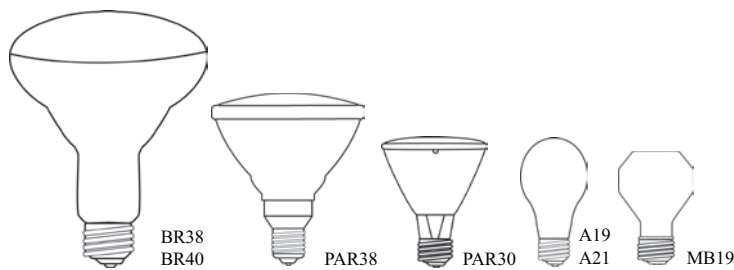

Bulb	Base	Product Number	Footnotes	Product Code	Description	Pkg. Qty.	Volts	Lumens	Avg. Life	Design Filament	MOL	Beam Spread
68 WATT												
A19	Med.	288580	11	A19FR68/10	Frost Prism® Ultra Life®	20/120	130	630	10000	C-9M	4.25"	-
70 WATT												
BR40	Med.	75004	\$,12,17	BR40FL100/70HX	Flood HaloXen®	12/24	125	1050	5000	CC-8	6.56"	-
PAR30	Med.	70200	ⓔ N,\$,18	HP30FL75/70HX	Flood HaloXen®	15	125	1160	5000	CC-8	3.62"	40°
		70201	ⓔ N,\$,18	HP30FL75L/70HX	Flood Long Neck HaloXen®	15	125	1080	5000	CC-8	4.75"	40°
75 WATT												
A19	Med.	103714	Al	A19CL75	Clear	120	130	860	1500	C-9	4.25"	-
		6326		A19CL75/5	Clear	120	130	700	5000	C-9	4.25"	-
		103706	Al	A19FR75	Frost	120	130	820	1500	C-9	4.25"	-
		6322		A19FR75/5	Frost	120	130	700	5000	C-9	4.25"	-
		103026		A19FR75/P10	Frost Prism® Ultra Life®	20/120	120	620	10000	C-9M	4.25"	-
		103524	x,N	A19FR75/20	Frost Prism® Ultra Life®	20/120	120	710	20000	C-9M	4.25"	-
		6222		A19SW75/120	Soft White	120	120	780	1500	CC-6	4.25"	-
		6152		A19RS75	Rough Service	20/120	130	1100	2500	C-9	4.25"	-
		6142		A19RS75/CS	CoverShield®	20/120	130	-	2000	C-9	4.25"	-
A21	Med.	101248	N	A21FR75/ND	Frost Neodymium PureLite®	12/60	120	710	5000	CC-6	5.00"	-
MB19	Med.	108860		MB19FR75	Frost Halogen Prism®	1/12	130	1050	3000	CC-8	4.25"	-
PAR30	Med.	107633	ⓔ N,\$,18	HP30FL75	Flood Prism®	15	130	1150	3000	CC-8	3.62"	40°
		107670	ⓔ N,\$,18	HP30FL75/120	Flood Prism®	15	120	1150	3000	CC-8	3.62"	40°
		107634	ⓔ N,\$,18	HP30FL75L	Flood Long Neck Prism®	15	130	1100	3000	CC-8	4.75"	40°
		107672	ⓔ N,\$,18	HP30FL75L/120	Flood Long Neck Prism®	15	120	1100	3000	CC-8	4.75"	40°
		107540	ⓔ N,\$,18	HP30SP75	Spot Prism®	15	130	1150	3000	CC-8	3.62"	10°
		107542	ⓔ N,\$,18	HP30SP75L	Spot Long Neck Prism®	15	130	1100	3000	CC-8	4.75"	10°
		107572	ⓔ N,\$,18	HP30WFL75L	Wide Flood Long Neck Prism®	15	130	1100	3000	CC-8	4.75"	60°
PAR38	Med.	107576	ⓔ N,\$,19	HP38FL75	Flood Prism®	15	130	1100	3000	CC-8	5.32"	30°
		107864	ⓔ N,\$,19	HP38FL75/120	Flood Prism®	15	120	1100	3000	CC-8	5.32"	30°
85 WATT												
BR38	Med.	75002	\$,12,17	BR38FL150/85HX	Flood HaloXen®	12/24	125	820	5000	CC-8	5.37"	-
BR40	Med.	75005	\$,12,17	BR40FL120/85HX	Flood HaloXen®	12/24	125	1480	5000	CC-8	5.37"	-
PAR38	Med.	70403	ⓔ N,\$,19	HP38FL90/85HX	Flood HaloXen®	15	125	1420	5000	CC-8	5.32"	30°
90 WATT												
A19	Med.	288582	ⓔ x,\$,11	A19FR90/10	Frost Prism® Ultra Life®	20/120	130	920	10000	C-9M	4.25"	-
PAR38	Med.	107644	ⓔ N,\$,19	HP38FL90	Flood Prism®	15	130	1350	3000	CC-8	5.32"	30°
		107696	ⓔ N,\$,19	HP38FL90/120	Flood Prism®	15	120	1350	3000	CC-8	5.32"	30°
		107584	ⓔ N,\$,19	HP38SP90	Spot Prism®	15	130	1350	3000	CC-8	5.32"	10°
		107866	ⓔ N,\$,19	HP38SP90/120	Spot Prism®	15	120	1350	3000	CC-8	5.32"	10°
100 WATT												
A19	Med.	103716	Al	A19CL100	Clear	120	130	1150	1500	C-9	4.25"	-