



PAR20

PAR30

PAR30L

PAR38

## HALOXEN® PAR Reflector Series

**Halco**  
LIGHTING TECHNOLOGIES®

HALOXEN® PAR Reflector Series lamps are a more economic and energy efficient alternative to higher wattage Halogen lamps. Aluminum PAR Reflector lamps use improved construction to offer light output comparable to 45W and 50W standard Halogen PAR lamps.

### Specifications:

- Halogen-Xenon burner
- Up-to 2,000 hour life
- Brass base
- Crisp, white light
- Dimmable
- Precision beam control
- Higher lumens per watt than standard Halogen
- Energy efficient alternative to standard 45W and 50W Halogen
- Available in 120V and 130V

- » Halogen-Xenon burner
- » Dimmable
- » Crisp, white light

### Markets:

- Residential
- Commercial

### Applications:

- Office
- Residential
- Retail/Display
- Accent
- General

where there's light, there's halco®

Contact your account representative at 800.677.3334 for pricing, orders and technical support.


Visit us at [halcolighting.com](http://halcolighting.com)

## Ordering Information

Watt	Base	Product #	Product Code	Description	Volts	Color Temp.	CBCP	Lumens	Avg. Rated Life	Pkg. Qty.	Filament Design	Beam Spread	MOL	Equivalent Wattage
<b>PAR20</b>														
39 Watt	Med.	70343	HP20NFL39/HX	Dimmable Narrow Flood	120V	2850	900	530	2000	1/15	CC-8	30°	3.23	50
39 Watt	Med.	70354	HP20NFL39/HX/130	Dimmable Narrow Flood	130V	2850	900	530	2000	1/15	CC-8	30°	3.23	50
<b>PAR30</b>														
39 Watt	Med.	70347	HP30FL39/HX	Dimmable Flood	120V	2850	1100	530	2000	1/15	CC-8	30°	3.62	50
39 Watt	Med.	70353	HP30FL39/HX/130	Dimmable Flood	130V	2850	1100	530	2000	1/15	CC-8	30°	3.62	50
<b>PAR30L</b>														
39 Watt	Med.	70344	HP30FL39L/HX	Dimmable Flood	120V	2850	1000	530	2000	1/15	CC-8	30°	4.75	50
39 Watt	Med.	70204	HP30WFL39L/HX	Dimmable Wide Flood	120V	2850	650	530	2000	1/15	CC-8	50°	4.75	50
39 Watt	Med.	70203	HP30SP39L/HX	Dimmable Spot	120V	2850	4000	530	2000	1/15	CC-8	15°	4.75	50
39 Watt	Med.	70356	HP30FL39L/HX/130	Dimmable Flood	130V	2850	1000	530	2000	1/15	CC-8	36°	4.75	50
<b>PAR38</b>														
39 Watt	Med.	70340	HP38FL39/HX	Dimmable Flood	120V	2850	1000	530	2000	1/15	CC-8	30°	5.31	45
39 Watt	Med.	70404	HP38SP39/HX	Dimmable Spot	120V	2850	5000	530	2000	1/15	CC-8	10°	5.31	45
39 Watt	Med.	70355	HP38FL39/HX/130	Dimmable Flood	130V	2850	1100	530	2000	1/15	CC-8	30°	5.31	45

This product contains an internal halogen-based capsule that may continue to operate and emit UV if the outer glass envelope is cracked or broken. The capsule is under pressure, operates at high temperatures, and could unexpectedly shatter, which may result in the discharge of extremely hot glass particles into the fixture and/or surrounding area, creating a risk of personal injury or fire. Adhering to the operating instructions will greatly reduce these risks.

## Energy Savings Comparison

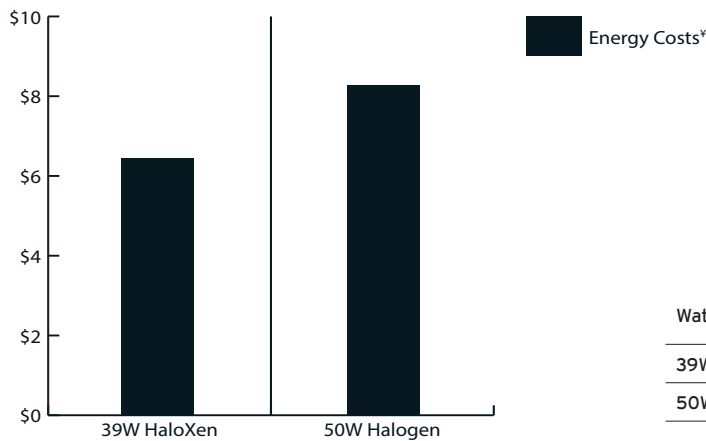

\* Energy costs based on \$0.11 kWh over 1,500 hour life.