


# INCANDESCENT LAMPS

## General Service

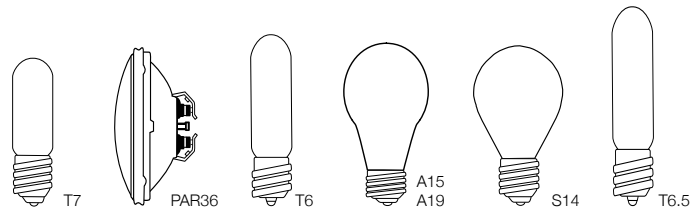

Bulb	Base	Product Number	Footnotes	Product Code	Description	Pkg. Qty.	Volts	Lumens	Avg. Life	Design Filament	MOL	Beam Spread	
<b>11 WATT</b>													
S14	Med.	9051		S14CL11	Clear	25/250	130	80	5000	C-9	3.50"	-	
		9057		S14FR11	Frost	25/250	130	75	3000	C-9	3.50"	-	
		9056		S14AMB11T	Transparent Amber	25/250	130	-	3000	C-9	3.50"	-	
		9076		S14BLU11C	Ceramic Blue	25/250	130	-	3000	C-9	3.50"	-	
		9055		S14BLU11T	Transparent Blue	25/250	130	-	3000	C-9	3.50"	-	
		9070		S14GRN11C	Ceramic Green	25/250	130	-	3000	C-9	3.50"	-	
		9054		S14GRN11T	Transparent Green	25/250	130	-	3000	C-9	3.50"	-	
		105334		S14RED11C	Ceramic Red	25/250	130	-	3000	C-9	3.50"	-	
		9052		S14RED11T	Transparent Red	25/250	130	-	3000	C-9	3.50"	-	
		9058		S14WH11C	Ceramic White	25/250	130	-	3000	C-9	3.50"	-	
		105336		S14YEL11C	Ceramic Yellow	25/250	130	-	3000	C-9	3.50"	-	
		9053		S14YEL11T	Transparent Yellow	25/250	130	-	3000	C-9	3.50"	-	
<b>15 WATT</b>													
A15	Med.	6013		A15CL15	Clear	20/120	130	95	3000	C-9	3.50"	-	
		6014		A15FR15	Frost	20/120	130	90	3000	C-9	3.50"	-	
T6	Cand.	9030		T6CL15/CAN	Clear	25/500	130	90	2000	C-5A	3.06"	-	
		9021		T6CL15/145V	Clear	25/500	145	80	2000	C-5A	3.06"	-	
T7	Cand.	9039		T7CL15CAN	Clear	25/1000	120	100	2000	C-5A	2.25"	-	
		BA15d	9038		T7CL15DC	Clear	25/1000	120	100	2000	C-5A	2.35"	-
		Int.	9037		T7CL15INT	Clear	25/1000	120	100	2000	C-5A	2.35"	-
<b>20 WATT</b>													
PAR36	Screw Term.	107788	\$.17	HP36NSP20/HX	Narrow Spot HaloXen®	12	12	260	5000	C-6	2.75"	12°	
		107790	\$.17	HP36VNSP20/HX	Very Narrow Spot HaloXen®	12	12	260	5000	C-6	2.75"	5°	
		107792	\$.17	HP36WFL20/HX	Wide Flood HaloXen®	12	12	260	5000	C-6	2.75"	32°	
T6.5	BA15d	9022		T6.5CL20DC	Clear	25/500	130	150	2500	C-8	5.56"	-	
		9023		T6.5FR20DC	Frost	25/500	130	150	2500	C-8	5.56"	-	
	Int.	9019		T6.5CL20INT	Clear	25/500	130	150	2500	C-8	5.50"	-	
		9028		T6.5FR20INT	Frost	25/500	130	150	2500	C-8	5.50"	-	
<b>25 WATT</b>													
A15	Med.	6016		A15CL25	Clear	20/120	130	130	3000	C-9	3.50"	-	
		6015		A15FR25	Frost	20/120	130	120	3000	C-9	3.50"	-	
A19	Med.	6318		A19CL25/5	Clear	120	130	175	5000	C-9	4.25"	-	
		103700	AI	A19FR25	Frost	120	130	160	1500	C-9	4.25"	-	
		6319		A19FR25/5	Frost	120	130	150	5000	C-9	4.25"	-	
		101159	10	A19FR25/12V	Frost	12/240	12	240	2000	C-6	4.25"	-	
		101150		A19BLU25T	Transparent Blue	12/120	130	-	2000	C-9	4.25"	-	

Ⓢ Means this lamp meets Federal Minimum Efficiency standards.  
Incandescent lamp symbols, footnotes and abbreviations are located on pages 151-153.