



**MOGUL PULLING ELBOW - TYPE LB (ALUMINUM)**

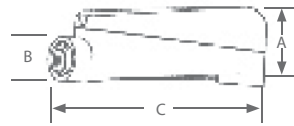


HALEX PART #	DIMENSIONS (INCHES)		
	A	B	C
58212B	3.500	2.719	9.625
58215B	5.500	4.125	14.563
58220B	5.500	4.125	14.563

**WATER-TIGHT CONDUIT HUBS (ZINC DIE CAST)**

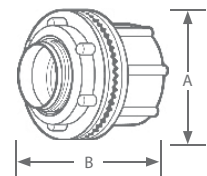


HALEX PART #	DIMENSIONS (INCHES)	
	A	B
91631	1.438	1.344
91632	1.719	1.469
16310	2.000	1.656
16312	2.375	1.688
16315	2.750	1.688
16320	3.250	1.750
16325B	3.750	2.219
16330B	4.375	2.313
16335B	5.000	2.375
16340B	5.500	2.438

**90° SHORT RADIUS ELBOWS (ZINC DIE CAST)**

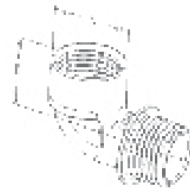

HALEX PART #	DIMENSIONS (INCHES)	
	A	B
19005	0.98	0.96
19007	1.17	1.04

**90° LARGE RADIUS ADAPTER ELBOWS (ZINC DIE CAST)**

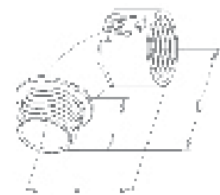


HALEX PART #	DIMENSIONS (INCHES)		
	A	B	C
19205B	1.294	1.450	0.521
19207B	1.526	1.690	0.521

**BAGGED ITEMS**

91921	1.294	1.450	0.521
91922	1.526	1.690	0.521

**RIGID COUPLINGS (STEEL)**

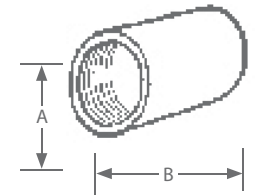

HALEX PART #	DIMENSIONS (INCHES)	
	A	B
64005	1.010	1.625
64005B	1.010	1.625
64007	1.250	1.640
64007B	1.250	1.640
64010	1.525	1.970
64012	1.869	2.030
64015	2.155	2.060
64020	2.650	2.125
64025	3.250	3.190
64030	3.870	3.315
64035	4.500	3.410
64040	4.875	3.515

**90° RIGID ELBOWS (STEEL)**



HALEX PART #	A	DIMENSIONS (INCHES)	
		MIN. UL RADIUS	B
64105	6.375	4.000	1.750
64105B	6.375	4.000	1.750
64107	7.438	4.500	2.250
64107B	7.438	4.500	2.250
64110	9.500	5.750	2.250
64110B	9.500	5.750	2.250
64112	11.375	7.250	3.000
64112B	11.375	7.250	3.000
64115	12.813	8.250	3.500
64115B	12.813	8.250	3.500
64120	15.500	9.500	4.000
64120B	15.500	9.500	4.000
64125	19.250	10.500	4.750
64130	21.500	13.000	6.000
64135	24.500	15.000	5.500
64140	25.500	16.000	5.750

**45° RIGID ELBOWS (STEEL)**



HALEX PART #	A	DIMENSIONS (INCHES)	
		MIN. UL RADIUS	B
64205	6.375	4.000	1.750
64207	7.438	4.500	2.250
64210	9.500	5.750	2.250
64212	11.375	7.250	3.000
64215	12.813	8.250	3.500
64220	15.500	9.500	4.000