



## Heyco® Open/Closed Bushings

Mounting Hole Diameter Range: .375" (9,5 mm) to 2.500" (63,5 mm)

MOUNTING HOLE DIAMETER		PART NO.	DESCRIPTION	PART DIMENSIONS					
in.	mm.			A Inside Diameter		B Head Diameter		C Overall Height	

Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)



	.375	9,5	<b>2865</b>	OCB 375	.27	6,7	.42	10,7	.39	9,9
	.437	11,1	<b>2867</b>	OCB 437	.33	8,4	.50	12,7	.41	10,3
	.500	12,7	<b>2871</b>	OCB 500	.31	7,9	.56	14,3		
<b>NEW!</b>	.512	13,0	<b>2875</b>	OCB 512	.35	9,0	.59	14,9		
	.562	14,3	<b>2869</b>	OCB 562	.39	9,9	.64	16,3		
	.625	15,9	<b>2872</b>	OCB 625	.45	11,1	.69	17,5		
<b>NEW!</b>	.650	16,5	<b>2914</b>	OCB 650	.48	12,3	.73	18,6		
	.750	19,1	<b>2873</b>	OCB 750	.55	12,7	.78	19,8		
<b>NEW!</b>	.866	22,0	<b>2917</b>	OCB 866	.68	17,3	.98	24,8		
	.875	22,2	<b>2874</b>	OCB 875	.67	14,3	.92	23,4		
<b>NEW!</b>	.984	25,0	<b>2920</b>	OCB 984	.80	20,4	1.04	26,4		
	1.000	25,4	<b>2878</b>	OCB 1000	.81	19,1	1.05	26,6		
	1.093	27,8	<b>2879</b>	OCB 1093	.88	20,6	1.16	29,4		
	1.250	31,8	<b>2881</b>	OCB 1250	1.05	25,8	1.34	34,1		
	1.375	34,9	<b>2882</b>	OCB 1375	1.17	25,4	1.47	37,3		
	1.500	38,1	<b>2883</b>	OCB 1500	1.25	26,9	1.58	40,1		
	2.000	50,8	<b>2900</b>	OCB 2000	1.73	43,9	2.12	53,9	.42	10,7

Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)

2.500	63,5	<b>2909</b>	OCB 2.5	2.00	50,8	2.60	66,0	.72	18,3
-------	------	-------------	---------	------	------	------	------	-----	------

Standard color black. Consult Heyco for white and other colors.

- **Split design allows side entry** and encirclement of preassembled harnesses, capillary tubes, computer cables, power cords, or other assemblies that have segments larger than the bushing's I.D.
- May also be assembled into holes that already contain cable, wire or other filaments.
- Fingertip pressure snap-locks the bushing into its mounting hole.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Multiple sizes for use in mounting holes from .375" (9,5 mm) to 2.500" (63,5 mm).

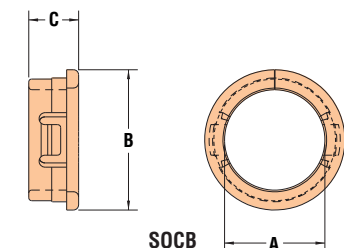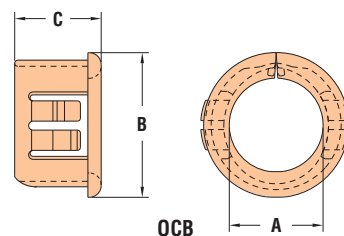

**ALL NEW PRODUCTS!**

- **For use in panels .062" (1,6 mm) and thinner.**
- Lower overall height protrudes less through thin mounting panels; thus Shorty Open/Closed Bushings occupy less "real estate" inside your application.
- **Split design allows side entry** and encirclement of preassembled harnesses, power cords, capillary tubes or other assemblies that have segments larger than the bushing's ID.
- May also be assembled into holes that already contain cable, wire or other filaments.
- Fingertip pressure snap-locks the bushing into its mounting hole.

## Heyco® Open/Closed Shorty Bushings

Single Locking Step for Panel Thickness up to .062" (1,6 mm)

Mounting Hole Diameter Range: 7,0 mm (.276") 27,0 mm (1.063")

MOUNTING HOLE DIAMETER		PART NO.	DESCRIPTION	PART DIMENSIONS					
in.	mm.			A Inside Diameter		B Head Diameter		C Overall Height	

Standard color black. Consult Heyco for white and other colors.

Material	Nylon 6/6
Certifications	Recognized under the Component Program of Underwriters' Laboratories File E15331 Certified by the Canadian Standards Association File 8919
Flammability Rating	94V-2
Temperature Range	-4°F (-18°C) to 221°F (105°C)