




Heyco® SunBundler® Stainless Steel *Wire* Cable Ties

- **Extremely durable, vinyl jacketed Stainless Steel Cable Tie.**
- Smooth vinyl jacketing prevents damage to installation cable insulation.
- Stainless steel crimp sleeve for easy field installation with electrician linesman pliers, or wire cutters.
- UV protected vinyl jacket is excellent for solar installation where product durability is required.
- Use standard wire cutters to both crimp the sleeve and cut the excess wire.
- Not for use in a marine salt water environment. Contact Heyco for alternative materials.

PART SPECIFICATIONS				PART NO.		DESCRIPTION	PART DIMENSIONS			
Max. Tensile Strength		Max. Bundle Diameter		100 Pack	Bulk		A Length		B Diameter	
Lbs.	N	in.	mm.				in.	mm.	in.	mm.
Black vinyl jacketed 302/304 stainless steel wire										
		2.30	58,4	S6408	S6409	SunBundler® 8	8	203		
		2.92	74,2	S6410	S6411	SunBundler® 10	10	254		
100	440	3.88	98,6	S6412	S6413	SunBundler® 12	12	305	.06	1,6
		4.20	106,7	S6414	S6415	SunBundler® 14	14	356		
		6.36	161,5	S6420	S6421	SunBundler® 20	20	508		

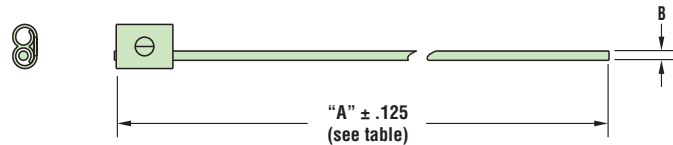

Material Commercial Aircraft Grade 302/304 stainless wire w/UV protected vinyl jacket and 304 stainless steel crimp sleeve

Certifications Certified by Underwriter's Laboratories for Compliance with both Canadian and U.S. Requirements under File E54523




Heyco® SunWrap™ - Heavy Duty Cable Guard



- **Easy to use: Just twist on wire!**
- Designed to shield heavier cables and cable bundles; **extend cable life.**
- Available in a **variety of sizes** that fit cable and cable bundles from 3/4" to 6" in diameter.
- **Smooth finished interior wall.**
- **Highly flexible** for ease of movement.
- Packaged as one continuous piece in a box, not spooled.
- May be **cut to desired length**, please consult Heyco.

BUNDLE RANGE				PART NO.	DESCRIPTION	PART DIMENSIONS					
Minimum Diameter		Maximum Diameter				A Outside Dia.		B Pitch		C Thickness	
in.	mm.	in.	mm.			in.	mm.	in.	mm.	in.	mm.
.75	19,1	1.50	38,1	8964	CWG 99 PE	.93	23,6	.95	24,1	.12	3,0
1.00	25,4	2.00	50,8	8966	CWG 126 PE	1.12	28,4	1.25	31,8	.13	3,3
1.25	31,8	2.50	63,5	8968	CWG 153 PE	1.37	34,8	1.35	34,3	.14	3,5
1.50	38,1	3.00	76,2	8970	CWG 181 PE	1.62	41,1	1.50	38,1	.15	3,9
2.00	50,8	3.50	88,9	8972	CWG 234 PE	2.09	53,1	1.60	40,6	.17	4,3
3.50	88,9	6.00	152,4	8974	CWG 401 PE	3.50	88,9	1.95	49,5	.25	6,4

*Standard color black or color coded

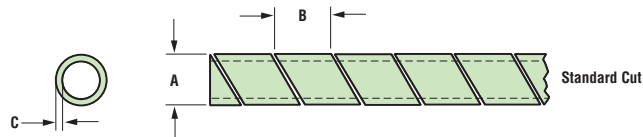

Material High Density Polyethylene

Certifications Recognized under the Component Program of Underwriter's Laboratories File E54523

Flammability Rating 94-HB

Temperature Range 0°F (-18°C) to 165°F (74°C)

Quick Specs