

ARMORED CABLE CONNECTORS

ZINC DIE CAST - CONNECTORS



Application

- For use in dry locations to bond armored cable to a box or enclosure

Product Feature

- Rugged metallic construction insures mechanical protection for the raceway

Compliance

-  – Standard 514B
-  – C22.2 #18




Clamp Type
Die Cast Zinc



Squeeze Type
Uninsulated
Die Cast Zinc


RACO COMMERCIAL FITTINGS

2661

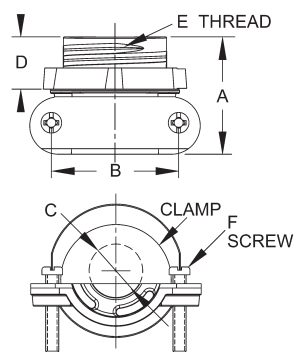

- A = Length
- B = Screw centerlines
- C = Clamping range
- D = Thread length
- E = Thread spec.
- F = Screw

2191 - 2194

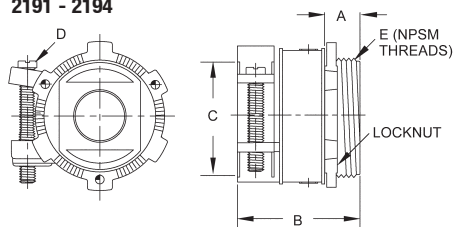

- A = Thread length
- B = Overall length
- C = Conduit opening
- D = Screw spec
- E = Thread spec

ORDERING INFORMATION - DIMENSIONS

CLAMP TYPE - DIE CAST ZINC

CATALOG NUMBER	TRADE SIZE	UNIT. CTN. QTY.	SHIP. CTN. QTY.	UPC BAR CODE
2661	3/8"	100	1000	—

For 1/2" knockout. Suitable for use with steel armored cable sizes 2#14, 3#14, 2#12, 3#12, 2#10, and 3#10 all with ground wire

DIMENSIONS

CATALOG NUMBER	A	B	C	D	E	F
2661	27/32"	7/8"	23/64"	3/8"	1/2"-14 NPSM	8-32 x 3/4"

SQUEEZE TYPE - UNINSULATED - DIE CAST ZINC

CATALOG NUMBER	TRADE SIZE	UNIT. CTN. QTY.	SHIP. CTN. QTY.	UPC BAR CODE
2191	3/8"*	50	500	—
2192	1/2"	25	250	—
2193	3/4"	25	250	—
2194	1"	10	100	—

* For 1/2" knockout. Suitable for steel armored cable and flexible metal conduit

DIMENSIONS

CATALOG NUMBER	A	B	C	D	E
2191	13/32"	1"	21/32"	No. 10 x 1.00	1/2"-14 NPSM
2192	1/2"	1-1/2"	63/64"	No. 10 x 1.00	1/2"-14 NPSM
2193	1/2"	1-19/32"	1-3/16"	No. 12 x 1.00	3/4"-14 NPSM
2194	9/16"	1-49/64"	1-29/64"	No. 12 x 1.25	1"-11-1/2 NPSM