

Application

- For use in dry locations to bond armored cable to a box or enclosure

Product Features

- Rugged metallic construction insures mechanical protection for the raceway
- UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code and packaged in pre-scored tear top cartons for an attractive presentation

Compliance


- 



90 Degree Squeeze
Insulated Throat
Malleable Iron



90 Degree Squeeze
Uninsulated Throat
Malleable Iron

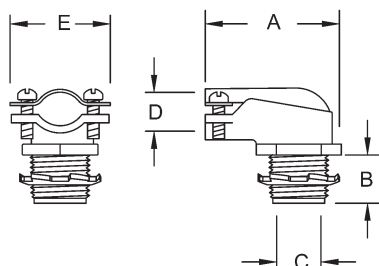

- A = Overall length
- B = Thread length and thread spec
- C = Throat I.D.
- D = Clamping range
- E = Maximum width body

ORDERING INFORMATION - DIMENSIONS

90 DEGREE SQUEEZE - INSULATED THROAT - MALLEABLE IRON

CATALOG NUMBER	TRADE SIZE	UNIT. CTN. QTY.	SHIP. CTN. QTY.	UPC BAR CODE
3201	3/8" *	—	50	—
3202	1/2"	—	25	—
3202-8	1/2"	1	25	
3203	3/4"	—	25	—
3203-8	3/4"	1	20	

* For 1/2" knockout

90 DEGREE SQUEEZE - UNINSULATED - MALLEABLE IRON

CATALOG NUMBER	TRADE SIZE	UNIT. CTN. QTY.	SHIP. CTN. QTY.	UPC BAR CODE
2201	3/8" *	—	50	—
2202	1/2"	25	100	—
2202-8	1/2"	1	25	
2203	3/4"	—	25	—
2203-8	3/4"	1	20	

* For 1/2" knockout

DIMENSIONS

CAT. NO. INSULATED	CAT. NO. UNINSLTD.	A	B	THD. SPEC.	C	D	E
3201	2201	2-1/64"	23/64"	1/2-14 NPS	.570	.390-.630	1-3/8"
3202	2202	2-15/64"	27/64"	1/2-14 NPS	.570	.817-.950	1-51/64"
3202-8	2202-8						
3203	2203	2-1/2"	1/2"	3/4-14 NPS	.822	.830-1.110	1-31/32"
3203-8	2203-8						