

Application

- For use with underground feeder (UF) cable to provide a non-watertight connection to meters and enclosures

Product Feature

- Rugged metallic construction will last the lifetime of the installation

Compliance


-  – Standard 514B



Connectors For Oval Cable
Die Cast Zinc



Connectors For Oval or Round Cable
Die Cast Zinc

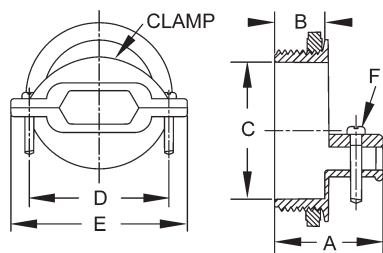

- A = Overall length
- B = Thread length and thread spec
- C = Throat I.D.
- D = Screw center to center
- E = Maximum body width
- F = Screw size

ORDERING INFORMATION - DIMENSIONS

CONNECTORS FOR OVAL CABLE - DIE CAST ZINC					
CATALOG NUMBER	TRADE SIZE	NOMINAL CABLE SIZE	UNIT CTN. QTY.	SHIP CTN. QTY.	UPC BAR CODE
2853	3/4"	3#8, 3#6	—	25	—
2854	1"	3#6, 3#4	—	25	—
2855	1-1/4"	3#6, 3#2	—	10	—
2856	1-1/2"	3#1/0, 3#2/0, 3#1	—	10	—
2858	2"	3#3/0, 3#4/0	—	10	—

CONNECTORS FOR OVAL OR ROUND CABLE - DIE CAST ZINC					
CATALOG NUMBER	TRADE SIZE	NOMINAL CABLE SIZE	UNIT CTN. QTY.	SHIP CTN. QTY.	UPC BAR CODE
2863	3/4"	3#10, 3#6, 2#6	50	500	—
2864	1"	3#6, 3#4	25	250	—

DIMENSIONS						
CATALOG NUMBER	A	B	C	D	E	F
2853/2863	15/16"	27/64"	3/4"- 14 NPSM	1-3/16"	1-21/32"	No. 10-24 x 1"
2854/2864	1-7/64"	33/64"	1"- 11-1/2 NPSM	1-7/16"	1-15/16"	No. 10-24 x 1"
2855	1-5/16"	39/64"	1-1/4"- 11-1/2 NPSM	1-5/8"	2-1/4"	No. 10-24 x 1"
2856	1-21/64"	19/32"	1-1/2"- 11-1/2 NPSM	2-13/64"	2-27/32"	No. 10-24 x 1"
2858	1-37/64"	47/64"	2"- 11-1/2 NPSM	2-3/4"	3-1/2"	No. 12-24 x 1"