

Note: Works with Mechanical Interlocks, see page B-39 for additional information.



**TPE Gland Seal**

Assorted glands accommodate a wide range of cord sizes from #16-3 Type SJ to #8-5 Type S, SO



**Panel or Box Mount Receptacles and Inlets**

- High impact, thermoplastic housing for heavy-duty industrial environments.
- Catalog number and color-coded voltage rating are easily visible when in use.
- Stainless Steel 302/304, #10 multiple drive head mounting screws provide corrosion resistance.
- Mounting screw recesses minimize screwdriver slippage.
- Lockout/tagout hole on inlets allow compliance to OSHA regulation 29 CFR 1910.147.
- TPE closure cap provided with inlets for environmental seal when not in use.
- Accepts all mating NEMA locking plugs and most connector bodies, allowing interchangeability with existing devices.



**Spring-Loaded Cover**



One-step push-to-close spring-loaded cover with latch allows for fast opening and closing of lift cover. Result: environmental sealing is assured



**Safety-Shroud**

- Virtually eliminates bent and broken plug blades, leading to longer equipment life.
- Extends life of mating receptacles by eliminating damage caused by insertion of bent blades.
- Extra protection for personnel by significantly reducing chance of inadvertent contact with blades when connecting or disconnecting energized receptacles and connector bodies.
- Reduces exposure to arcing when connecting or disconnecting plugs under load.
- Compliance with California Code of Regulations, Title 8, Article 51, subsection 2510.7(b), which requires shrouding for devices exceeding 300 volts.
- Lockout/tagout hole allows compliance with OSHA regulation 29 CFR 1910.147.
- Sealing gland and thermoplastic guard assure sealing when fully connected.




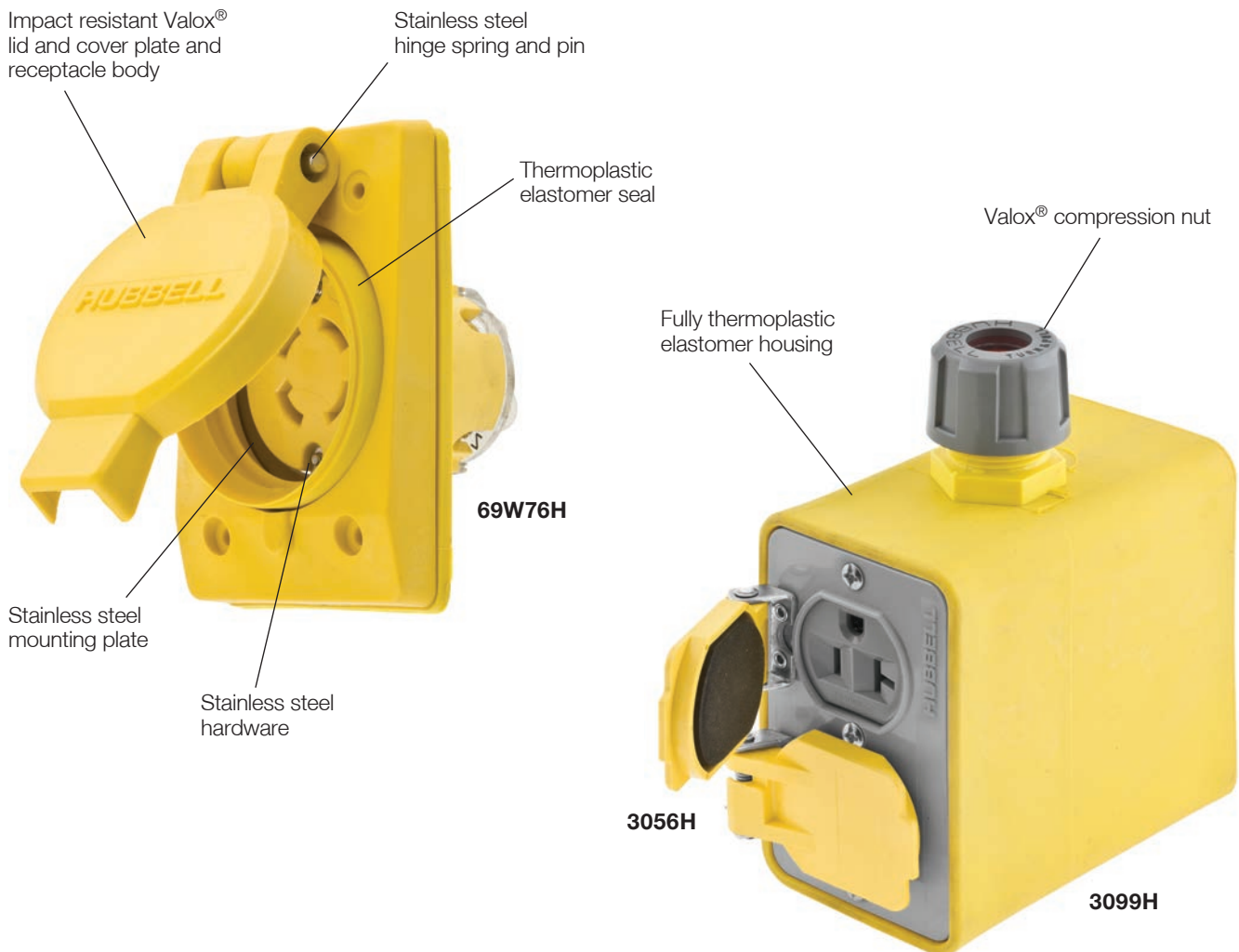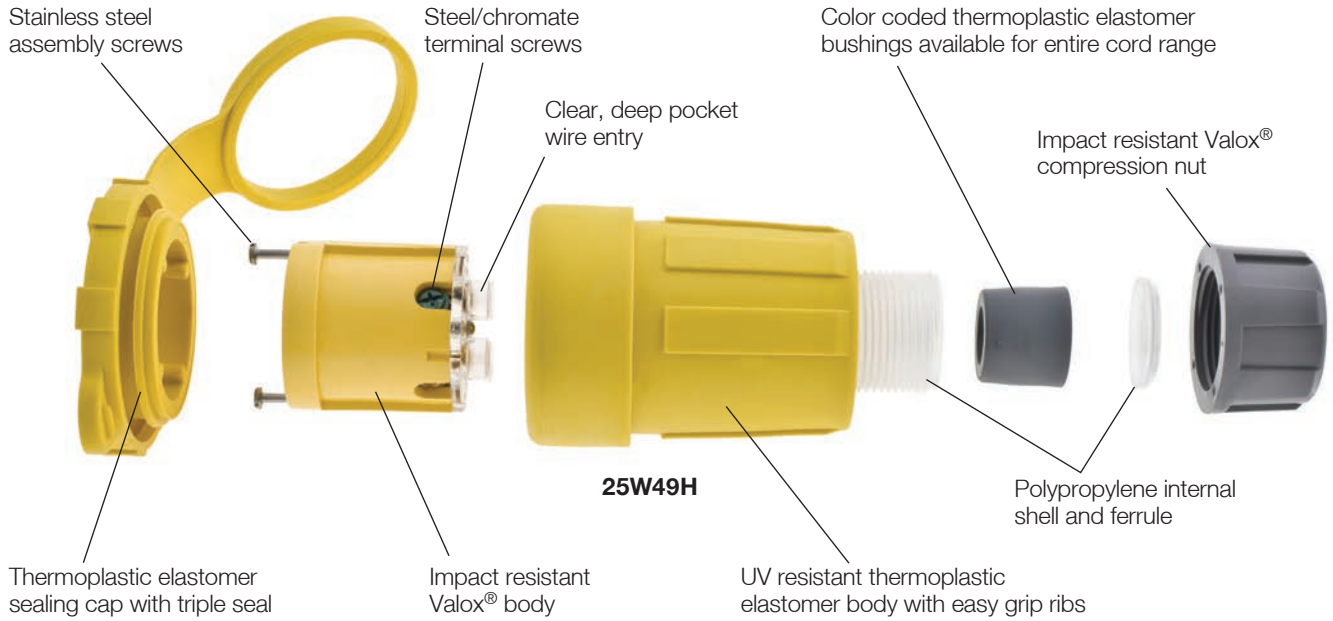


Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.



 
**IP65, 66, 67**  
SUITABILITY



 3P 4W  
30A 125/250V  
NEMA L14-30P  
UL/CSA  
2 (2) HP



 3P 4W  
30A 3Ø 250V AC  
NEMA L15-30P  
UL/CSA  
3 HP



3P 4W  
30A 3Ø 480V AC  
NEMA L16-30P  
UL/CSA  
10 HP

**30A Twist-Lock® Plugs**

 
Description	Cord Dia.	Catalog Number	Catalog Number	Catalog Number
Thermoplastic elastomer yellow plugs.	.640"-.930" (16.3-23.6)	<b>28W74H</b>	<b>28W75H</b>	<b>28W76H</b>




28W76H

**30A Twist-Lock® Connectors/Receptacles\***


Description	Cord Dia.	Catalog Number	Catalog Number	Catalog Number
Thermoplastic elastomer yellow connectors.	.640"-.930" (16.3-23.6)	<b>29W74H</b>	<b>29W75H</b>	<b>29W76H</b>
Thermoplastic elastomer yellow receptacles.	—	<b>69W74H</b>	<b>69W75H</b>	<b>69W76H</b>



 3P 4W  
30A 125/250V  
NEMA L14-30R  
UL/CSA  
2 (2) HP



 3P 4W  
30A 3Ø 250V AC  
NEMA L15-30R  
UL/CSA  
3 HP




3P 4W  
30A 3Ø 480V AC  
NEMA L16-30R  
UL/CSA  
10 HP



29W76H

 **IP65, 66, 67**  
SUITABILITY



3P 4W  
30A 3Ø 600V AC  
NEMA L17-30P  
UL/CSA



4P 4W  
30A 3ØY  
120/208V AC  
NEMA L18-30P  
UL Listed  
3 HP

**30A Twist-Lock® Plugs**

Description	Cord Dia.	Catalog Number	Catalog Number
Thermoplastic elastomer yellow plugs.	.640"-.930" (16.3-23.6)	<b>28W77H</b>	<b>28W78H</b>



3P 4W  
30A 3Ø 600V AC  
NEMA L17-30R  
UL/CSA



4P 4W  
30A 3ØY  
120/208V AC  
NEMA L18-30R  
UL Listed  
3 HP

**30A Twist-Lock® Connectors/Receptacles\***

Description	Cord Dia.	Catalog Number	Catalog Number
Thermoplastic elastomer yellow connectors.	.640"-.930" (16.3-23.6)	<b>29W77H</b>	<b>29W78H</b>
Thermoplastic elastomer yellow receptacles.	—	<b>69W77H</b>	—



69W76H

**IP65, 66, 67**  
SUITABILITY



3P 3W  
30A 125/250V  
Non-NEMA



4P 4W  
30A 3Ø Y  
120/208V AC  
Non-NEMA

**Non-NEMA 30A Twist-Lock® Plugs**

Description	Cord Dia.	Catalog Number	Cord Dia.	Catalog Number
Thermoplastic elastomer yellow plugs.	.475"-.720" (12.1-19.2)	<b>28W08H</b>	.640"-.930" (16.3-23.6)	<b>28W09H*</b>



3P 3W  
30A 125/250V  
Non-NEMA



4P 4W  
30A 3Ø Y  
120/208V AC  
Non-NEMA

**Non-NEMA 30A Twist-Lock® Connectors/Receptacles\***

Description	Cord Dia.	Catalog Number	Cord Dia.	Catalog Number
Thermoplastic elastomer yellow connectors.	.475"-.720" (12.1-19.2)	<b>29W08H*</b>	.640"-.930" (16.3-23.6)	<b>29W09H*</b>
Thermoplastic elastomer yellow receptacles.	—	<b>69W08H*</b>	—	—

Note: \*Receptacles are NEMA 3R, IP44 suitability.  
•UL listed only.