

Kellems® Wire Management Products
Metallic Liquidtight Conduit Fittings



Straight Conduit Fitting

Trade Size (metric designator)	Insulated	Non-Insulated
3/8 (9)	H0381	H038
1/2 (13)	H0501	H050
3/4 (19)	H0751	H075
1 (25)	H1001	H100
1 1/4 (32)	H1251	H125
1 1/2 (38)	H1501	H150
2 (51)	H2001	H200
2 1/2 (63)	H2501	H250
3 (76)	H3001	H300
3 1/2 (89)	H3501	H350
4 (102)	H4001	H400

Note: See page T-116 for additional technical data.



**Straight with Male
Hubbell Conduit Fitting
H050**

45° Conduit Fitting

Trade Size (metric designator)	Insulated	Non-Insulated
3/8 (9)	H03841	H0384
1/2 (13)	H05041	H0504
3/4 (19)	H07541	H0754
1 (25)	H10041	H1004
1 1/4 (32)	H12541	H1254
1 1/2 (38)	H15041	H1504
2 (51)	H20041	H2004

Note: See page T-116 for additional technical data.



**45° Angle with Male
Hubbell Conduit Fitting
H0504**

90° Conduit Fitting

Trade Size (metric designator)	Insulated	Non-Insulated
3/8 (9)	H03891	H0389
1/2 (13)	H05091	H0509
3/4 (19)	H07591	H0759
1 (25)	H10091	H1009
1 1/4 (32)	H12591	H1259
1 1/2 (38)	H15091	H1509
2 (51)	H20091	H2009
2 1/2 (63)	H25091	H2509
3 (76)	H30091	H3009
4 (102)	H40091	H4009


Notes: 3/8" Liquidtight conduit fitting have 1/2 N.P.T. male threads.
 For use with Liquidtight Metal conduit and PolyTuff I Non-Metallic conduit.
 See page T-116 for additional technical data.



**90° Angle with Male
Hubbell Conduit Fitting
H0509**

Kellems® Wire Management Products
Metallic Liquidtight Conduit Fittings

Features and Benefits

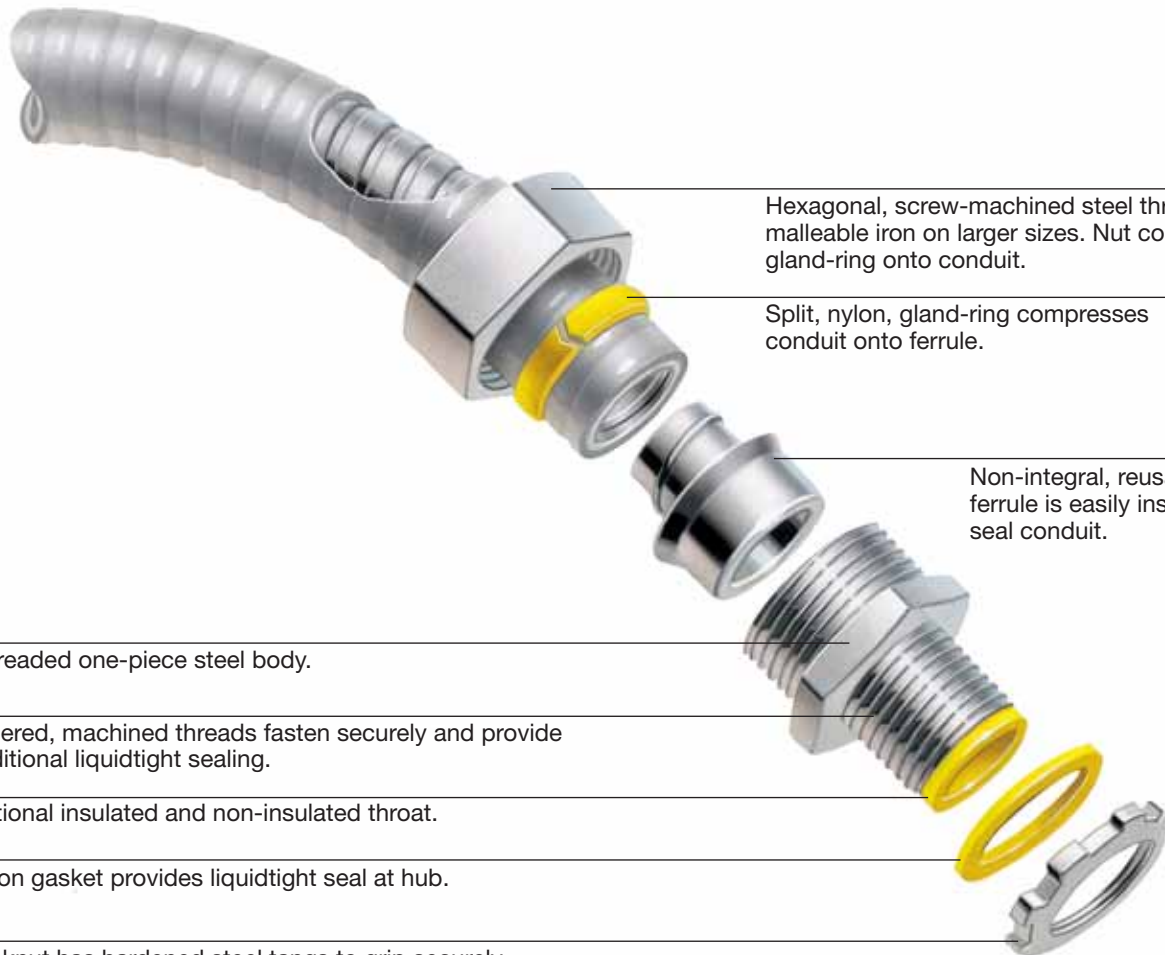

Hexagonal, screw-machined steel thru 1", and malleable iron on larger sizes. Nut compresses gland-ring onto conduit.

Split, nylon, gland-ring compresses conduit onto ferrule.

Non-integral, reusable steel, ferrule is easily installed, to seal conduit.

Threaded one-piece steel body.

Tapered, machined threads fasten securely and provide additional liquidtight sealing.

Optional insulated and non-insulated throat.

Nylon gasket provides liquidtight seal at hub.

Locknut has hardened steel tangs to grip securely.