

Applications


- For use with threaded Rigid/IMC conduit
- Use three-piece couplings to couple conduit ends when the conduit cannot be turned
- RACO® three-piece couplings provide concrete-tight connections

Product Features

- All malleable construction insures mechanical protection of the raceway
- All components are zinc electro plated for corrosion protection

Compliance

- 

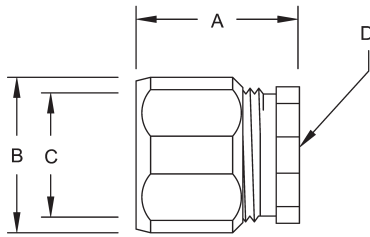

A = Overall length
 B = O.D. body
 C = I.D. body
 D = Thread size



Three-piece Couplings
Malleable

ORDERING INFORMATION - DIMENSIONS

THREE-PIECE COUPLINGS - MALLEABLE				
CATALOG NUMBER	TRADE SIZE	UNIT CTN. QTY.	SHIP CTN. QTY.	UPC BAR CODE
1502	1/2"	—	25	—
1503	3/4"	—	25	—
1504	1"	—	5	—
1505	1-1/4"	—	5	—
1506	1-1/2"	—	5	—
1508	2"	—	5	—
1510	2-1/2"	—	4	—
1512	3"	—	4	—
1514	3-1/2"	—	2	—
1516	4"	—	2	—
1520	5"	—	1	—
1524	6"	—	1	—

DIMENSIONS				
CATALOG NUMBER	A	B	C	D THD. SPEC.
1502	1-3/32"	1-7/32"	49/64"	1/2"-14 NPT
1503	1-1/8"	1-7/16"	31/32"	3/4"-14 NPT
1504	1-3/8"	1-3/4"	1-7/32"	1"-11-1/2 NPT
1505	1-11/16"	2-5/32"	1-9/16"	1-1/4"-11-1/2 NPT
1506	2-17/64"	2-3/4"	1-13/16"	1-1/2"-11-1/2 NPT
1508	2-13/32"	3-3/8"	2-9/32"	2"-11-1/2 NPT
1510	3-1/8"	4-1/16"	2-3/4"	2-1/2"- 8 NPT
1512	3-3/8"	4-17/32"	3-3/8"	3"- 8 NPT
1514	3-43/64"	5-3/16"	3-7/8"	3-1/2"- 8 NPT
1516	3-15/32"	5-3/4"	4-3/8"	4"- 8 NPT
1520	4-3/32"	6-3/4"	5-7/16"	5"- 8 NPT
1524	4-17/64"	8-1/16"	6-1/2"	6"- 8 NPT