


HS & S SERIES WIREWAY ACCESSORIES						
CATALOG NUMBER						DESCRIPTION
2.50 x 2.50 (64 x 64)	4.00 x 4.00 (102 x 102)	6.00 x 6.00 (152 x 152)	8.00 x 8.00 (203 x 203)	10.00 x 10.00* (254 x 254)	12.00 x 12.00* (305 x 305)	
E0202	E0404	E0606	E0808	—	—	End caps (with knockouts)
E0202NK	E0404NK	E0606NK	E0808NK	E1010NK	E1212NK	End caps (without knockouts)
T0202	T0404	T0606	T0808	T1010	T1212	Tee
X0202	X0404	X0606	X0808	X1010	X1212	Cross
AF0202	AF0404	AF0606	AF0808	AF1010	AF1212	Telescope
C0202	C0404	C0606	C0808	C1010	C1212	Connectors
PA0202	PA0404	PA0606	PA0808	PA1010	PA1212	Panel-Adapter
BH0202	BH0404	BH0606	BH0808	BH1010	BH1212	Bracket Hanger
—	R0402	R0604	R0806	R1008	R1208	Reducer
SL020290	SL040490	SL060690	SL080890	SL101090	SL121290	Sweep Elbow – 90°
L020290	L040490	L060690	L080890	L101090	L121290	Elbow – 90°
L020245	L040445	L060645	L080845	L101045	L121245	Elbow – 45°
S SERIES ACCESSORIES (GALVANIZED)						
—	E0404G	E0606G	E0808G	—	—	End caps (without knockouts)
E0202GNK	—	—	—	E1010GNK	E1212GNK	End caps (with knockouts)
T0202G	T0404G	T0606G	T0808G	T1010G	T1212G	Galvanized Tee
X0202G	X0404G	X0606G	X0808G	X1010G	X1212G	Galvanized Cross
AF0202G	AF0404G	AF0606G	AF0808G	AF1010G	AF1212G	Galvanized Telescope
C0202G	C0404G	C0606G	C0808G	C1010G	C1212G	Galvanized Connectors
PA0202G	PA0404G	PA0606G	PA0808G	PA1010G	PA1212G	Galvanized Panel-Adapter
BH0202G	BH0404G	BH0606G	BH0808G	BH1010G	BH1212G	Galvanized Bracket Hanger
—	R0402G	R0604G	R0806G	R1008G	R1208G	Galvanized Reducer
SL020290G	SL040490G	SL060690G	SL080890G	SL101090G	SL121290G	Galvanized Sweep Elbow – 90°
L020290G	L040490G	L060690G	L080890G	L101090G	L121290G	Galvanized Elbow – 90°
L020245G	L040445G	L060645G	L080845G	L101045G	L121245G	Galvanized Elbow – 45°

HS SERIES 2" STRAIGHT SECTION DIMENSIONS			
CATALOG NUMBER	A	B	C
HS221 & HS221NK	12.00 (300)	—	3.00 (75)
HS222 & HS222NK	24.00 (600)	1.00 (25)	7.00 (175)
HS223 & HS223NK	36.00 (900)	2.00 (50)	11.00 (275)
HS224 & HS224NK	48.00 (1200)	3.00 (75)	15.00 (375)
HS225 & HS225NK	60.00 (1500)	4.00 (100)	19.00 (475)
HS226 & HS226NK	72.00 (1800)	5.00 (125)	23.00 (575)
HS2210 & HS2210NK	120.00 (3000)	9.00 (225)	39.00 (975)

NK = No Knockouts

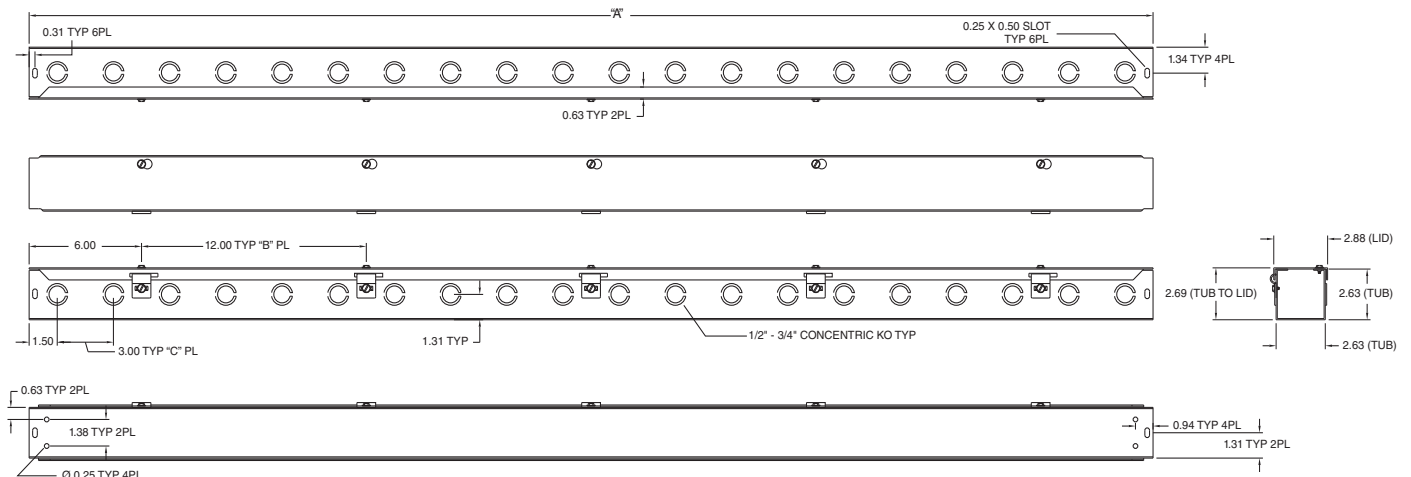

**HS SERIES 2" STRAIGHT SECTION DIMENSIONS**

PART NUMBER	PAGE	PART NUMBER	PAGE	PART NUMBER	PAGE	PART NUMBER	PAGE
NP3624SS	.I4	NP6030G	.C7, C16, D18	P1010G	.C2	PB4BC	.H16-H26
NP3624SSC	.I5	NP6036	.I4	P1206	.I2	PB4S	.H16-H26
NP3630	.I4	NP6036C	.I5	P1206G	.C2	PB4SBC	.H16-H26
NP3630C	.I5	NP6036CG	.D8	P1210	.I2	PB5	.H16-H26
NP3630CG	.D8	NP6036G	.C7, C16, D18	P1210AL	.I2	PB5BC	.H16-H26
NP3630G	.C7, C16, D18	NP6036PP	.B7	P1210G	.C2	PB6	.H16-H26
NP3630PP	.B7	NP6036SS	.I4	P1210SS	.I2	PB6BC	.H16-H26
NP3630SS	.I4	NP6036SSC	.I5	P1212	.I2	PB6VL	.H16-H26
NP3630SSC	.I5	NP7230	.I4	P1212G	.C2	PB6VLBC	.H16-H26
NP3636	.I4	NP7230G	.C7, C16, D18	P1212SS	.I2	PB8	.H16-H26
NP3636C	.I5	NP7236	.I4	P1408	.I2	PB8BC	.H16-H26
NP3636CG	.D8	NP7236G	.C7, C16, D18	P1408G	.C2	PB9	.H16-H26
NP3636G	.C7, C16, D18	NPDD4242	.I7	P1412	.I2	PB9BC	.H16-H26
NP3636PP	.B7	NPDD4242G	.C19, C24	P1412AL	.I2	PBGX1	.H16-H26
NP3636SS	.I4	NPDD4260	.I7	P1412G	.C2	PBGX12	.H16-H26
NP3636SSC	.I5	NPDD4260G	.C19, C24	P1412SS	.I2	PBGX2	.H16-H26
NP3642C	.I5	NPDD4842	.I7	P1610	.I2	PBGX20	.H16-H26
NP3642CG	.D8	NPDD4842G	.C19, C24	P1610G	.C2	PBGX25	.H16-H26
NP4024	.I4	NPDD4848	.I7	P1614	.I2	PBGX3	.H16-H26
NP4024C	.I5	NPDD4848G	.C19, C24	P1614AL	.I2	PBGX4	.H16-H26
NP4024CG	.D8	NPDD5442	.I7	P1614G	.C2	PBGX6	.H16-H26
NP4024G	.C7, C16, D18	NPDD5442G	.C19, C24	P1614SS	.I2	PBGX9	.H16-H26
NP4224	.I4	NPDD6048	.I7	PA0202	.G2	PBSS1	.E2
NP4224G	.C7, C16, D18	NPDD6048G	.C19, C24	PA0202G	.G2	PBSS12	.E2
NP4230	.I4	NPDD6060	.I7	PA0404	.G2	PBSS12A	.E2
NP4230G	.C7, C16, D18	NPDD6060G	.C19, C24	PA0404G	.G2	PBSS1A	.E2
NP4230PP	.B7	NPDD7260	.I7	PA0606	.G2	PBSS2	.E2
NP4230SS	.I4	NPDD7260G	.C19, C24	PA0606G	.G2	PBSS2A	.E2
NP4236	.I4	NPDD7272	.I7	PA0808	.G2	PBSS3	.E2
NP4236C	.I5	NPDD7272G	.C19, C24	PA0808G	.G2	PBSS3A	.E2
NP4236CG	.D8	P0604	.I2	PA1010	.G2	PBSS4	.E2
NP4236G	.C7, C16, D18	P0604AL	.I2	PA1010G	.G2	PBSS4A	.E2
NP4236PP	.B7	P0604G	.C2	PA1212	.G2	PBSS6	.E2
NP4236SS	.I4	P0604SS	.I2	PA1212G	.G2	PBSS6A	.E2
NP4236SSC	.I5	P0606	.I2	PB1	.H16-H26	PBSS9	.E2
NP4824	.I4	P0606AL	.I2	PB10	.H16-H26	PBSS9A	.E2
NP4824C	.I5	P0606G	.C2	PB10BC	.H16-H26	PBXD1	.H16-H26
NP4824CG	.D8	P0606SS	.I2	PB12	.H16-H26	PBXD10	.H16-H26
NP4824G	.C7, C16, D18	P0806	.I2	PB12BC	.H16-H26	PBXD12	.H16-H26
NP4830	.I4	P0806AL	.I2	PB16	.H16-H26	PBXD16	.H16-H26
NP4830G	.C7, C16, D18	P0806G	.C2	PB16BC	.H16-H26	PBXD16SS	.E2
NP4836	.I4	P0806SS	.I2	PB1BC	.H16-H26	PBXD16V	.H16-H26
NP4836C	.I5	P0808	.I2	PB2	.H16-H26	PBXD1SS	.E2
NP4836CG	.D8	P0808G	.C2	PB25	.H16-H26	PBXD2	.H16-H26
NP4836G	.C7, C16, D18	P1008	.I2	PB25BC	.H16-H26	PBXD20	.H16-H26
NP4836PP	.B7	P1008AL	.I2	PB2BC	.H16-H26	PBXD25	.H16-H26
NP4836SS	.I4	P1008G	.C2	PB3	.H16-H26	PBXD2SS	.E2
NP4836SSC	.I5	P1008SS	.I2	PB3BC	.H16-H26	PBXD3	.H16-H26
NP6030	.I4	P1010	.I2	PB4	.H16-H26	PBXD3SS	.E2