



WIDE RANGE GRIPS

N.P.S./N.P.T.* Hub Size	Catalog Number	Cable Diameter Range Inches (cm)	Mesh Length Inches (cm)
½ N.P.S.	BDSR24	.24-.32 (.61-.81)	3¼ (8.25)
½ N.P.S.	BDSR32	.32-.43 (.81-1.09)	3¾ (9.52)
½ N.P.S.	BDSR43	.43-.54 (1.09-1.37)	4¾ (12.06)
¾ N.P.S.	BDSR54	.54-.73 (1.37-1.85)	6½ (16.51)
1 N.P.S.	BDSR73	.73-.97 (1.85-2.46)	7 (17.78)
1¼ N.P.S.	BDSR97	.97-1.25 (2.46-3.17)	9 (22.86)
1½ N.P.T.	BDSR125	1.25-1.50 (3.17-3.81)	11¾ (29.84)
2 N.P.T.	BDSR150	1.50-1.70 (3.81-4.32)	13¼ (33.65)
2½ N.P.T.	BDSR170	1.70-2.00 (4.32-5.08)	13½ (34.29)
2½ N.P.T.	BDSR200	2.00-2.45 (5.08-6.22)	13¾ (34.92)


Note: *N.P.S. = National Pipe Straight; N.P.T. = National Pipe Taper.

Application:

For indoor use only to connect flexible cord or bus drop cables to electrical enclosures; used for preventing cable pullout damage and for controlling arc-of-bend by absorbing tension from terminals

Ideal For Use In:

- Bus drop systems
- Motor connections
- Panel boards
- Internal wiring of machines and cabinets

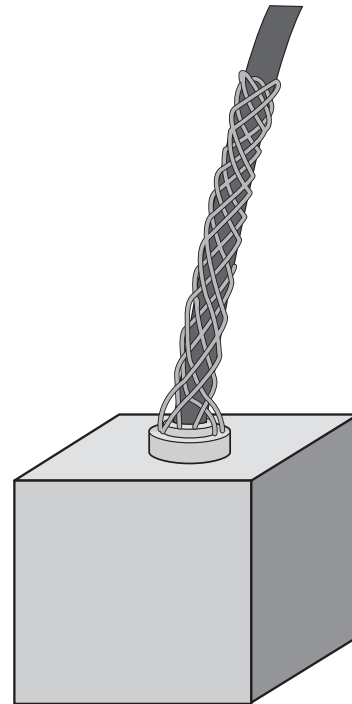

BDSR43

KNOCKOUT HOLES

N.P.S./N.P.T.* Hub Size	Knockout Hole Recommended Min. To Max. Inches (mm)
¼	.54-.57 (13.7-14.5)
⅜	.67-.70 (17.0-17.8)
½	.86-.91 (21.8-23.1)
¾	1.09-1.14 (27.7-29.0)
1"	1.36-1.41 (34.5-35.8)
1¼	1.72-1.77 (43.7-44.9)
1½	1.97-2.02 (50.0-51.3)
2	2.45-2.50 (62.2-63.5)
2½	2.95-3.00 (74.9-76.2)
3	3.58-3.63 (90.9-92.2)

Note: *N.P.S. = National Pipe Straight; N.P.T. = National Pipe Taper.