



**15A 125V**  
 NEMA 5-15R  
 UL CSA  
 0.5 HP







**20A 125V**  
 NEMA 5-20R  
 UL CSA  
 1 HP

## Commercial Specification Grade Receptacles

### Style Line® Decorator

Description	Color	Catalog Number	
Smooth nylon face, Style Line® decorator duplex, back and side wired.	Almond	<b>DR15AL</b>	<b>DR20AL</b>
	Black	<b>DR15BLK</b>	<b>DR20BLK</b>
	Brown	<b>DR15</b>	<b>DR20</b>
	Gray	<b>DR15GRY</b>	<b>DR20GRY</b>
	Ivory	<b>DR15I</b>	<b>DR20I</b>
	Light Almond	<b>DR15LA</b>	<b>DR20LA</b>
	Red	<b>DR15R</b>	<b>DR20R</b>
White	<b>DR15WHI</b>	<b>DR20WHI</b>	
Tamper-Resistant*, Style Line® decorator duplex, smooth nylon face, back and side wired.	Almond	<b>DR15ALTR</b>	<b>DR20ALTR</b>
	Black	<b>DR15BLKTR</b>	<b>DR20BLKTR</b>
	Brown	<b>DR15TR</b>	<b>DR20TR</b>
	Gray	<b>DR15GRYTR</b>	<b>DR20GRYTR</b>
	Ivory	<b>DR15ITR</b>	<b>DR20ITR</b>
	Light Almond	<b>DR15LATR</b>	<b>DR20LATR</b>
White	<b>DR15WHITR</b>	<b>DR20WHITR</b>	
Weather and Tamper-Resistant*, Style Line® decorator duplex, smooth nylon face, back and side wired.	Black	<b>DR15BLKWRTR</b>	<b>DR20BLKWRTR</b>
	Brown	<b>DR15WRTR</b>	<b>DR20WRTR</b>
	Gray	<b>DR15GRYWRTR</b>	<b>DR20GRYWRTR</b>
	Ivory	<b>DR15IWRTR</b>	<b>DR20IWRTR</b>
	Light Almond	<b>DR15LAWRTR</b>	<b>DR20LAWRTR</b>
	White	<b>DR15WHIWRTR</b>	<b>DR20WHIWRTR</b>
Pre-wired receptacles, Style Line® decorator duplex, smooth nylon face, back and side wired, self-grounding, 8" solid wire leads.	Black	<b>DR15BLKP1</b>	<b>DR20BLKP1</b>
	Brown	<b>DR15P1</b>	<b>DR20P1</b>
	Gray	<b>DR15GRYP1</b>	<b>DR20GRYP1</b>
	Ivory	<b>DR15IP1</b>	<b>DR20IP1</b>
	Light Almond	<b>DR15LAP1</b>	<b>DR20LAP1</b>
	White	<b>DR15WHIP1</b>	<b>DR20WHIP1</b>
Pre-wired receptacles, Style Line® decorator duplex, smooth nylon face, back and side wired, self-grounding, 8" stranded wire leads.	Black	<b>DR15BLKP2</b>	<b>DR20BLKP2</b>
	Brown	<b>DR15P2</b>	<b>DR20P2</b>
	Gray	<b>DR15GRYP2</b>	<b>DR20GRYP2</b>
	Ivory	<b>DR15IP2</b>	<b>DR20IP2</b>
	Light Almond	<b>DR15LAP2</b>	<b>DR20LAP2</b>
	White	<b>DR15WHIP2</b>	<b>DR20WHIP2</b>
Pre-wired receptacles, Tamper-Resistant*, Style Line® decorator duplex, smooth nylon face, back and side wired, self-grounding, 8" solid wire leads.	Black	<b>DR15BLKTRP1</b>	<b>DR20BLKTRP1</b>
	Brown	<b>DR15TRP1</b>	<b>DR20TRP1</b>
	Gray	<b>DR15GRYTRP1</b>	<b>DR20GRYTRP1</b>
	Ivory	<b>DR15ITRP1</b>	<b>DR20ITRP1</b>
	Light Almond	<b>DR15LATRP1</b>	<b>DR20LATRP1</b>
	White	<b>DR15WHITRP1</b>	<b>DR20WHITRP1</b>
Pre-wired receptacles, Tamper-Resistant*, Style Line® decorator duplex, smooth nylon face, back and side wired, self-grounding, 8" stranded wire leads.	Black	<b>DR15BLKTRP2</b>	<b>DR20BLKTRP2</b>
	Brown	<b>DR15TRP2</b>	<b>DR20TRP2</b>
	Gray	<b>DR15GRYTRP2</b>	<b>DR20GRYTRP2</b>
	Ivory	<b>DR15ITRP2</b>	<b>DR20ITRP2</b>
	Light Almond	<b>DR15LATRP2</b>	<b>DR20LATRP2</b>
	White	<b>DR15WHITRP2</b>	<b>DR20WHITRP2</b>

Note: \*Tamper-resistant devices are not Fed. Spec. Listed.  
 See page A-46 for accessories.  
 See pages A-58 and A-59 for technical information.  
 See page Tech-10 for Tamper and Weather Resistant descriptions.  
 See section N for wallplates.

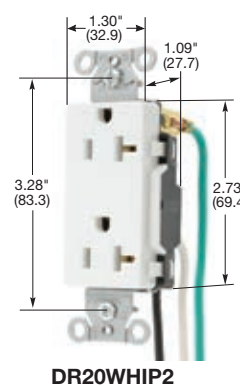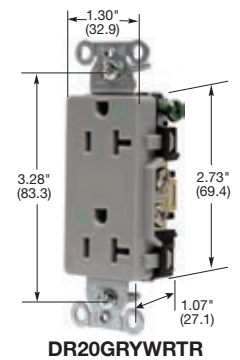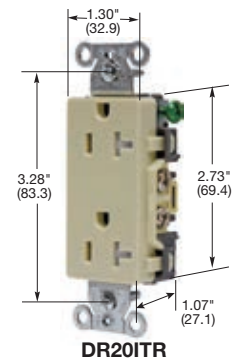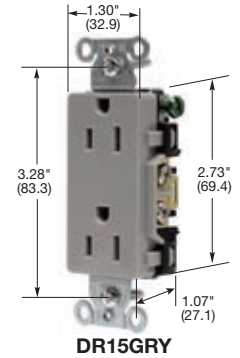

Dimensions in Inches (mm)