


Straight Blade Devices

15 and 20 Ampere, 125 Volts

2 Pole, 3 Wire Grounding

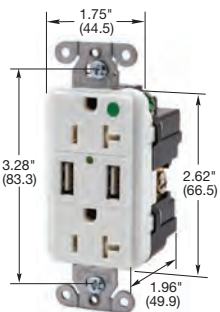

USB8300W



USB Charger Tamper-Resistant Hospital Grade ● Receptacles

USB Charger Tamper-Resistant receptacle, Two USB Type 2.0 ports 3 Amp, 5 Volt DC, 15 or 20 Amp, 125 Volt AC decorator duplex

Color
Black
Brown
Gray
Ivory
Light Almond
Red
White



15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP



Description	Color	15A 125V AC	20A 125V AC
USB Charger Tamper-Resistant receptacle, Two USB Type 2.0 ports 3 Amp, 5 Volt DC, 15 or 20 Amp, 125 Volt AC decorator duplex	Black	USB8200BK	USB8300BK
	Brown	USB8200	USB8300
	Gray	USB8200GY	USB8300GY
	Ivory	USB8200I	USB8300I
	Light Almond	USB8200LA	USB8300LA
	Red	USB8200R	USB8300R
	White	USB8200W	USB8300W

Note: See page A-18 for additional information on standard USB charger.
See page A-56 for technical information.
See page Tech-10 for Tamper-Resistant description.

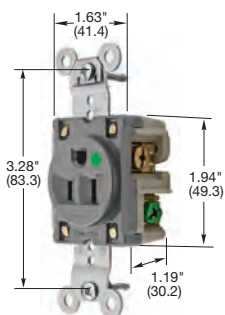

HBL8210GY

IP20
SUITABILITY

HBL® Extra Heavy Duty Hospital Grade ● Single Receptacles

Flush, nylon face, back and side wired, Fed. Spec. verified.

Color
Almond
Brown
Gray
Ivory
Red
White




15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

Description	Color	Catalog Number	
Flush, nylon face, back and side wired, Fed. Spec. verified.	Almond	-	HBL8310AL
	Brown	HBL8210	HBL8310
	Gray	HBL8210GY	HBL8310GY
	Ivory	HBL8210I	HBL8310I
	Red	HBL8210R	HBL8310R
	White	HBL8210W	HBL8310W
	Panel mount on 1.94 in. (49.2) centers.	Brown	HBL8284
	Ivory	HBL8284I	HBL8384I
Isolated ground ^A .	Orange	IG8210	IG8310

Note: ^ASee section M for additional information on isolated ground devices.

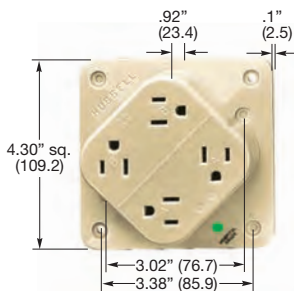

HBL415HI

4-PLEX® Hospital Grade ● Receptacles

4 outlet high impact resistant Polycarbonate construction. Mount to 4 in. square box.

Color
Brown
Gray
Ivory
Red
White




15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

Description	Color	Catalog Number	
4 outlet high impact resistant Polycarbonate construction. Mount to 4 in. square box.	Brown	HBL415H	HBL420H
	Gray	-	HBL420HG
	Ivory	HBL415HI	HBL420HI
	Red	HBL415HR	HBL420HR
	White	HBL415HW	HBL420HW
4-PLEX adapter plates for 1- and 2-gang, device boxes.	Brown	HBL4AP	HBL4AP
	Gray	HBL4APGY	HBL4APGY
	Ivory	HBL4API	HBL4API
	Red	HBL4APR	HBL4APR
	White	HBL4APW	HBL4APW

Note: See page A-23 for additional information on 4-PLEX devices.
See page A-60 for technical information.
4-PLEX devices are not Fed. Spec. Listed.

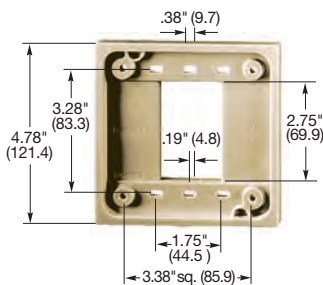

HBL4API

Dimensions in Inches (mm)