



## AMO - Advanced Multimedia Outlet Housing


AMO is our largest capacity surface mount housing accommodating 12 copper or 12/24 fiber connections.

Excellent as a MUTOA.

Downward orientation.

Hidden label field beneath cover.

Compatible with **MEDIATRAK®**: MT2, MT7 and MT8.

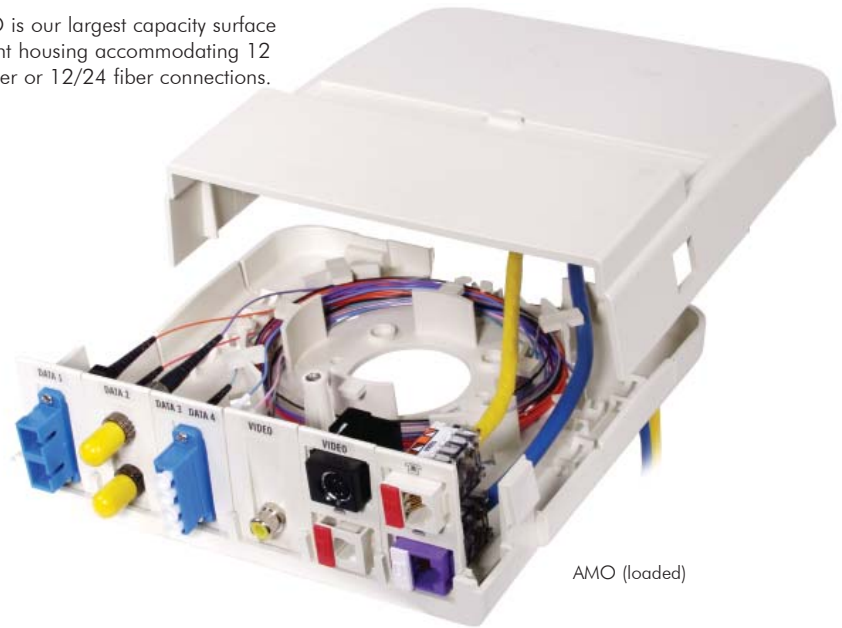

AMO (loaded)

### FEATURES

- Compatible with UTP, STP, Coax and Fiber.
- Fiber storage drum to protect bend radius of fiber.
- Label field hidden beneath cover: MUTOA labeling compliant.
- Overhead shroud protects connectors.
- Durable yet attractive housing with securable features.

The Advanced Multimedia Outlet (AMO) is a high-capacity, low-profile, multimedia surface housing capable of supporting up to 12 copper/fiber connectors or 24 small form factor LC connectors. The AMO may be used as a multi-user telecommunications outlet assembly (MUTOA) as specified in TIA/EIA-TSB-75. The AMO provides fiber storage supporting up to 1m of buffered fiber.

### SPECIFICATIONS


- ◆ Listed under UL File #E129878.
- ◆ CSA certified file #LR80837.
- ◆ High-impact housing: UL 94V-0 rated thermoplastic.
- ◆ AMO dimensions: 7.15"W (181) x 7.53"H (191) x 2.3"D (58).

### TSB-75 Additional Horizontal Cabling Practices for Open Offices

#### The Multi-User Telecommunications Outlet Assembly (MUTOA)

- ◆ Houses several telecommunications outlets/connectors for several work areas in one location.
- ◆ Solid conductor 4-pair UTP cables or fiber optic cables are run from the telecom room (TR) to the MUTOA and terminated.
- ◆ MUTOA is permanently mounted in or on a building structure that is in close proximity to a furniture cluster or open area.
- ◆ Work area cables extend from the MUTOA through the furniture raceways.
- ◆ Work area cables are made of stranded conductor cable, terminated with modular plugs on both ends.
- ◆ Work area cables connecting the MUTOA to the work area equipment must be labeled on both ends.
- ◆ MUTOA should serve a maximum of 6-12 work areas.

### MUTOA Solution

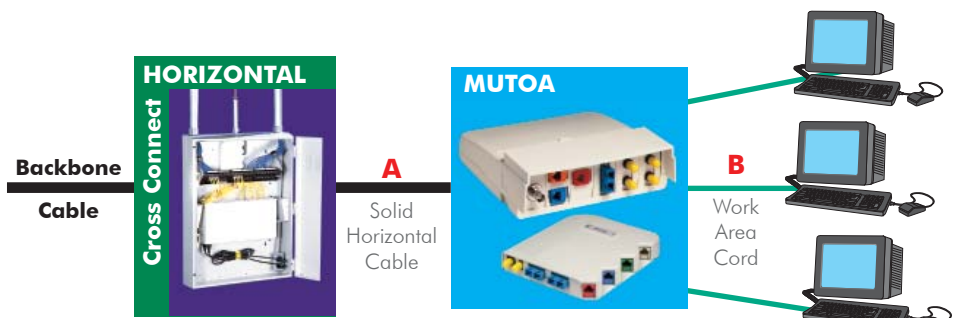

A
Horizontal Cable Maximum Length
90 meters/295 ft.
85 meters/279 ft.
80 meters/262 ft.
75 meters/246 ft.
70 meters/230 ft.


B
Work Area Cord Maximum Length
3 meters/9.8 ft.
7 meters/23 ft.
11 meters/36 ft.
15 meters/49 ft.
20 meters/66 ft.



**Order Information**


**AMO BASE UNIT HOUSING**

Description	Catalog No.
Office White with 6 bracket locations.	<b>AMO</b>

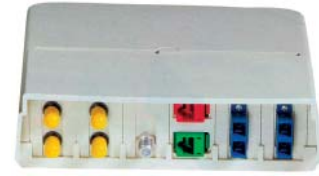

**AMO ADAPTER BRACKETS**


Description	Catalog No.
Blank adapter bracket.	<b>AMOBBN10*</b>
BNC adapter bracket. 1/2" opening.	<b>AMOBL10*</b>
F-style adapter bracket. 3/8" opening.	<b>AMOFB10*</b>
LC Quad adapter bracket. Includes 1 LC Quad adapter.	<b>AMOLCQ</b>
RCA Solder-type adapter bracket. 1/4" opening.	<b>AMOBRC10*</b>
SC adapter bracket. Includes 1 duplex MM/SM SC adapter.	<b>AMOBSCD</b>
ST-style adapter bracket. Includes 2 MM/SM ST-style adapters.	<b>AMOBST2</b>
<b>XCELERATOR™</b> Jack single adapter bracket.	<b>AMOBJ10*</b>
<b>XCELERATOR</b> Jack dual adapter bracket.	<b>AMOB2J10*</b>

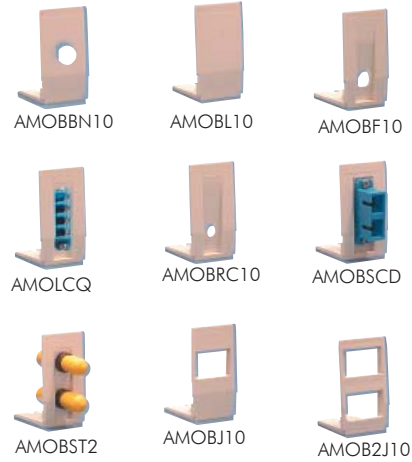

See page B8-B11 in the Full Line Catalog for more Audio/Video connector options.

**Hlabel** HUBBELL Compatible with **Hubbell Labeling System** - see page B56 in the Full Line Catalog.

**DIMENSIONS**

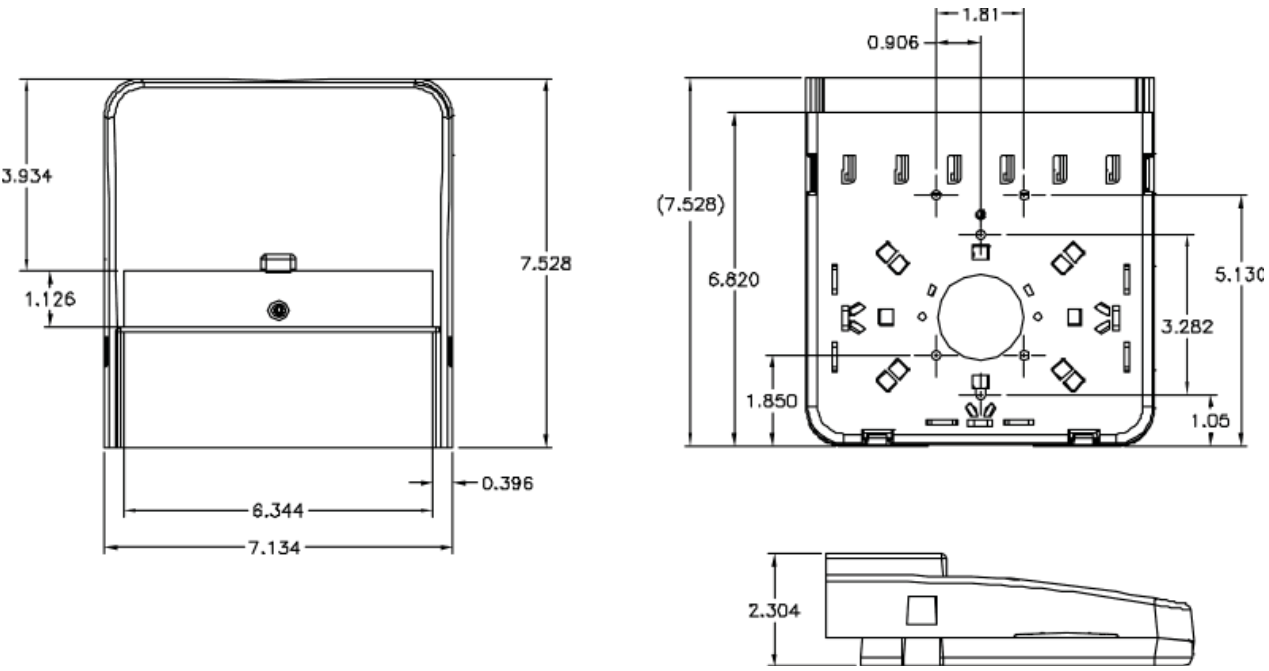

**Hubbell Premise Wiring**  
 HUBBELL INCORPORATED (Delaware)  
 14 Lord's Hill Road • Stonington, CT 06378-0901 • (860) 535-8326 • 800-626-0005  
 Fax: (860) 535-8328 • Internet site: <http://www.hubbell-premise.com>

**Worldwide Locations**

Hubbell Premise Wiring, Asia Pacific	852-2836-7131	Fax: 852-2836-7132	Hubbell Premise Wiring, Latin America	305-408-4501	Fax: 305-408-8201
Hubbell Canada Inc.	905-839-1138	Fax: 905-839-9108	Hubbell de Mexico, S.A. de C.V.	(5255) 9151-9999	Fax: (5255) 9151-9989
Hubbell Premise Wiring, Central America	506-309-4158	Fax: 506-260-1616	Hubbell Premise Wiring, Middle East	971-4-393-4192	Fax: 971-4-393-4194
Hubbell Premise Wiring, China	8621-6309-0119	Fax: 8621-6309-0122	Hubbell-Taian Co., Ltd., Taiwan	886-2-2522-1862	Fax: 886-2-2522-1872
Hubbell Premise Wiring, Colombia	571-245-8940	Fax: 571-340-0925	Hubbell Premise Wiring, Turkey	90-216-313-5016	Fax: 90-216-414-8148
Hubbell Premise Wiring, Europe	44-01283 500500	Fax: 44-01283 500400	Hubbell Premise Wiring, Venezuela	58-416-680-7453	Fax: 58-281-274-7900
Hubbell Int'l. Inc., Korea Branch	82-2-(0)2607-1363	Fax: 82-2-(0)2603-7386			