

Aluminum Service Poles



Aluminum Series Offering



HBLPP10AI



HBLPP10IGA

HBLPP10SAI




HBLPP10GFW



ATB



PPTRIM1

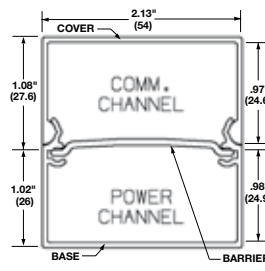

Three Service Aluminum Service Poles

Height Feet (m)

Description	Color	10' 2" (3.10m)	12' 2" (3.71m)	15' 2" (4.62m)
(2) 20A 125V Style Line® duplex receptacles; one circuit	Black	HBLPP10BK	HBLPP12BK	HBLPP15BK
	Gray	HBLPP10A	HBLPP12A	HBLPP15A
	Ivory	HBLPP10AI	HBLPP12AI	HBLPP15AI
	Office White	HBLPP10OW	HBLPP12OW	HBLPP15OW
	White	HBLPP10W	HBLPP12W	HBLPP15W
	Clear Anodized Aluminum	HBLPP10AAL	HBLPP12AAL	HBLPP15AAL
(1) Orange isolated ground 20A 125V Style Line® duplex receptacle; (1) 20A 125V Style Line® duplex receptacle; two circuits	Black	HBLPP10IGBK	—	—
	Gray	HBLPP10IGA	—	—
	Ivory	HBLPP10IGAI	—	—
	Office White	HBLPP10IGOW	—	—
	White	HBLPP10IGW	—	—
	Clear Anodized Aluminum	HBLPP10IGAL	—	—
(2) Orange isolated ground 20A 125V Style Line® duplex receptacles; (1) isolated ground surge suppression 20A 125V duplex receptacle; one circuit	Black	HBLPP10SBK	—	—
	Gray	HBLPP10SA	—	—
	Ivory	HBLPP10SAI	—	—
	Office White	HBLPP10SOW	—	—
	White	HBLPP10SW	—	—
	Clear Anodized Aluminum	HBLPP10SAL	—	—
(1) 20A 125V GFCI Self Test duplex receptacle with (2) ground fault protected 20A 125V Style Line® duplex receptacles; one circuit	Black	HBLPP10GFBK	HBLPP12GFBK	HBLPP15GFBK
	Gray	HBLPP10GF	HBLPP12GF	HBLPP15GF
	Ivory	HBLPP10GFI	HBLPP12GFI	HBLPP15GFI
	Office White	HBLPP10GFW	HBLPP12GFW	HBLPP15GFW
	White	HBLPP10GFW	HBLPP12GFW	HBLPP15GFW
	Clear Anodized Aluminum	HBLPP10GFAL	HBLPP12GFAL	HBLPP15GFAL
Blank pole; divider; (4) Style Line® device knockouts	Black	HBLPPOBK	HBLPPO12BK	HBLPPO15BK
	Gray	HBLPPOA	HBLPPO12A	HBLPPO15A
	Ivory	HBLPPOAI	HBLPPO12AI	HBLPPO15AI
	Office White	HBLPPOOW	HBLPPO12OW	HBLPPO15OW
	White	HBLPPOW	HBLPPO12W	HBLPPO15W
	Clear Anodized Aluminum	HBLPPOAAL	HBLPPO12AAL	HBLPPO15AAL

Accessories

Description	Catalog Number
Adjustable T-bar assembly for mounting poles in the middle of ceiling tile.	ATB*
Replacement service pole trim kit (office white).	PPTRIM1*

Note: * Not UL listed.

Dimensions

