

Ground Fault Devices


Heavy Duty GFCI Receptacles with Auto Grounding



10kA Short Circuit Current Rating

When test button is actuated, both the electronic components and mechanical trip mechanism are functionally tested

Open circuit condition eliminates false assumption of protection at face

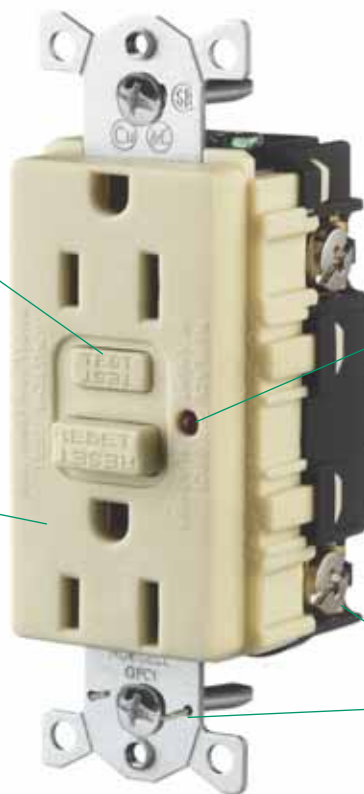

Rapid-flashing **RED** indicates device has lost capability to provide ground fault protection

Internal back wiring; automatic grounding features; captive mounting screws

GF15ILA

HOSPITAL GRADE ● GFCI RECEPTACLES



GF82OWLA

| Description | Color | Catalog Number | |
|-----------------------------------------------------------------------------------------------------------------------|--------------|-----------------|-----------------|
| Hospital grade; flush; nylon face; brass bridge; back and side wired; multiple drive screws; automatic grounding clip | Almond | GF82ALLA | GF83ALLA |
| | Black | GF82BKLA | GF83BKLA |
| | Brown | GF82LA | GF83LA |
| | Gray | GF82GYLA | GF83GYLA |
| | Ivory | GF82ILA | GF83ILA |
| | Light Almond | GF82LALA | GF83LALA |
| | Office White | GF82OWLA | GF83OWLA |
| | Red | GF82RLA | GF83RLA |
| | White | GF82WLA | GF83WLA |

COMMERCIAL GFCI RECEPTACLES



GF15ILA

| Description | Color | Catalog Number | |
|-----------------------------------------------------------------------------------------|--------------|-----------------|-----------------|
| Flush; nylon face; back and side wired; multiple drive screws; automatic grounding clip | Almond | GF15ALLA | GF20ALLA |
| | Black | GF15BKLA | GF20BKLA |
| | Brown | GF15LA | GF20LA |
| | Gray | GF15GYLA | GF20GYLA |
| | Ivory | GF15ILA | GF20ILA |
| | Light Almond | GF15LALA | GF20LALA |
| | Office White | GF15OWLA | GF20OWLA |
| | Red | GF15RLA | GF20RLA |
| | White | GF15WLA | GF20WLA |

Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles listed above are furnished with a matching color nylon wallplate. 20 amp feedthrough capability.