






# Hubbell<sup>®</sup> Devices

## 30 Ampere, 600 and 480 Volts AC, 20 Ampere, 250 Volts DC

3 Pole, 4 Wire Grounding and 4 Pole, 5 Wire Grounding Connector Bodies and Receptacles

   **IP30**  
SUITABILITY




### Connector Bodies

| Description                                  | Cord Dia.                    | Catalog Number     |                  |                  |
|--|------------------------------|--------------------|------------------|------------------|
| Black nylon housing, thermoplastic interior. | .700"-1.200"<br>(17.78-30.5) | <b>HBL21414B</b>   | -                | -                |
| Same as above except corrosion resistant.    | .700"-1.200"<br>(17.78-30.5) | <b>HBL21CM414B</b> | -                | -                |
| Red nylon housing, thermoset interior.       | .700"-1.200"<br>(17.78-30.5) | -                  | <b>HBL20444B</b> | -                |
| Black nylon housing, thermoplastic interior. | .700"-1.200"<br>(17.78-30.5) | -                  | -                | <b>HBL25414B</b> |

Accessories on page B-68.



**HBL21414B**

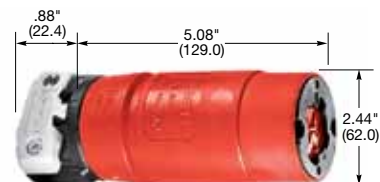

**HBL20444B**




**HBL25414B**


### Receptacles

| Description   | Catalog Number    |                 |                 |
|---|-------------------|-----------------|-----------------|
| Black phenolic.   | <b>HBL20403</b>   | -               | -               |
| Weathertight, corrosion resistant, nickel plated brass plate, for FS/FD box mounting. <b>IP44</b> SUITABILITY.        | <b>HBL22CM427</b> | -               | -               |
| Aluminum angle housing, with 3/4" hub for surface mounting. <b>IP44</b> SUITABILITY.                                  | <b>HBL21420</b>   | -               | -               |
| Black phenolic, red center insert.  | -                 | <b>HBL20443</b> | -               |
| Black phenolic interior, aluminum housing, blue finish, for FS/FD box mounting.                                       | -                 | -               | <b>HBL25403</b> |
| Black phenolic interior, aluminum weatherproof housing, blue finish, for FS/FD box mounting. <b>IP44</b> SUITABILITY. | -                 | -               | <b>HBL25250</b> |


Accessories on page B-68.

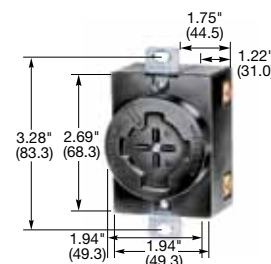

**HBL20403**

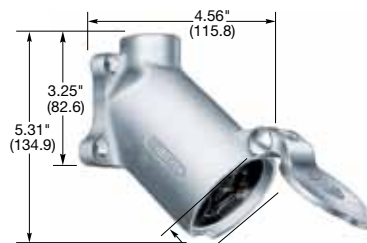

**HBL21420**

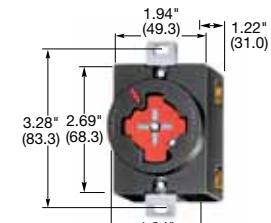


**HBL20443**

### Receptacle Accessories


| Description   | Catalog Number     |
|---|--------------------|
| Thermoplastic, WET LOCATIONS with cover "open," gray.   | <b>HBL7428WOG*</b> |
| Thermoplastic, WET LOCATIONS with cover "open," yellow. | <b>HBL7428WOY*</b> |
| Thermoplastic, WET LOCATIONS with cover "open," red.    | <b>HBL7428WOR*</b> |
| Cast aluminum weatherproof, lift cover plate.           | <b>HBL20405</b>    |
| Cast aluminum, weatherproof, red finish.                | <b>HBL20446</b>    |
| 302/304 stainless, single gang, smooth.                 | <b>SS737</b>       |

Note: \* Features two #6-32 threaded inserts to back mount device to cover.

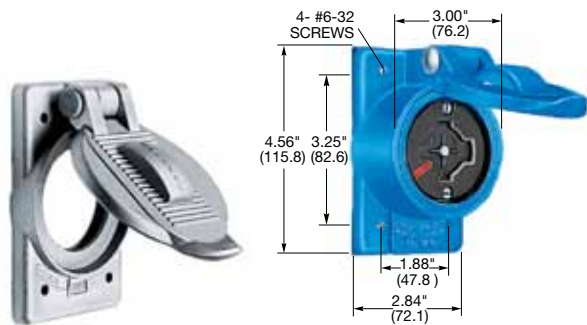

**HBL20405**

**HBL25250**

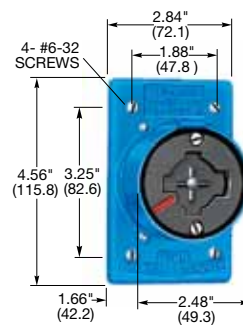

**HBL25403**

