

Twist-Lock® Devices

30 Ampere, 125, 250 Volts and 277 Volts AC

2 Pole, 3 Wire Grounding

Insulgrip® Connector Bodies and Receptacles



30A 125V
NEMA L5-30R
UL/CSA
2 HP



30A 250V
NEMA L6-30R
UL/CSA
2 HP



30A 277V AC
NEMA L7-30R
UL/CSA
3 HP

Connector Bodies

Watertight Safety-Shroud®		IP66 SUITABILITY		
Description	Cord Dia.	Catalog Number		
Black Valox® housing, white Valox® clamps.	.360"-.930" (9-24)	HBL2613SW	HBL2623SW	-
Insulgrip®		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Number		
Black and white nylon.	.360"-.930" (9-24)	HBL2613	HBL2623	HBL2633
Heat stabilized, gray nylon, 220° F (104° C).	.360"-.930" (9-24)	HBL2613F	HBL2623F	-
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	HBL26CM13	HBL26CM23	-
All black nylon.	.360"-.930" (9-24)	HBL2613BK	HBL2623BK	-

Accessories on page B-51.

Valise®		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Number		
Yellow nylon.	.590"-.930" (15.0-23.6)	HBL2613VY	HBL2623VY	-
Corrosion resistant, yellow nylon.	.590"-.930" (15.0-23.6)	HBL26CM13V	-	-
Black nylon.	.590"-.930" (15.0-23.6)	HBL2613VBK	HBL2623VBK	-

Accessories on page B-51.

Receptacles

Watertight Safety-Shroud®, Back Wired		IP66 SUITABILITY		
Description	Catalog Number			
Gray Valox® housing and flange.	HBL2610SW	HBL2620SW	-	

Accessories on page B-54.

Safety-Shroud® Twist-Lock®, Back Wired		IP20 SUITABILITY		
Description	Catalog Number			
Gray Valox® angle housing, one gang.	HBL2610AR	HBL2620AR	-	
Gray Valox® surface mounting, one gang.	HBL2610SR	HBL2620SR	-	
Gray Valox® semi-flush, two gang.	HBL2610SR2	HBL2620SR2	-	

Accessories on page B-54.

Single Flush, Back and Side Wired		IP20 SUITABILITY		
Description	Catalog Number			
Black nylon face.	HBL2610	HBL2620	HBL2630	
Blue nylon face.	HBL2610M6	HBL2620M6	-	
Isolated ground, orange nylon face.	IG2610	IG2620	-	
Corrosion resistant, yellow nylon face.	HBL26CM10	HBL26CM20	-	
Ring terminal connection.	HBL2610RT	HBL2620RT	-	

Accessories on page B-50.

Insulgrip® Flanged Receptacles

Description	Catalog Number		
Nylon casing, back wired.	HBL2616	HBL2626	HBL2636
Heat stabilized, gray nylon, 220° F (104° C).	HBL2616F	HBL2626F	-


Accessories on page B-50.



HBL2613SW



HBL2623

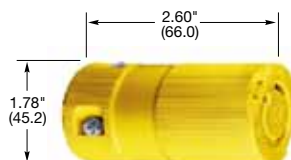


HBL2613VY



HBL2610SW



HBL2620AR

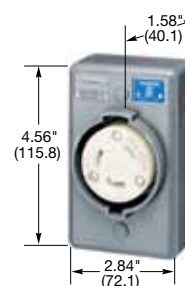

HBL2620SR

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.

