



Twist-Lock® Devices

15 Ampere, 125, 250 Volts and 277 Volts AC

2 Pole, 3 Wire Grounding

Insulgrip® Connector Bodies and Receptacles

IP20
SUITABILITY



Connector Bodies

Description	Cord Dia.	125V	250V	277V AC
Insulgrip connector body, black and white nylon. Multiple drive screws.	.230"-.720" (5.8-18.3)	HBL4729C	HBL4579C	HBL4779C
All black nylon.	.230"-.720" (5.8-18.3)	HBL4729CBK	-	-
Insulgrip connector body, 8 position angle, black and white nylon. Multiple drive screws.	.325"-.655" (8.3-16.6)	HBL4729CA	-	-
Insulgrip connector body, corrosion resistant, yellow and white nylon. Multiple drive screws.	.230"-.720" (5.8-18.3)	HBL47CM29C	HBL45CM79C	HBL47CM79C
Elastogrip connector body, yellow elastomer, dust tight.	.300"-.655" (7.6-16.6)	HBL2547	-	-
Elastogrip® connector body, yellow elastomer, water/dust tight.	.300"-.655" (7.6-16.6)	HBL25W47**	-	-
Valise® connector body, yellow nylon.	.220"-.660" (5.6-16.8)	HBL4729VY	HBL4579VY	HBL4779VY
Valise® connector body, black nylon.	.220"-.660" (5.6-16.8)	HBL4729VBK	HBL4579VBK	HBL4779VBK

Accessories on page B-49.



HBL4729C



HBL25W47




HBL4729VY


Receptacles, Back and Side Wired

Description	125V	250V	277V AC
Duplex, flush, brown RTP face.	HBL4700*	HBL4550*	HBL4750*
Duplex, flush, ivory RTP face.	HBL4700I*	-	-
Duplex, ring terminal connection.	HBL4700RT*	HBL4550RT*	-
Duplex, isolated ground, flush, orange RTP face.	IG4700A*	IG4550A*	-
Duplex, corrosion resistant, yellow RTP face.	HBL47CM00*	-	-
Single, flush, black nylon face.	HBL4710	HBL4560	HBL4760
Same as HBL4760 without mounting screws, ears. Terminal screws backed out.	-	-	HBL4760C
Single, ring terminal connection.	HBL4710RT	HBL4560RT	-
Single, isolated ground, flush, orange nylon face.	IG4710	IG4560	-
Single, black nylon face mounted on a 4" (101.6) round box cover.	HBL4711	-	HBL4761
Single, panel mount, black nylon face, side wired only, 1.75" or 1.937" (44.5 or 49.2) mounting centers.	HBL4713	HBL4563	HBL4763

Accessories on pages B-48 and B-49.

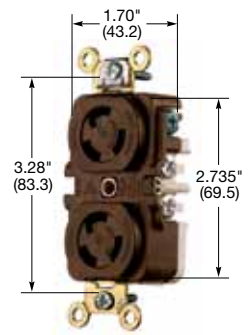

HBL4700

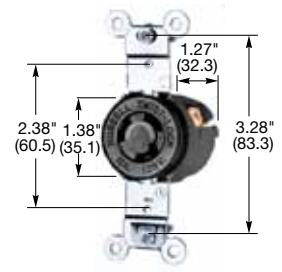

HBL4710

Flanged Receptacles

Description	125V	250V	277V AC
Insulgrip flanged receptacle, nylon casing, back wired.	HBL4715C	HBL4585C	HBL4785C
Stainless steel casing, brown phenolic.	HBL4715	HBL4585	HBL4785
Corrosion resistant, stainless steel casing, yellow melamine.	HBL47CM15	-	-

Accessories on pages B-48 and B-49.

Note: HP ratings are AC only.

RTP is an abbreviation for reinforced thermoplastic polyester.


See Section J for full line of isolated ground devices.

* Supplied with break-off tabs for split circuit wiring.

** Watertight connector body IP55 suitability when closure plug inserted or when installed and used properly with watertight plug.



HBL4715

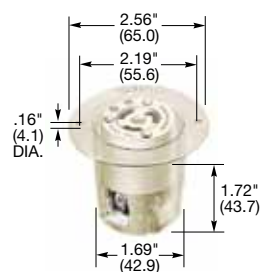

HBL4715C

