

Straight Blade Devices

15 and 20 Ampere, 125 Volts

2 Pole, 3 Wire Grounding


HBL® Extra Heavy Duty, Specification Grade, Weather-Resistant, Single and Special Purpose Receptacles




15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP

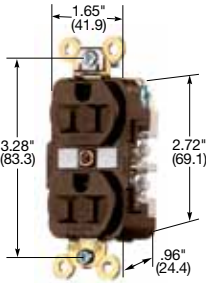


HBL5262

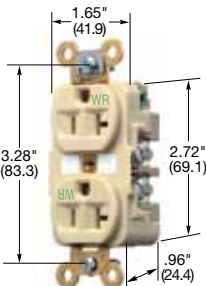

HBL5362IWR

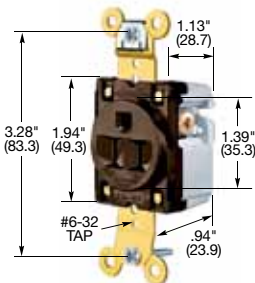

HBL5261

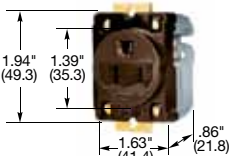

HBL5284

Receptacles

HBL® Extra Heavy Duty, Specification Grade, Duplex

Description	Color	Catalog Number	Catalog Number
Flush, nylon face, back and side wired, multiple drive screws.	Black	HBL5262BK	HBL5362BK
	Blue	-	HBL5362BL
	Brown	HBL5262	HBL5362
	Gray	HBL5262GY	HBL5362GY
	Ivory	HBL5262I	HBL5362I
	Red	HBL5262R	HBL5362R
	White	HBL5262W	HBL5362W
Isolated ground. ⁽¹⁾	Gray	IG5262GY	IG5362GY
	Ivory	IG5262I	IG5362I
	Orange	IG5262	IG5362
	Red	IG5262R	IG5362R
	White	-	IG5362W
Non-isolated ground, bulk pack of 100.	Orange	-	HBL5362M4
Weather-Resistant, flush, nylon face, back and side wired, multiple drive screws.	Black	HBL5262BKWR	HBL5362BKWR
	Brown	HBL5262WR	HBL5362WR
	Gray	HBL5262GYWR	HBL5362GYWR
	Ivory	HBL5262IWR	HBL5362IWR
	Red	HBL5262RWR	HBL5362RWR
Corrosion resistant.	Ivory	HBL52CM62I	-
	Yellow	HBL52CM62	HBL53CM62
Weather-Resistant, Isolated ground. ⁽¹⁾	Gray	IG5262GYWR	IG5362GYWR
	Ivory	IG5262IWR	IG5362IWR
	Orange	IG5262WR	IG5362WR
	Red	IG5262RWR	IG5362RWR
	White	-	IG5362WWR
On 4 in. (101.6) round cover.	Brown	HBL5282	-



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

HBL® Extra Heavy Duty, Specification Grade, Single

Description	Color	Catalog Number	Catalog Number
Flush, nylon face, back and side wired, multiple drive screws.	Black	HBL5261BK	HBL5361BK
	Brown	HBL5261	HBL5361
	Gray	-	HBL5361GRY
	Ivory	HBL5261I	HBL5361I
	White	-	HBL5361W
Isolated ground. ⁽¹⁾	Orange	IG5261	IG5361
Weather-Resistant, Isolated ground. ⁽¹⁾	Orange	IG5261WR	IG5361WR
	Orange	IG5261WR	IG5361WR
Ring terminal connection.	Brown	HBL5261RT	HBL5361RT
Weather-Resistant, flush, nylon face, back and side wired, multiple drive screws.	White	HBL5261WRT	-
	Yellow	HBL5261YRT	-
	Brown	HBL5261WR	HBL5361WR
Corrosion resistant.	Gray	HBL5261GYWR	HBL5361GYWR
	Ivory	HBL5261IWR	HBL5361IWR
Panel mount on 1.94 in. (49.3) centers.	Yellow	HBL52CM61	HBL53CM61
	Brown	HBL5284	HBL5357

Note: (1) See Section J for complete line of isolated ground devices.
See page A-15 for NEC® Tamper and Weather-Resistant Code Requirements.
See pages A-46 and A-47 for accessories.
See Section K for wallplates.