



Straight Blade Devices

20 Ampere, 125/250 Volts and 3Ø 250 Volts AC

3 Pole, 3 Wire Non-Grounding; 3 Pole, 4 Wire Grounding; 4 Pole 4 Wire Non-Grounding

Receptacles and Plugs



20A, 125/250V 3 Pole, 3 Wire Non-Grounding Receptacles and Plugs

IP20
SUITABILITY




20A 125V/250V
NEMA 10-20R
UL Listed
2(1) HP



20A 125V/250V
NEMA 10-20P
UL Listed
2(1) HP

Description	Cord Diameter	Catalog Number	
Receptacle, black phenolic.	-	HBL6810	-
Plug, Insulgrip®, nylon.	.385"-.780" (9.8-19.8)	-	HBL9977C

Note: Horsepower ratings listed above are AC only.
Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).
Those in parentheses are phase to neutral (120V AC).
See pages A-46 and A-47 for accessories.

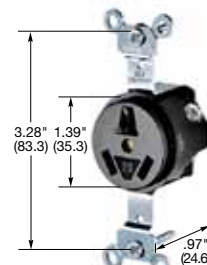

HBL6810



HBL9977C



20A, 125/250V 3 Pole, 4 Wire Grounding Receptacles and Plugs

IP20
SUITABILITY




20A 125V/250V
NEMA 14-20R
UL CSA
2(1) HP




20A 125V/250V
NEMA 14-20P
UL CSA
2(1) HP

Description	Cord Diameter	Catalog Number	
Receptacle, black nylon body, back and side wired.	-	HBL8410	-
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	-	HBL8411C

Note: See pages A-46 and A-47 for accessories.

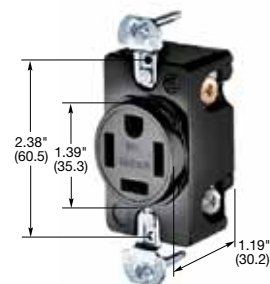

HBL8410

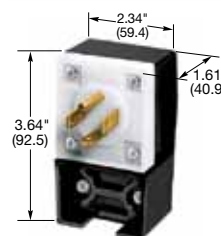

HBL8411C



20A, 3Ø 250V AC 3 Pole, 4 Wire Grounding Receptacles and Plugs

IP20
SUITABILITY




20A 3Ø 250V AC
NEMA 15-20R
UL CSA
3 HP



20A 3Ø 250V AC
NEMA 15-20P
UL CSA
3 HP

Description	Cord Diameter	Catalog Number	
Receptacle, black nylon body, back and side wired.	-	HBL8420	-
Plug, nylon, angle 4-position.	.390"-.775" (9.9-19.7)	-	HBL8421C

Note: Horsepower ratings listed above are AC only.
Horsepower ratings not in parentheses are phase to phase (208 to 240V AC).
Horsepower ratings in parentheses are phase to neutral (120V AC).
See pages A-46 and A-47 for accessories.

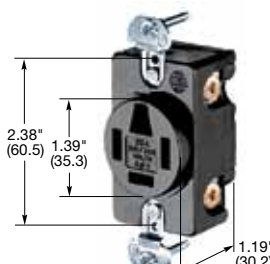

HBL8420



HBL8421C



20A, 3ØY 120/208V AC 4 Pole, 4 Wire Non-Grounding Receptacles and Plugs

IP20
SUITABILITY



20A 3ØY 120/208V AC
NEMA 18-20R
UL Listed
2 HP



20A 3ØY 120/208V AC
NEMA 18-20P
UL Listed
2 HP

Description	Cord Diameter	Catalog Number	
Receptacle, black nylon body.	-	HBL7250	-
Plug, nylon, angle, 4-position.	.390"-.775" (9.9-19.7)	-	HBL7251C

Note: Horsepower ratings are phase to phase (208 to 240V AC).
Weatherproof boots for plugs not available.
See pages A-46 and A-47 for accessories.