


## METAL LOW PROFILE IN-USE COVERS

- Superior Commercial Quality Die-Cast Metal Construction
- Patented Quick-Fit™ Keyhole Mounting System Allows Installation in Under a Minute
- Patented Universal-Fit™ Technology
- Mounting Hardware, Gasket and Installation Instructions Included
- Meets or Exceeds Extra Duty Specifications
- Lockable Open or Closed
- **UL LISTED** & 2011 NEC® Compliant
- **NEMA 3R** Compliant

Meets or Exceeds  
**EXTRA-DUTY**  
Specifications!




**8 in 1**

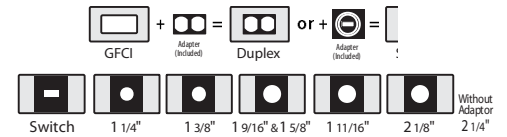

### CONFIGURATIONS

 
**8 in 1**



### CONFIGURATIONS



 
**8 in 1**



### CONFIGURATIONS

**55 in 1**

### CONFIGURATIONS

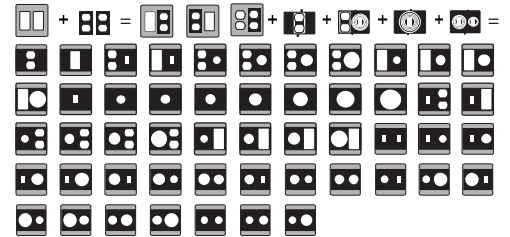

Multiple combinations of duplex, GFCI, switch, and rounds:  
1 1/4", 1 3/8", 1 9/16", 1 5/8", 1 11/16", 2 1/8", 2 1/4", 2 7/16"

TAYMAC ITEM #	UPC NUMBER	DESCRIPTION	DEPTH	COLOR	SHELF PACK	SHELF PACK WEIGHT (LBS)
<b>Metal Low Profile In-Use Covers</b>						
MX4280S	0-92326-10128-8	Vertical 8-in-1	2"	Gray	6	4.75
MX4280WH	0-92326-11740-1	Vertical 8-in-1	2"	White	6	4.75
MX4280Z	0-92326-11739-5	Vertical 8-in-1	2"	Bronze	6	4.75
MX4380S	0-92326-10134-9	Horizontal 8-in-1	2"	Gray	3	2.53
MX5280S	0-92326-10135-6	Vertical Deep 8-in-1	2.5"	Gray	2	1.80
MX7280S	0-92326-10137-0	Vertical 2-Gang 55-in-1	2"	Gray	2	2.35