

EMT FITTINGS

STEEL COMBINATION COUPLINGS

Application


- Use RACO® Cat. Nos. 1432-1434 when coupling unthreaded rigid/IMC to EMT

Product Features

- Rugged metallic construction insures mechanical protection
- All steel components are zinc electro plated for corrosion protection
- UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code and packaged in pre-scored tear top cartons for an attractive presentation



EMT – Rigid Couplings Set Screw
Steel

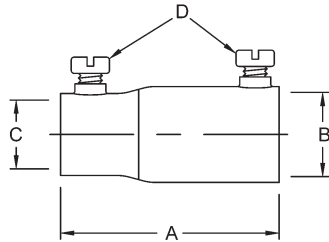

A = Overall length
B = I.D. rigid side
C = I.D. EMT side
D = Screw spec

RACO COMMERCIAL FITTINGS

ORDERING INFORMATION - DIMENSIONS

EMT – RIGID COUPLINGS SET SCREW - STEEL				
CATALOG NUMBER	TRADE SIZE	UNIT CTN. QTY.	SHIP CTN. QTY.	UPC BAR CODE
1432	1/2"	—	25	—
1432-8	1/2"	1	25	
1433	3/4"	—	25	—
1433-8	3/4"	1	15	
1434	1"	—	25	—
1434-8	1"	1	15	

DIMENSIONS				
CATALOG NUMBER	A	B	C	D
1432	2-13/64"	55/64"	23/32"	1/4-28 x 3/8" Pan Head
1432-8	2-13/64"	55/64"	23/32"	1/4-28 x 3/8" Pan Head
1433	2-21/32"	1-1/16"	59/64"	1/4-28 x 3/8" Pan Head
1433-8	2-21/32"	1-1/16"	59/64"	1/4-28 x 3/8" Pan Head
1434	3-5/64"	1-21/64"	1-11/64"	1/4-28 x 3/8" Pan Head
1434-8	3-5/64"	1-21/64"	1-11/64"	1/4-28 x 3/8" Pan Head