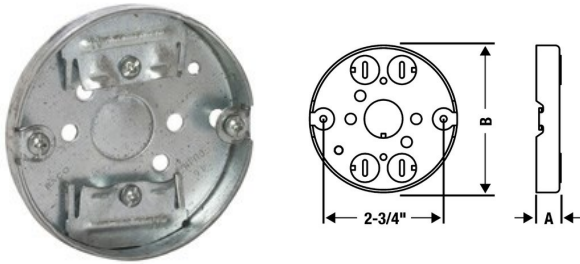


**CEILING PANS****3-1/2 in. Round Ceiling Pan - Drawn with Nonmetallic Sheathed Cable Clamps**  
1/2 in. Depth**A36.1**

Catalog #: 8292

**APPLICATIONS**

RACO® Ceiling Pans are used in the installation of ceiling or wall lighting fixtures  
N/A

**PRODUCT FEATURES**

Combination screw heads provide for faster installation

**UL LISTED**

File E195978

**FIRE RESISTANCE**

Acceptable for use in 2-hour rated walls and ceilings

**US PATENTS**

7,148,420; 4,892,211

**OTHER PATENTS**

Canada 1,324,360; Mexico 166.125

**GENERAL PRODUCT INFORMATION**

Wiring System: Nonmetallic Sheathed Cable  
Country of Origin: USA

**RECOMMENDED MAX LOAD**

Ceiling Fan (Dynamic) Lbs.: No  
Fixture (Static) Lbs.: 50

**CONFIGURATION**

Cable Priouts: 4  
Drawn or Welded: Drawn  
Raised Ground: No  
Side Knockout(s): ---  
Bottom Knockouts(s): (1) 1/2 in.

**DRAWING DIMENSIONS**

Dimension A: 1/2 in.  
Dimension B: 3-3/8 in.

**PRODUCT MEASUREMENTS**

Depth: 1/2 in.  
Cubic Inches (cm3): 4.0 (65.5)  
Wt. Ea. (Lbs.): 0.295  
Product Length (in.): 0.56  
Product Width (in.): 3.38  
Product Height (in.): 3.38

**PACKAGING**

Minimum Pack Qty.: 25  
Std. Pkg.: 25  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 29.50  
Ship Carton Length (in.): 9.00  
Ship Carton Width (in.): 4.63  
Ship Carton Height (in.): 7.25  
Ctn Weight (Lbs.): 13.38  
Pallet Qty: 4200  
UPC Number: 050169002926  
I2of5: 40050169002924