




WELDED GANG BOXES WITH CONDUIT KO'S

Gang Boxes, 1-5/8 in. Deep - Welded with Conduit KO's
7-Gang

A54

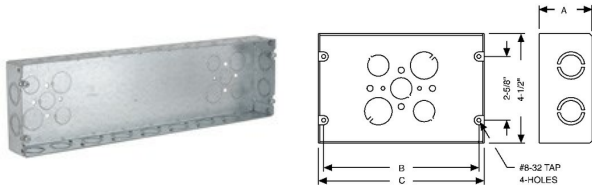

Catalog #: 956

APPLICATIONS

RACO® Gang boxes are used where a number of wiring devices are to be centrally located
N/A

PRODUCT FEATURES

Gang boxes save time in installation, no need to gang boxes together
Have 1/2" and 3/4" concentric KO's for use with a wide variety of wiring methods
Bottom KO pattern, 3-1/2" and 2-3/4" at either end of box
Accepts two styles of covers, flat and 3/4" raised device cover
Use low voltage partitions #947 or #949

UL LISTED

File E195978

GENERAL PRODUCT INFORMATION

Wiring System: Conduit
Country of Origin: USA

CONFIGURATION

Top & Bottom Knockouts(s): (18) 1/2-3/4 in. Concentric
Back Knockout(s): (6) 1/2 in. & (4) 3/4 in.
Gangs: 7
Side Knockout(s): (4) 1/2-3/4 in. Concentric

DRAWING DIMENSIONS

Dimension A: 1-5/8 in.
Dimension B: 15-7/16 in.
Dimension C: 15-7/8 in.

PRODUCT MEASUREMENTS

Depth: 1-5/8 in.
Cubic Inches (cm3): 111.5 (1827.1)
Wt. Ea. (Lbs.): 3.044
Product Length (in.): 1.63
Product Width (in.): 4.50
Product Height (in.): 15.88

PACKAGING

Minimum Pack Qty.: 1
Std. Pkg.: 1
Product UPC-A Labeled: No
Weight (Lbs. Per/C): 304.40
Ship Carton Length (in.): 20.00
Ship Carton Width (in.): 2.44
Ship Carton Height (in.): 4.88
Ctn Weight (Lbs.): 3.04
Pallet Qty: 144
UPC Number: 050169009567
I2of5: 50050169009562