

**NEW**

# Outdoor Recessed Wall Outlet Enclosure



MR420CG

**EXTRA DUTY**



MR420CW




MR420CZ

Fits Duplex, GFCI or Round Receptacle (not included)

**Electrical Box**  
21.0 CU IN wiring capacity  
(4) NM Sheathed cable clamps  
(2) 0.5"/0.75" eccentric knockouts

Stud or Wall Mount  
Suitable for 2x4 framing (depth) or larger

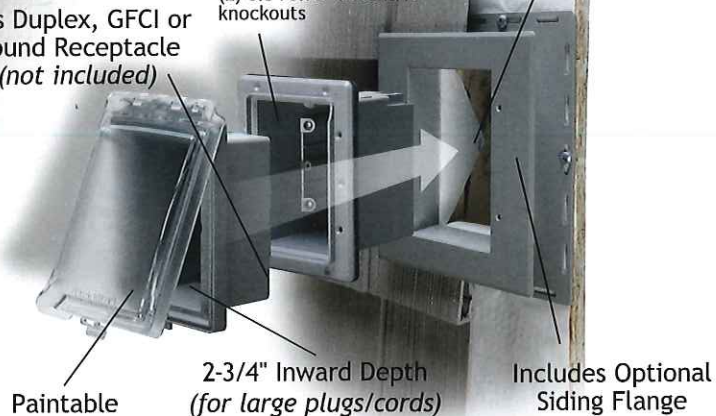

Paintable

2-3/4" Inward Depth (for large plugs/cords)

Includes Optional Siding Flange

Shown with exposed siding for reference only

- New Work and Old Work compatible for all common siding types and materials: Vinyl | Wood | Stucco | Brick/Block
- Extra-Duty Non-Metallic
- Weatherproof While in Use
- Mounts Horizontally or Vertically
- Compatible with Duplex, GFCI or Round Receptacle. (receptacle not included)
- Size: 4.56" W x 6.15" H x 4.98" D

CATALOG #	COLOR	PKG. TYPE	STD. PKG.	UPC	12 of 5
<b>Outdoor Recessed Wall Outlet Enclosure</b>					
MR420CG	Clear/Gray	Boxed	4	050169964200	50050169964205
MR420CW	Clear/White	Boxed	4	050169998304	50050169998309
MR420CZ	Clear/Bronze	Boxed	4	050169998311	50050169998316



Stucco Installation



Brick Installation (Horizontal)