

## Grounding Accessories

- Solid and stranded pigtail lead wires are convenient for device grounding applications
- Grounding screws offer a unique thread-forming, hole-finding feature plus combination hex, Phillips, slotted and Robertson head

### Grounding Tails - Stranded Wire

 


Fig. A - #14 AWG  
Fig. B - #12 AWG



Fig. C



Fig. D



Fig. E

Stranded Wire Grounding Tails	Quantity	Cat. No.	Fig.
14 AWG stranded, 7-3/4 in. tail w/#10 fork & 10 ring and ground screw	Bag of 25	<b>30-3183</b>	A
12 AWG stranded, 7-3/4 in. tail w/#10 fork & 10 ring and ground screw	Bag of 25	<b>30-3184</b>	B
12 AWG stranded, 7-3/4 in. tail w/#10 fork & 10 ring and ground screw	Bundle of 100	<b>30-3284</b>	B
12 AWG solid tail, one stripped end, one end w/ground screw, joined to 12 AWG stranded tail at a ring terminal, w/fork terminal on second end	Bundle of 25	<b>30-3286</b>	—
12 AWG stranded, 2-wire tail joined w/#10 ring and ground screw, one stripped-end tail and one 10 fork tail	Bag of 25	<b>30-3287</b>	C
12 AWG stranded, 2-wire tail joined w/#10 ring and ground screw and two #10 fork tails	Bag of 25	<b>30-3288</b>	D
12 AWG stranded, 3-wire tail joined w/#10 ring and ground screw, one stripped-end tail and two 10 fork tails	Bag of 25	<b>30-3289</b>	E
12 AWG stranded, 7-3/4 in. tail w/#10 fork and #10 ring and ground screw	Plastic Box of 50	<b>30-3385</b>	B

Custom tails available. Contact your IDEAL Sales Representative for further information.

### Grounding Tails - Solid Wire



Fig. A



Fig. A - 6-1/2 in. length

Fig. B - 7 in. length

Fig. C - 8 in. length

Fig. D - 10 in. length



Fig. E

Solid Wire Grounding Tails	Quantity	Cat. No.	Fig.
Pail-o-Tails™ 12 AWG solid, 6.5 in. tail w/loop & ground screw and stripped end	Pail of 500 (Bundles of 100)	<b>30-3365</b>	A
14 AWG solid, 8 in. tail w/loop & ground screw and stripped end	Box of 50	<b>30-3390</b>	E
12 AWG solid, 8 in. tail w/loop & ground screw and stripped end	Box of 50	<b>30-3392</b>	C
12 AWG solid, 10 in. tail w/loop & ground screw and stripped end	Bundle of 50	<b>30-3394</b>	D
12 AWG solid, 8 in. tail w/loop & ground screw and stripped end	Plastic box of 100	<b>30-3399</b>	C
12 AWG solid, 7 in. tail w/loop & ground screw and stripped end	Bag of 50	<b>30-3407</b>	B
12 AWG solid, 10 in. tail w/loop & ground screw and stripped end	Bag of 50	<b>30-3410</b>	D
12 AWG solid, 8 in. tail w/loop & ground screw and stripped end	Bundle of 50	<b>30-3496</b>	C

### Grounding Accessories

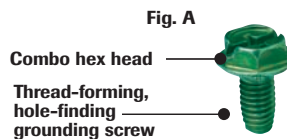


Fig. A  
Combo hex head  
Thread-forming,  
hole-finding  
grounding screw



Fig. B

Grounding Accessories	Qty.	Cat. No.	Fig.
Ground Screw, thread-forming, hole-finding tip combination hex, Phillips, slotted and Robertson head	Pack of 50	<b>30-3194</b>	A
Ground Screw, thread-forming, hole-finding tip combination hex, Phillips, slotted and Robertson head	Bag of 100	<b>30-3294</b>	A
Grounding clip – accepts 10, 12 or 14 AWG Wire	Pack of 100	<b>30-3395</b>	B
Ground Screw, thread-forming, hole-finding tip combination hex, Phillips, slotted and Robertson head	Jar of 400	<b>30-3494</b>	A